


Sta-Kon®

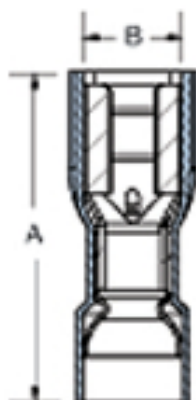

T&B Catalog Number:

RA2573

UPC Number:

78621085669

Description:

Fully Insulated Nylon Female - 250 Series Disconnects For Wire Range 22-18 Length 0.97, Tab Size .250 x .032, Red

Status:

Active

WEB_USE

-T&B Product Line	029
-US Cutsheet PDF Catalog Link	http://www-public.tnb.com/contractor/docs/stakon.pdf

Features

-	Unique construction of the female disconnect offers long-term dependability. Brazed seam serrated barrel provides maximum tensile strength.
---	---

General

-Disconnect Type	Female - 250 Series
-Insulation Type	Fully Insulated Nylon
-Terminal Series	RA
-Material	Brass
-Finish	Electro - Tin Plated
-Color	Red
-Wire Range	22-18
-Tab Size	.250 x .032

Dimension Information

-Maximum Insulation (inches)	.165
-Stock Thickness	.03
-A (inches)	.97
-B (inches)	.38

Specifications

-Temperature Rating	105°C
-Voltage Rating	600V
-Flammability Rating	UL 94 V-2

Tooling

-Tool Charts	Available on Website
-Application Tools	WT145C, WT2000, WT112M, ERG4001, ERG4003
-Recommended Tool	ERG4001

Packaging

-T&B Order Multiple	1000
-T&B Inner Pack	1000
-Package in Units	10000
-Package Type	Bulk
-T&B Sold in UOM	Each
-T&B Weight Per UOM	0.34 lbs. per 100
-Alternate Package Qty	18RA2577

Application Support

-Overview	Available on Website
-Wire Guide Tables	Available on Website

Certifications

-RoHS Compliance	Yes
------------------	-----

Certifications



File Nbr:
E66716

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com