




# Sta-Kon®

**T&B Catalog Number:** RA857  
**UPC Number:** 78621081740  
**Description:** Insulated Vinyl Ring Terminal For Wire Range 22-16 Stud Size #6, Red

**Status:** Active

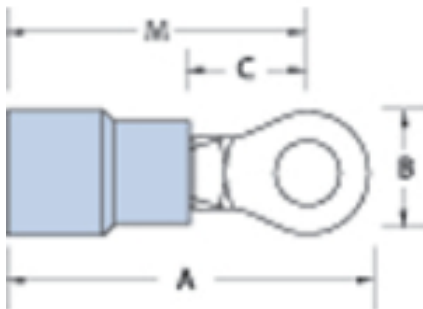

WEB_USE	
-T&B Product Line	029
-US Cutsheet PDF Catalog Link	<a href="http://www-public.tnb.com/contractor/docs/stakon.pdf">http://www-public.tnb.com/contractor/docs/stakon.pdf</a>

Features	
-	These terminals are self-insulated with a PVC insulation sleeve of extra length to give protection and relieve bending stress at wire's flex point. Brazed seam barrel is serrated to obtain high pull-out value.

General	
-Insulation Type	Insulated Vinyl
-Terminal Series	RA
-Material	Copper
-Finish	Electro -Tin Plated
-Color	Red
-Wire Range	22-16
-Stud Size	#6

Dimension Information	
-Maximum Insulation (inches)	.150
-Stock Thickness	.03
-A (inches)	.94
-B (inches)	.25
-C (inches)	.27
-M (inches)	.81

Specifications	
-Temperature Rating	105°C
-Voltage Rating	600V
-Flammability Rating	UL 94 V-0

Tooling	
-Tool Charts	Available on Website
-Application Tools	WT145C, WT2000, WT112M, ERG4001, ERG4003
-Recommended Tool	ERG4001

Packaging	
-T&B Order Multiple	1000
-T&B Inner Pack	1000
-Package in Units	10000
-Package Type	Bulk
-T&B Sold in UOM	Each
-T&B Weight Per UOM	0.22 lbs. per 100
-Alternate Package Qty	18RA-6

Application Support	
-Overview	Available on Website
-Wire Guide Tables	Available on Website

### Notes

-

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk catalog numbers.

### Certifications

-RoHS Compliance

Yes

### Certifications



File Nbr:

E9809

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com