




Sta-Kon®

T&B Catalog Number: RB14-6F
UPC Number: 78621080403
Description: Insulated Nylon Fork Terminal For Wire Range 18-14 Stud Size #6, Blue

Status: Active

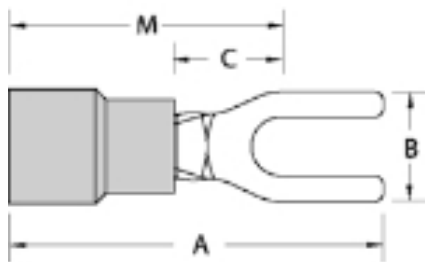

WEB_USE

-T&B Product Line -- 029
 -US Cutsheet PDF Catalog Link -- <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

- -- Inner bronze insulation grip sleeve lengthens flex radius of conductor and eliminates conductor creep. Nylon jacket is color-coded.

General

-Insulation Type -- Insulated Nylon
 -Terminal Series -- RB
 -Material -- Copper
 -Finish -- Electro -Tin Plated
 -Color -- Blue
 -Wire Range -- 18-14
 -Stud Size -- #6

Dimension Information

-Maximum Insulation (inches) -- .162
 -Stock Thickness -- .03
 -A (inches) -- .87
 -B (inches) -- .31
 -C (inches) -- .25
 -M (inches) -- .71

Specifications

-Temperature Rating -- 105°C
 -Voltage Rating -- 600V
 -Flammability Rating -- UL 94 V-2

Tooling

-Tool Charts Available on Website
 -Application Tools -- WT145C, WT2000, WT112M, ERG4001, ERG4003, WT145A
 -Recommended Tool -- ERG4001

Packaging

-T&B Order Multiple -- 100
 -T&B Inner Pack -- 100
 -Package in Units -- 500
 -Package Type -- Standard
 -T&B Sold in UOM -- Each
 -T&B Weight Per UOM -- 0.27 lbs. per 100
 -Alternate Package Qty -- RB1113

Application Support

-Overview Available on Website
 -Wire Guide Tables Available on Website

Certifications

-RoHS Compliance -- Yes

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com