




Sta-Kon®

T&B Catalog Number: RB2573
UPC Number: 78621085680
Description: Fully Insulated Nylon Female - 250 Series Disconnects For Wire Range 16-14 Length 0.97, Tab Size .250 x .032, Blue
Status: Active

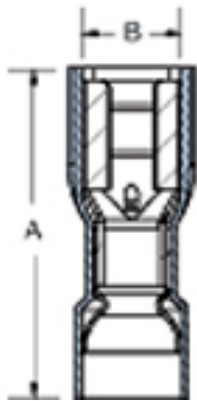

WEB_USE

-T&B Product Line -- 029
 -US Cutsheet PDF Catalog Link -- <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

- -- Unique construction of the female disconnect offers long-term dependability. Brazed seam serrated barrel provides maximum tensile strength.

General

-Disconnect Type -- Female - 250 Series
 -Insulation Type -- Fully Insulated Nylon
 -Terminal Series -- RB
 -Material -- Brass
 -Finish -- Electro -Tin Plated
 -Color -- Blue
 -Wire Range -- 16-14
 -Tab Size -- .250 x .032

Dimension Information

-Maximum Insulation (inches) -- .185
 -Stock Thickness -- .03
 -A (inches) -- .97
 -B (inches) -- .38

Specifications

-Temperature Rating -- 105°C
 -Voltage Rating -- 600V
 -Flammability Rating -- UL 94 V-2

Tooling

-Tool Charts Available on Website
 -Application Tools -- WT145C, WT2000, WT112M, ERG4001, ERG4003
 -Recommended Tool -- ERG4001

Packaging

-T&B Order Multiple -- 1000
 -T&B Inner Pack -- 1000
 -Package in Units -- 10000
 -Package Type -- Bulk
 -T&B Sold in UOM -- Each
 -T&B Weight Per UOM -- 0.35 lbs. per 100
 -Alternate Package Qty -- 14RB2577

Application Support

-Overview Available on Website
 -Wire Guide Tables Available on Website

Certifications

-RoHS Compliance

-- Yes

Certifications



File Nbr:

E66716

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com