


Sta-Kon®



T&B Catalog Number: RC10-8
UPC Number: 78621080434
Description: Insulated Nylon Ring Terminal For Wire Range 12-10 Stud Size #8, Yellow

Status: Active

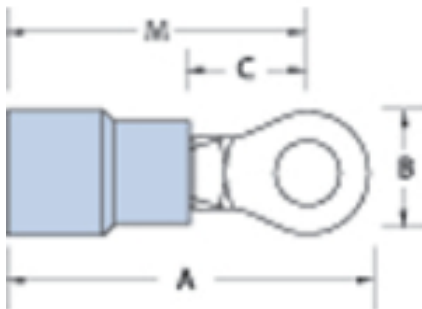

WEB_USE

-T&B Product Line -- 029
 -US Cutsheet PDF Catalog Link -- <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

- -- Self-insulated with high dielectric-strength nylon sleeves. An inner bronze insulation grip sleeve lengthens the flexing radius of the conductor and eliminates conductor creep.

General

-Insulation Type -- Insulated Nylon
 -Terminal Series -- RC
 -Material -- Copper
 -Finish -- Electro -Tin Plated
 -Color -- Yellow
 -Wire Range -- 12-10
 -Stud Size -- #8

Dimension Information

-Maximum Insulation (inches) -- .210
 -Stock Thickness -- .04
 -A (inches) -- 1.00
 -B (inches) -- .37
 -C (inches) -- .27
 -M (inches) -- .81

Specifications

-Temperature Rating -- 105°C
 -Voltage Rating -- 600V
 -Flammability Rating -- UL 94 V-2

Tooling

-Tool Charts Available on Website
 -Application Tools -- WT2000, WT112M, WT145C, ERG4001, ERG4003, WT145A
 -Recommended Tool -- ERG4001

Packaging

-T&B Order Multiple -- 50
 -T&B Inner Pack -- 50
 -Package in Units -- 250
 -Package Type -- Standard
 -T&B Sold in UOM -- Each
 -T&B Weight Per UOM -- 0.59 lbs. per 100
 -Alternate Package Qty -- RC863

Application Support

-T&B Sales Drawings wsd-000269

-Overview Available on Website
-Wire Guide Tables Available on Website

Certifications

-RoHS Compliance -- Yes

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com