




Sta-Kon®

T&B Catalog Number: RC2577F
UPC Number: 78621089448
Description: Insulated Nylon Female - 250 Series Disconnects For Wire Range 12-10 Length 0.8, Tab Size .250 x .032 , Yellow
Status: Active

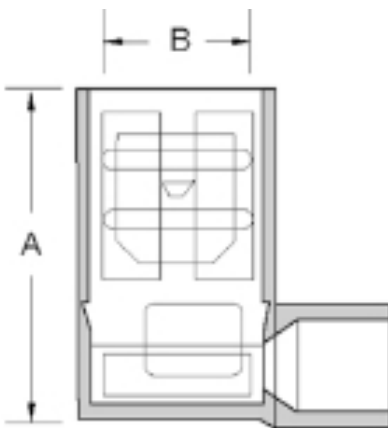

WEB_USE	
-T&B Product Line	-- 029
-US Cutsheet PDF Catalog Link	-- http://www-public.tnb.com/contractor/docs/stakon.pdf

Features	
-	-- Unique construction of the female disconnect offers long-term dependability. Brazed seam serrated barrel provides maximum tensile strength.

General	
-Disconnect Type	-- Female - 250 Series
-Insulation Type	-- Insulated Nylon
-Terminal Series	-- RC
-Material	-- Brass
-Finish	-- Electro -Tin Plated
-Color	-- Yellow
-Wire Range	-- 12-10
-Tab Size	-- .250 x .032

Dimension Information	
-Maximum Insulation (inches)	-- .245
-Stock Thickness	-- .04
-A (inches)	-- .80
-B (inches)	-- .88

Specifications	
-Temperature Rating	-- 105°C
-Voltage Rating	-- 600V
-Flammability Rating	-- UL 94 V-2

Tooling	
-Tool Charts	Available on Website
-Application Tools	-- WT145C, WT2000, WT112M, ERG4001, ERG4003
-Recommended Tool	-- ERG4001

Packaging	
-T&B Order Multiple	-- 500
-T&B Inner Pack	-- 500
-Package in Units	-- 5000
-Package Type	-- Bulk
-T&B Sold in UOM	-- Each
-T&B Weight Per UOM	-- 0.67 lbs. per 100
-Alternate Package Qty	-- RC10250A

Application Support	
-Overview	Available on Website
-Wire Guide Tables	Available on Website

Certifications

-RoHS Compliance

-- Yes

Certifications



File Nbr:

E66716

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com