


# Sta-Kon®



**T&B Catalog Number:** RC10-10  
**UPC Number:** 78621080438  
**Description:** Insulated Nylon Ring Terminal For Wire Range 12-10 Stud Size #10, Yellow

**Status:** Active

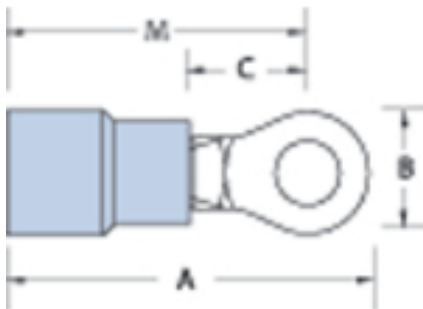

### WEB\_USE

-T&B Product Line -- 029  
 -US Cutsheet PDF Catalog Link -- <http://www-public.tnb.com/contractor/docs/stakon.pdf>

### Features

- -- Self-insulated with high dielectric-strength nylon sleeves. An inner bronze insulation grip sleeve lengthens the flexing radius of the conductor and eliminates conductor creep.

### General

-Insulation Type -- Insulated Nylon  
 -Terminal Series -- RC  
 -Material -- Copper  
 -Finish -- Electro -Tin Plated  
 -Color -- Yellow  
 -Wire Range -- 12-10  
 -Stud Size -- #10

### Dimension Information

-Maximum Insulation (inches) -- .210  
 -Stock Thickness -- .04  
 -A (inches) -- 1.00  
 -B (inches) -- .37  
 -C (inches) -- .27  
 -M (inches) -- .81

### Specifications

-Temperature Rating -- 105°C  
 -Voltage Rating -- 600V  
 -Flammability Rating -- UL 94 V-2

### Tooling

-Tool Charts Available on Website  
 -Application Tools -- WT2000, WT112M, WT145C, ERG4001, ERG4003, WT145A  
 -Recommended Tool -- ERG4001

### Packaging

-T&B Order Multiple -- 50  
 -T&B Inner Pack -- 50  
 -Package in Units -- 250  
 -Package Type -- Standard  
 -T&B Sold in UOM -- Each  
 -T&B Weight Per UOM -- 0.58 lbs. per 100  
 -Alternate Package Qty -- RC363

### Application Support

-T&B Sales Drawings wsd-000269

-Overview Available on Website  
-Wire Guide Tables Available on Website

### Certifications

-RoHS Compliance -- Yes

### Certifications



File Nbr:

E9809

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com