




Sta-Kon®

T&B Catalog Number: RC10-14F
UPC Number: 78621080443
Description: Insulated Nylon Fork Terminal For Wire Range 12-10 Stud Size 1/4, Yellow

Status: Active

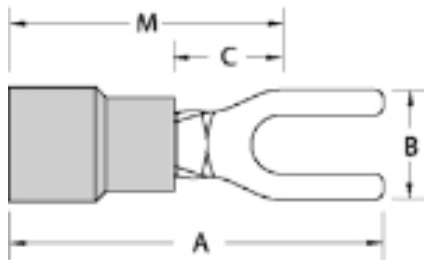

WEB_USE

-T&B Product Line	-- 029
-US Cutsheet PDF Catalog Link	-- http://www-public.tnb.com/contractor/docs/stakon.pdf

Features

-	-- Inner bronze insulation grip sleeve lengthens flex radius of conductor and eliminates conductor creep. Nylon jacket is color-coded.
---	--

General

-Insulation Type	-- Insulated Nylon
-Terminal Series	-- RC
-Material	-- Copper
-Finish	-- Electro -Tin Plated
-Color	-- Yellow
-Wire Range	-- 12-10
-Stud Size	-- 1/4

Dimension Information

-Maximum Insulation (inches)	-- .210
-Stock Thickness	-- .04
-A (inches)	-- 1.12
-B (inches)	-- .50
-C (inches)	-- .27
-M (inches)	-- .86

Specifications

-Temperature Rating	-- 105°C
-Voltage Rating	-- 600V
-Flammability Rating	-- UL 94 V-2

Tooling

-Tool Charts	Available on Website
-Application Tools	-- WT145C, WT2000, WT112M, ERG4001, ERG4003, WT145A
-Recommended Tool	-- ERG4001

Packaging

-T&B Order Multiple	-- 50
-T&B Inner Pack	-- 50
-Package in Units	-- 250
-Package Type	-- Standard
-T&B Sold in UOM	-- Each
-T&B Weight Per UOM	-- 0.68 lbs. per 100
-Alternate Package Qty	-- RC1163

Application Support

-Overview	Available on Website
-Wire Guide Tables	Available on Website

Certifications

-RoHS Compliance -- Yes

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com