

SPECIFICATION TYPE : 8RB



FOR YOUR REFERENCE ONLY
(NOT OFFICIAL)

Customer

Customer's Dwg. Number

Rev.

Customer's Part Number

Toko Sample Number

#187LY-363K

Approved by


Signature


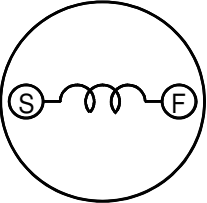
Date

One copy with your signature is required as your confirmation to our specifications.

Physical Dimensions

Unit : mm , Tolerance : ± 0.3

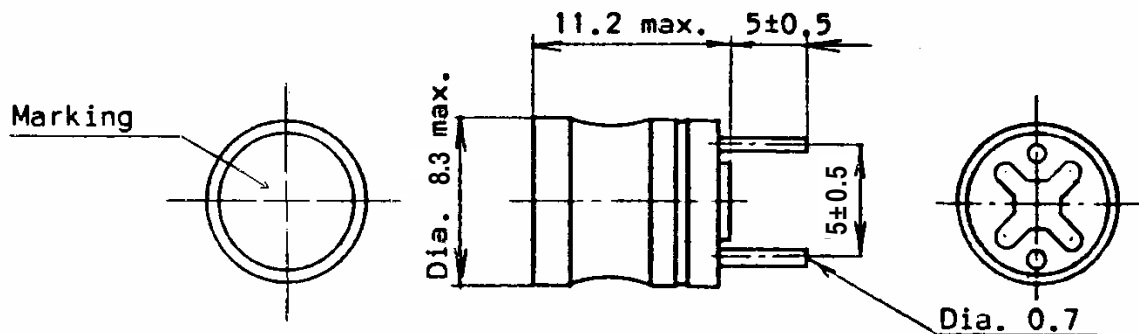

Electrical characteristics	Specifications		Note
Inductance & Tolerance	36mH $\pm 10\%$		at 79.6kHz
Unloaded Q	100min		
Marking  (Top view)	Number of turns		Connection (Bottom view)  s: start of winding
	S - F	1021	
		(ref.)	
Wire(mm)		0.07	

Note :

- 1) Inductance and Qu measured by Q-meter MQ-1601 or equivalent.
- 2) Above P/N is Lead-Free.
- 3) For non automotive usage.

Approved by	Checked by	Made by	Orig	2011-12-21	
			Issues		Sign



TOKO Electronic Mfg. Co., Ltd.

8/F Yau Lee Centre, 45 Hoi Yuen Road,
Kwun Tong, Kowloon, Hong Kong.
Tel: 852-23428131 Fax: 852-27979161