

Accessories

HDD Expansion Kit



UNO-2000 HDD Expansion Kit

- Dimensions: 188.8 x 106.5 x 21.0 mm (W x D x H) (Only extension kit)

Supported Models

- UNO-2050GL, UNO-2053GL, UNO-2059GL, UNO-2052E

Packing List

- Extend chassis, 1 piece 12 cm IDE cable, post for assembly 2.5" HDD

Ordering Information

- **UNO-HD20-AE** UNO-2000 series HDD expansion kit

DIN-rail Expansion Kit



UNO-2100 Series DIN-rail Kit

- Supports DIN-rail mounting (EN50022, 35 mm X 7.5 mm)

Supported Model List

- All UNO-2100 series

Ordering Information

- **UNO-DIN21-BE** UNO-2100 series DIN-rail kit

UNO-3000 Mounting Kit

Supported Models UNO-3072L, UNO-3072, UNO-3074

Panel Mounting Kit



Ordering Information

- **UNO-PM70-AE** Panel mounting kit for UNO-3000 series

Stand Mounting Kit



Ordering Information

- **UNO-SM70-AE** Stand mounting kit for UNO-3000 series

Wall Mounting Kit



Ordering Information

- **UNO-WM74-AE** Wall mounting kit for UNO-3074-P11E
- **UNO-WM72-AE** Wall mounting kit for UNO-3072L-C11E/ UNO-3072-P11E

Note: For UNO-3072L-C22BE, UNO-3074-P32BE wall mount requirement, please use UNO-PM70-AE mounted on the back as a wallmount kit

Supported Models UNO-3072LA, UNO-3082, UNO-3084

Panel Mounting Kit



Ordering Information

- **UNO-PM80-AE** Panel mounting kit for UNO-3082/UNO-3084 & UNO-3072LA

Stand Mounting Kit



Ordering Information

- **UNO-SM80-AE** Stand mounting kit for UNO-3082/UNO-3084 & UNO-3072LA

Wall Mounting Kit



Ordering Information

- **UNO-WM80-AE** Wall mounting kit for UNO-3082/3084 and UNO-3072LA series

VESA Mounting Kit



UNO-2000 Series VESA Mounting Kit

UNO-FPM21 could provide excellent integration of UNO and FPM models which could help installation easier and save more space in filed.

Features

- Dimensions: 271 x 163 x 12 mm (W x H x D) (Only extension kit)
- Supports VESA 75 and 100 monitor

Supported Models

- **UNO** All UNO-2000 series and UNO-2100 series
- **FPM** All FPM 12", 15", 17", 19" models

Ordering Information

- **UNO-FPM21-AE** UNO-2000 series VESA mount kit



UNO-1100 Series VESA Mounting Kit

Features

- Dimensions: 271 x 163 x 12 mm (W x H x D) (Only extension kit)
- Supports VESA 75 and 100 monitor

Supported Models

- **UNO** All UNO-1100 series
- **FPM** All FPM 12", 15", 17", 19" models

Ordering Information

- **UNO-FPM11-BE** UNO-1100 series VESA mount kit

PC/104 Expansion Kit

UNO-2100 Series PC/104 Expansion Kit



- Dimensions: 228 x 32 x 152 mm (W x H x D) (Only extension kit)
- Supports two PC/104 modules

Supported Model List

- **UNO-2170**
This kit includes one solid panel, one "2 x DB-9" panel and one "4 x DB-9" panel

Ordering Information

- **UNO-PCM21-AE** 2 x PC/104 expansion kit for UNO-2170



- Dimensions: 228 x 32 x 152 mm (W x H x D) (Only extension kit)
- Supports two PC/104 modules

Supported Model List

- **UNO-2171, UNO-2172, UNO-2176, UNO-2182**
This kit includes one solid panel, one "2 x DB-9" panel and one "4 x DB-9" panel

Ordering Information

- **UNO-PCM22-AE** 2 x PC/104 expansion kit for UNO-2100 series

Power Adapter and Power Cord Solutions

Industrial Grade Power Adapters



Features

- Input voltage: 100~240 V_{AC}, 47 ~ 63 Hz
 - Output Voltage: 24 V_{DC}
 - Operating Temperature: -20 ~ 70° C
- Note: Need to order power cord separately

Commercial Grade Power Adapters

Features

- Input voltage: 100 ~ 240 V_{AC}, 50 ~ 60 Hz
 - Output Voltage: 19 V_{DC}
 - Operating Temperature: 0 ~ 40° C
- Note: Need to order power cord separately

Ordering Information

- **1757002321**
63W AC to DC UNO series power adapter
- **1702002600**
Power Cable US Plug 1.8 M
- **1702031801**
Power Cable UK Plug 1.8 M
- **1702002605**
Power Cable EU Plug 1.8 M
- **1702031836**
Power Cable China/Australia Plug 1.8 M

Ordering Information

- **1757002682**
65W AC to DC power adapter
- **1700001524**
Power Cable 3-Pin US type 1.8M
- **170203183C**
Power Cable 3-pin EU type 1.8 M
- **170203180A**
Power Cable 3-pin UK type 1.8 M

UNO-4672 Expansion Solution


UNO-P168

Specifications

- 8-port RS-232/422/485 (DB-9)
- 2,500 V_{DC} EFT Protection
- 2,500 V_{DC} Isolation Protection
- Baud-rate (bps) : 50 ~ 921.6 k

Ordering Information

- **UNO-P168-AE** 8-port RS-232/422/485 w/Iso and EFT, PCI-104 for UNO-4672

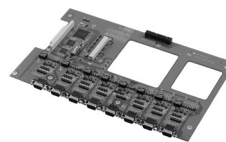

UNO-P166

Specifications

- 6-port RS-232/422/485 (DB-9), 2-port IRIG-B
- 2,500 V_{DC} EFT Protection
- 2,500 V_{DC} Isolation Protection
- Baud-rate (bps) : 50 ~ 921.6 k
- IRIG-B Time Code Input Interface: RS-422/485 (DB9), TTL (BNC-type)

Ordering Information

- **UNO-P166-AE** 6-port RS-232/422/485 w/Iso and EFT, 2-port IRIG-B, PCI-104 for UNO-4672

