

AkroBins®



- Control inventories, shorten assembly times, and minimize parts handling.
- Heavy-duty bins securely stack atop each other, sit on shelving, and hang from Akro-Mils racks, panels, rails, and carts.
- Molded of high-density polypropylene, AkroBins are unaffected by weak acids and alkalis.
- Sturdy, one-piece construction is water, rust, and corrosion-proof.
- Guaranteed not to crack or break under normal load conditions as stated in our 1-year limited warranty.
- Autoclavable up to 250° F.
- Available in 12 sizes and 4 colors: Red, Yellow, Blue, and Stone.



Anti-slide stop prevents stacked bins from shifting forward

Full-width hanger lip supports bin on hanging system




Curved-bottom hopper front makes it easy to retrieve small parts

Large front label slot allows larger bar code scanning

Extra-wide stacking edge saves space and prevents spills


Reinforced side ribs add strength & prevent spreading when stacked

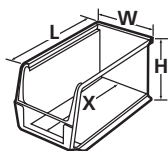

30270



 30235



30239



30230



30210

AkroBins

Model No.	Outside Dimensions						Inside Dimensions								Bin Load Capacity On Rack**	Ctn. Qty.
	Inches			mm			Inches				mm					
	L	W	H	L	W	H	L	W	H	X	L	W	H	X		
30210	5 ³ / ₈	4 ¹ / ₈	3	137	105	76	4 ³ / ₈	3 ⁷ / ₁₆	2 ¹ / ₁₆	4	120	87	71	102	10 lbs.	24
30220	7 ³ / ₈	4 ¹ / ₈	3	187	105	76	6 ³ / ₈	3 ⁷ / ₁₆	2 ¹ / ₁₆	6	171	87	71	152	10 lbs.	24
30224	10 ⁷ / ₈	4 ¹ / ₈	4	276	105	102	10 ¹ / ₄	3 ³ / ₁₆	3 ³ / ₈	9	260	87	95	229	30 lbs.	12
30230	10 ⁷ / ₈	5 ¹ / ₂	5	276	140	127	10 ¹ / ₄	4 ³ / ₈	4 ³ / ₈	9	260	111	121	229	30 lbs.	12
30234	14 ³ / ₈	5 ¹ / ₂	5	375	140	127	14 ¹ / ₁₆	4 ³ / ₈	4 ³ / ₈	12 ¹³ / ₁₆	357	111	121	325	50 lbs.	12
30235	10 ⁷ / ₈	11	5	276	279	127	10 ¹ / ₄	10	4 ³ / ₈	9	260	254	121	229	50 lbs.	6
30239	10 ³ / ₈	8 ¹ / ₄	7	273	210	178	10	6 ⁹ / ₁₆	6 ³ / ₈	8	254	167	171	203	50 lbs.	6
30240	14 ³ / ₈	8 ¹ / ₄	7	375	210	178	14	6 ⁹ / ₁₆	6 ³ / ₈	12	356	167	171	305	60 lbs.	12
30250	14 ³ / ₈	16 ¹ / ₂	7	375	419	178	14	14 ³ / ₈	6 ³ / ₈	12	356	375	171	305	75 lbs.	6
30255	10 ⁷ / ₈	16 ¹ / ₂	5	276	419	127	9 ³ / ₈	15	4 ³ / ₈	8 ¹ / ₂	248	381	121	216	60 lbs.	6
30265*	18	8 ¹ / ₄	9	457	210	229	17 ¹ / ₈	6 ³ / ₈	8 ¹ / ₄	14 ¹ / ₂	435	171	210	368	N/A	6
30270*	18	16 ¹ / ₂	11	457	419	279	17 ¹ / ₈	14 ³ / ₈	10 ¹ / ₄	13 ³ / ₄	435	375	260	349	N/A	3

One color per carton: Specify Red, Blue, Yellow, or Stone.

*Note 30265 and 30270 are not designed for use with hanging systems.


** CAUTION: When using bins with hanging systems, do not exceed the weight capacity for the rack which may be less than the total sum of bin capacities.

When compared to the competition, AkroBins:

- Support more weight when stacked.
- Handle more abuse.
- Hold more weight without cracking.



Accessories:

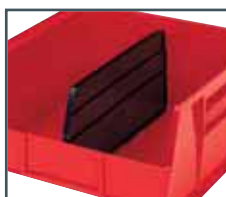

Dividers
Lengthwise dividers keep items separated in the bin.



Bin Lids*
"See-through" crystal styrene lids keep contents dust-free and protected.

Dividers

Model No.	Fits AkroBins	Pkg. Qty.
40210	30210 (1)	6
40220	30220 (1)	6
40230	30230 (1), 30235 (3)	6
40239	30239 (1)	6
40245	30240 (1), 30250 (1)	6
40265	30265 (1)	6
40270	30270 (3)	6

(Max. # of dividers)

*30224, 30255, 30234 no dividers available.

Bin Lids

Model No.	Fits AkroBins	Ctn. Qty.
30211	30210	24
30221	30220	24
30231	30230	12
30236	30235	6

*Assembly required – hinge pins included.

Super-Size AkroBins & Dollies

New!

Available in 5 sizes and 3 colors: Red, Yellow, and Blue.



30280



30281



30282



30283



30290



AkroBin solid steel Dollies (Model No. RU842HR2018 & RU842HR2918) are available for efficient parts transport.

- Control inventories, shorten assembly times, and minimize parts handling.
- Heavy-duty bins securely stack atop each other, or sit on shelving.
- Molded of high-density polypropylene, AkroBins are unaffected by weak acids and alkalis.
- Sturdy, one-piece construction is water, rust, and corrosion-proof.
- Guaranteed not to crack or break under normal load conditions as stated in our 1-year limited warranty.
- Autoclavable up to 250° F.



Extra-wide stacking ledge saves space and prevents spills

AkroBins can be used alone or stacked together for high-density storage



Easy to carry with large handle molded onto back of bin

Anti-slide stop prevents stacked bins from shifting forward

Large label area on front of bin

Curved-bottom hopper front makes it easy to retrieve small parts

Reinforced side ribs add strength and prevent spreading when stacked


Super-Sized AkroBins

Model No.	Outside Dimensions						Inside Dimensions						Max. Capacity Per Bin	Stacking Capacity /=Qty. Stacked	Ctn. Qty.		
	Inches			mm			Inches			mm							
	L	W	H	L	W	H	L	W	H	X	L	W	H	X			
30280	20	12 ³ / ₈	6	508	314	152	16 ⁷ / ₈	10 ¹ / ₁₆	5 ³ / ₈	15 ¹ / ₂	429	271	137	394	100lbs.	40lb./10	4
30281	20	12 ³ / ₈	8	508	314	203	16 ⁷ / ₈	10 ¹ / ₁₆	7 ³ / ₈	15 ¹ / ₂	429	271	187	394	150lbs.	50lb./7	3
30282	20	12 ³ / ₈	12	508	314	305	16 ⁷ / ₈	10 ¹ / ₁₆	11 ³ / ₈	15 ¹ / ₂	429	271	289	394	200lbs.	60lb./5	2
30283	20	18 ³ / ₈	12	508	467	305	16 ⁷ / ₈	16 ⁹ / ₁₆	11 ³ / ₈	15 ¹ / ₂	429	421	289	394	300lbs.	150lb./5	1
30290	29 ¹ / ₄	18 ³ / ₈	12	743	467	305	26 ¹ / ₈	16 ⁹ / ₁₆	11 ³ / ₈	24 ³ / ₄	664	421	289	629	300lbs.	150lb./5	1

One color per carton: Specify Red, Blue, or Yellow. Not recommended to hang on rack or panel systems.

Dollies

Model No.	Dimensions			Ctn. Qty.	Capacity Lbs.	Casters
	L	W	H			
RU842HR2018	20"	18 ³ / ₈ "	3 ¹ / ₂ "	1	500	2" Polyolefin
RU842HR2918	29 ¹ / ₄ "	18 ³ / ₈ "	3 ¹ / ₂ "	1	500	2" Polyolefin

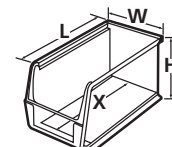

Nest & Stack Totes




Nest & Stack Totes stack when full; turn 180° and nest when empty.



- Extremely durable industrial-grade totes.
- Ideal for shipping, transfer, and storage applications.
- NST's stack with or without lids for storage and shipping, and nest when empty.
- Strong, high-density polyethylene will not rust, corrode, or bend out of shape even when fully loaded.
- Heavy-duty construction provides a longer service life resulting in lower replacement costs than other "budget-priced" totes.
- Smooth surfaces are easy to clean and resistant to most solvents and chemicals.
- Gray NST's are manufactured from FDA-approved materials.
- Optional lids protect contents from dust and damage.
- Available in 9 sizes and 3 colors: Red, Blue, and Gray.


Smooth surfaces are easy to clean

Comfortable grip makes handling easy

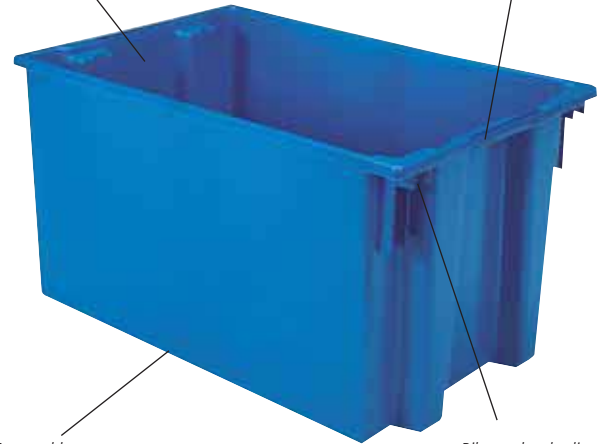

Textured bottoms provide a no-slip grip on conveyor belts

Ribs under the lip will prevent jamming when nested

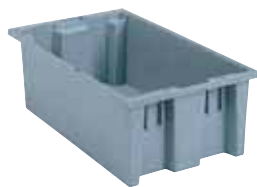

35180



35190



35225



35230



Dollies available to transport containers. See pages 36-37.

Optional Accessories:



Label Holders

Model No. 35101. Clear plastic label holders attach easily to NST's, with or without the lid in place. Holders accommodate labels up to 3" x 5". One size fits all totes.

Label Holders

Model No.	Package Qty.
35010	6




Lids

Lids snap tight to protect contents. See lids chart for matching lid size.

Lids Chart

NST Model No.	Optional Lids Model No.	Lid Ctn. Qty.
35180	35181	6
35185	35181	6
35190	35191	6
35195	35191	6
35200	35201	6
35225	35231	3
35230	35231	3
35240	35241	3
35300	35301	3

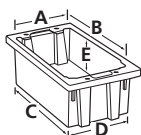

NST's

Model No.	Outside Dimensions			Inside Dimensions					NST Ctn. Qty.	Capacity Cu. Ft.								
	Inches			mm														
	L	W	H	L	W	H	A	B	C	D	E							
35180*	18	11	6	457	280	152	10	16	15¼	9¾	5½	254	406	387	238	149	6	.50
35185	18	11	9	457	280	229	10	16	15½	9½	8¾	254	406	384	232	225	6	.76
35190	19½	15½	10	495	394	254	14½	17	16	13¼	9¾	368	432	406	337	251	6	1.20
35195	19½	15½	13	495	394	330	14½	17	15¾	13¾	12¾	368	432	403	340	327	6	1.70
35200	19½	13½	8	495	343	203	12¾	17½	16¾	11½	7¾	314	454	416	292	200	6	.80
35225	23½	19½	10	597	495	254	18¼	20¾	19¾	16¾	9¾	464	530	492	429	251	3	2.00
35230	23½	19½	13	597	495	330	18¼	20¾	19½	16¾	12¾	460	530	495	429	327	3	2.60
35240	23½	15½	12	597	394	305	14¼	20¾	19¾	13	11¾	362	530	498	330	302	3	1.70
35300	29½	19½	15	750	495	381	18¼	26½	25½	16¾	14¾	464	676	638	422	378	3	3.70

One color per carton. Specify Red, Blue, or Gray.
* NST 35180 is made of high-density polypropylene.

ESD Containers

AkroBins®

- Akro-Mils ESD containers dissipate electrostatic charges which can severely damage sensitive electronic components.
- Sturdy, one-piece construction is water, rust, and corrosion proof, and heat resistant to 300°F.




Hanging Systems

- Storage systems provide convenient parts storage and retrieval.
- Six options let you choose the system that works best for you.



Shelf Bins

- Shelf Bins provide an economical solution to electronic component storage problems.
- Works with 12", 18", and 24" deep shelving or vertical storage and retrieval units.

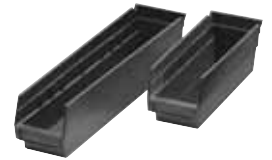


Grids

- Grids are compatible with most racks, shelving, and automated material handling equipment.
- Ribbed design gives added strength.



ESD AkroBins (Black Only)

Model No.	Outside Dimensions						Inside Dimensions						Bin Load Capacity On Rack	Ctn Qty.
	Inches			mm			Inches			mm				
	L	W	H	L	W	H	L	W	H	X	L	W	H	X
30210ESD	5 $\frac{3}{8}$	4 $\frac{1}{8}$	3	136	105	76	4 $\frac{3}{4}$	3 $\frac{7}{16}$	2 $\frac{13}{16}$	4	121	87	71	102
30220ESD	7 $\frac{3}{8}$	4 $\frac{1}{8}$	3	187	105	76	6 $\frac{3}{4}$	3 $\frac{7}{16}$	2 $\frac{13}{16}$	6	171	87	71	152
30230ESD	10 $\frac{7}{8}$	5 $\frac{1}{2}$	5	276	140	127	10 $\frac{1}{4}$	4 $\frac{3}{8}$	4 $\frac{3}{4}$	9	260	111	121	229
30235ESD	10 $\frac{7}{8}$	11	5	276	279	127	10 $\frac{1}{4}$	10	4 $\frac{3}{4}$	9	260	254	121	229
30240ESD	14 $\frac{3}{4}$	8 $\frac{1}{4}$	7	375	210	178	14	6 $\frac{9}{16}$	6 $\frac{3}{4}$	12	356	167	171	305

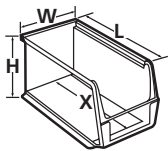

Louvered Panels And Bench Racks

Use this chart to determine the quantity of same-size AkroBins required to fill each panel.

See pages 5-6 for hanging system features.

Model No.	Description	Ctn. Qty.	AkroBin Model No. (Bin Wt. Capacity)				
			30210ESD (10 lbs.)	30220ESD (10 lbs.)	30230ESD (30 lbs.)	30235ESD (50 lbs.)	30240ESD (60 lbs.)
30618	18" x 19" Louvered Panel	4	16	16	9	-	-
30636	35 $\frac{3}{4}$ " x 19" Louvered Panel	4	32	32	18	9	8
98600	27 $\frac{3}{4}$ " Bench Rack	1	30	30	12	6	6
98636	36" Bench Rack	1	40	40	18	9	8



Grounding wire 98100 – Conducts static charges away from the storage system. Designed to convert existing Akro-Mils racks and hanging systems (see pages 5-6).

Louvered Floor Racks



Use this chart to determine the quantity of same-size AkroBins required to fill each floor rack.

Bins sold separately.

Model No.	Description	Dimensions			AkroBin Model Number							
		Inches		mm	30210ESD	30220ESD	30230ESD	30235ESD	30240ESD			
		L	W	H	L	W	H					
30626	Double-Sided Snap Fastener Louvered Rack	36	20	60	914	508	1524	192	192	108	54	48
30653	Louvered Floor Rack	35 $\frac{3}{4}$	32	75 $\frac{1}{8}$	908	813	1908	288	288	144	72	72

ESD Shelf Bins

Model No.	Outside Dimension						Inside Dimension						Ctn Qty.
	Inches			mm			Inches			mm			
	L	W	H	L	W	H	L	W	H	L	W	H	
30120ESD	11 $\frac{1}{8}$	4 $\frac{1}{8}$	4	295	105	102	10 $\frac{1}{4}$	3	4	260	76	102	24
30128ESD	17 $\frac{7}{8}$	4 $\frac{1}{8}$	4	454	105	102	16 $\frac{1}{2}$	3	4	419	76	102	12
30124ESD	23 $\frac{3}{8}$	4 $\frac{1}{8}$	4	600	105	102	22 $\frac{1}{2}$	3	4	562	76	102	12

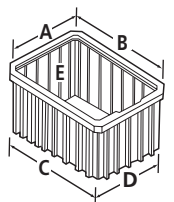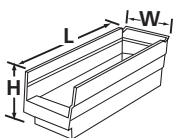

ESD Grids

Model No.	Outside Dimensions						Inside Dimensions						Ctn. Qty.				
	Inches			mm			Inches			mm							
	L	W	H	L	W	H	A	B	C	D	E	A	B	C	D	E	
33164ESD	16 $\frac{1}{2}$	10 $\frac{7}{8}$	4	419	276	102	9 $\frac{3}{8}$	14 $\frac{15}{16}$	14 $\frac{13}{16}$	9 $\frac{3}{16}$	3 $\frac{7}{8}$	238	379	376	233	98	12
33224ESD	22 $\frac{3}{8}$	17 $\frac{3}{8}$	4	568	441	102	15 $\frac{1}{16}$	20 $\frac{1}{16}$	20	15	3 $\frac{7}{8}$	383	510	508	381	98	6

Pick Rack Systems



Bench Pick Rack
Holds up to 24 bins on 3 shelves

- Improve workspace organization and efficiency with rack and bin systems
- Convenient, high-density storage with up to 192 bins
- Easy to assemble
- Angled shelves keep parts at the front of bins for easy access
- Choose from 4 styles available separately or in a package with Akro-Mils yellow Shelf Bins



Single Sided Pick Rack
Holds up to 96 bins on 8 shelves
Maximum 400 lb. weight capacity

Angled shelves
increase picking
efficiency

Single Sided Pick Rack 12"D x 36"W x 60"H

SKU Number	Description	Bin Model No.	Bin Dimensions L x W x H	Qty. of Bins	Bonus Bins*
APRS	Single Sided Pick Rack, no Bins	-	-	-	-
APRS110Y	Rack with Bins	30110	11-5/8" x 2-3/4" x 4"	96	-
APRS120Y	Rack with Bins	30120	11-5/8" x 4-1/8" x 4"	64	8
APRS130Y	Rack with Bins	30130	11-5/8" x 6-5/8" x 4"	40	8
APRS150Y	Rack with Bins	30150	11-5/8" x 8-3/8" x 4"	32	4
APRS170Y	Rack with Bins	30170	11-5/8" x 11-1/8" x 4"	24	-

*Due to case pack, Bonus Bins are included, at no extra charge.

Bench Pick Rack 12"D x 36"W x 21"H

SKU Number	Description	Bin Model No.	Bin Dimensions L x W x H	Qty. of Bins
APRBENCH	Bench Pick Rack, no Bins	-	-	-
APRBENCH 120	Bench Pick Rack with Bins	30120	11-5/8" x 4-1/8" x 4"	24
APRBENCH 150	Bench Pick Rack with Bins	30150	11-5/8" x 8-3/8" x 4"	12

Double Sided Pick Rack 24"D x 36"W x 60"H

SKU Number	Description	Bin Model No.	Bin Dimensions L x W x H	Qty. of Bins	Bonus Bins*
APRD	Double Sided Pick Rack, no Bins	-	-	-	-
APRD110Y	Rack with Bins	30110	11-5/8" x 2-3/4" x 4"	192	-
APRD120Y	Rack with Bins	30120	11-5/8" x 4-1/8" x 4"	128	16
APRD130Y	Rack with Bins	30130	11-5/8" x 6-5/8" x 4"	80	4
APRD150Y	Rack with Bins	30150	11-5/8" x 8-3/8" x 4"	64	8
APRD170Y	Rack with Bins	30170	11-5/8" x 11-1/8" x 4"	48	-

*Due to case pack, Bonus Bins are included, at no extra charge.

Mobile Kit

SKU Number	Description
APRDMOBILE	Mobile Kit For Double Sided Pick Rack



Double Sided Pick Rack
Holds up to 192 bins on 16 shelves
Maximum 800 lb. weight capacity

Double Sided Pick Rack & Mobile Kit
Creates a mobile double sided pick rack
Maximum 500 lb. weight capacity



Shelf Bins



Shelf bins tilt out for complete access to contents.


- Shelf Bins outlast corrugated bins – paying for themselves in reduced replacement costs.
- Superior construction allows Shelf Bins to be fully loaded without bulging or cracking.
- Durable polypropylene bins provide an attractive, neat appearance.
- Works with 12", 18", and 24" deep shelving, or vertical storage and retrieval units.
- One-piece construction is waterproof and unaffected by grease or oil.
- Available in 13 sizes and 3 colors: Red, Yellow, and Blue.

Wide hopper front allows easy access

Built-in rear hanglock allows bin to tilt out for complete access

Molded-in label holder identifies contents

Optional dividers increase versatility

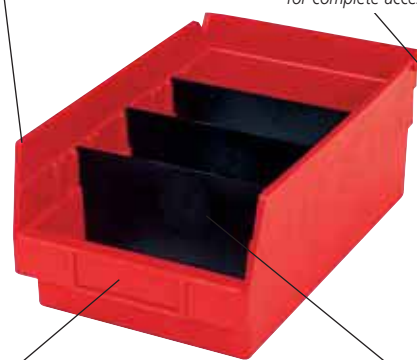


30120



30150



 
30158



30124




 30164



30174

Shelf Bins

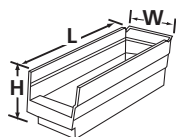

Model No.	Outside Dimension						Inside Dimension						Ctn Qty.	Cups Per Bin		Optional Divider
	Inches			mm			Inches			mm				Small 30101	Large 30102	
	L	W	H	L	W	H	L	W	H	L	W	H				
12" Shelf Bin																
30110	11 ⁵ / ₈	2 ³ / ₄	4	295	70	102	10 ¹ / ₄	1 ⁵ / ₈	4	260	41	102	24	3	-	None
30120	11 ⁵ / ₈	4 ¹ / ₈	4	295	105	102	10 ¹ / ₄	3	4	260	76	102	24	5	2	40120
30130	11 ⁵ / ₈	6 ³ / ₈	4	295	168	102	10 ¹ / ₄	5 ¹ / ₂	4	260	140	102	12	9	4	40130
30150	11 ⁵ / ₈	8 ³ / ₈	4	295	219	102	10 ¹ / ₄	7 ⁷ / ₈	4	260	181	102	12	11	4	40150
30170	11 ⁵ / ₈	11 ¹ / ₈	4	295	283	102	10 ¹ / ₄	10	4	260	254	102	12	15	6	40170
18" Shelf Bin																
30128	17 ⁷ / ₈	4 ¹ / ₈	4	454	105	102	16 ¹ / ₂	3	4	419	76	102	12	8	3	40120
30138	17 ⁷ / ₈	6 ⁵ / ₈	4	454	168	102	16 ¹ / ₂	5 ¹ / ₂	4	419	140	102	12	15	6	40130
30158	17 ⁷ / ₈	8 ³ / ₈	4	454	213	102	16 ¹ / ₂	7 ¹ / ₈	4	419	181	102	12	15	6	40150
30178	17 ⁷ / ₈	11 ¹ / ₈	4	454	283	102	16 ¹ / ₂	10	4	419	254	102	12	25	12	40170
24" Shelf Bin																
30124	23 ⁵ / ₈	4 ¹ / ₈	4	600	105	102	22 ¹ / ₈	3	4	562	76	102	12	11	4	40120
30164	23 ⁵ / ₈	6 ³ / ₈	4	600	168	102	22 ¹ / ₈	5 ¹ / ₂	4	562	140	102	6	21	8	40130
30184	23 ⁵ / ₈	8 ³ / ₈	4	600	213	102	22 ¹ / ₈	7 ⁷ / ₈	4	562	181	102	6	25	8	40150
30174	23 ⁵ / ₈	11 ¹ / ₈	4	600	283	102	22 ¹ / ₈	10	4	562	254	102	6	35	16	40170


One color per carton. Specify color: Red, Yellow, or Blue.

Optional Accessories:




Dividers

Black polypropylene dividers create compartments. Sizes to fit all bins except 30110. Each bin accepts up to 7 compartment dividers.

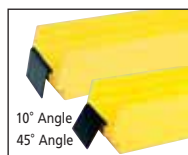

Extended Label Holders

Designed for larger bar code scanning. Label holders fit all shelf bins except the 30110.

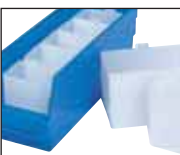

Bin Cups

Bin Cups lift out easily for parts retrieval and fit all Shelf Bins. (Refer to Shelf Bin chart for number of cups per bin.)

Dividers

Model No.	Fits Shelf Bins	Width	Pkg. Qty.
40120	30120, 30124, 30128	4 ¹ / ₈ "	24
40130	30130, 30138, 30164	6 ⁵ / ₈ "	24
40150	30150, 30158, 30184	8 ³ / ₈ "	24
40170	30170, 30174, 30178	11 ¹ / ₈ "	24

Extended Label Holders

Model No.	Description	Dimensions		Pkg. Qty.
		W	H	
40410	10° Angle	4"	2 ¹ / ₄ "	24
40445	45° Angle	4"	2 ¹ / ₄ "	24

Bin Cups


Model No.	Description	Dimensions			Ctn. Qty.
		L	W	H	
30101	Small Bin Cup	3 ¹ / ₄ "	2"	3"	48
30102	Large Bin Cup	5"	2 ³ / ₄ "	3"	24

Steel Storage Cabinets



Steel cabinets stack together for high-density storage.

- Store, consolidate, and organize small parts.
- Two cabinets fit side by side on standard 36" wide shelving.
- Drawers are removable and are rust, corrosion, and dent-proof.
- No sharp edges to damage parts.
- Unique rear stop tab on each drawer prevents spills.
- Additional dividers, labels, and replacement drawers can be purchased separately.
- Color: Gray.

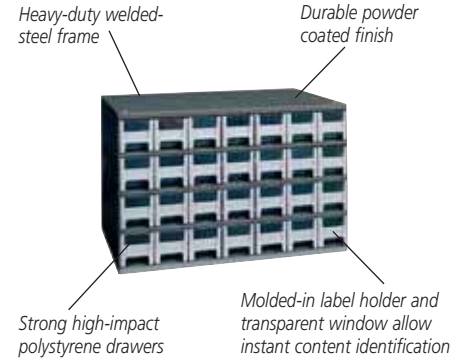

19-Series Heavy-Duty Cabinets

Cabinet frame: 17" wide x 11" deep x 11" high with 10⁹/₁₆" drawer depth. Steel cabinets have five different drawer sizes. Each drawer includes two removable dividers and one label. Seven divider slots per drawer. Optional security cabinet with locking door.



17-Series Light-Duty Cabinets

Cabinet frames: 18" wide x 6" deep x 9¹/₂" high with 5³/₄" drawer depth.

 


Two Drawer Depths

19-Series



17-Series



17-Series have 5³/₄" deep drawers. 19-Series have extra-deep 10⁹/₁₆" drawers for optimum storage flexibility.

Steel Storage Cabinets


Model No.	Description	Drawers Per Cabinet	Drawer Dimensions						Ctn. Qty.	Drawer Model No.	Dividers 25/Pkg. Model No.
			Inches			mm					
			W	H	D	W	H	D			
19-Series Heavy-Duty 17" W x 11" D x 11" H (432 x 279 x 279mm)											
19228	Storage Cabinet*	28	2 ³ / ₁₆	2 ¹ / ₁₆	10 ⁹ / ₁₆	56	52	268	1	20228	40228
19320	Storage Cabinet*	20	3 ³ / ₁₆	2 ¹ / ₁₆	10 ⁹ / ₁₆	81	52	268	1	20320	40320
19416	Storage Cabinet*	16	4	2 ¹ / ₁₆	10 ⁹ / ₁₆	102	54	268	1	20416	40416
19715	Storage Cabinet*	15	3 ³ / ₁₆	3 ¹ / ₁₆	10 ⁹ / ₁₆	81	78	268	1	20715	40715
19909	Storage Cabinet*	9	5 ³ / ₁₆	3 ¹ / ₁₆	10 ⁹ / ₁₆	132	78	268	1	20909	40909
19109	Security Cabinet w/ locking door	9	5 ³ / ₁₆	3 ¹ / ₁₆	10 ⁹ / ₁₆	132	78	268	1	20909	40909
17-Series Light-Duty 18" W x 6" D x 9¹/₂" H (457 x 152 x 241mm)											
17018	Storage Cabinet	18	2 ³ / ₄	2 ¹ / ₂	5 ³ / ₄	70	64	146	1	20902	40901
17136	Storage Cabinet	36	2 ³ / ₄	1 ¹ / ₄	5 ³ / ₄	70	32	146	1	20502	40501

*Available with a locking door when ordered in quantities of 50 or more.

Storage Cabinet Hanging Systems

Mobile Steel Cabinet Rack*

Double-sided, mobile rail rack holds 12 of the 19-Series cabinets with as many as 336 drawers. Supports up to 500 lbs.

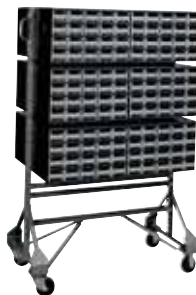

Order These Components and Quantities

- 30012 Double-Sided Rail Rack – Qty: 1
- 30424 Mobile Kit – Qty: 1
- 19-Series Cabinets – Mix or Match – Qty: 12
- 98400 Suspension Straps (Set of 2 straps) – Qty: 12 Sets

*Assembly required



Storage-Go-Round*

Access 20 cabinets and as many as 560 drawers in less than three square feet of floor space. Holds up to 1,000 lbs. of parts.

Accommodates Akro-Mils 19-Series Steel Cabinets (sold separately).

Order These Components and Quantities

- 98325 Storage-Go-Round with turntable base
- Assembled Storage-Go-Round stands 31" L x 31" W x 60" H (787 x 787 x 1524 mm)

19-Series Cabinets – Mix or Match – Qty: 20

*Assembly required

Storage Cabinets



- Strong plastic cabinets organize and protect components.
- A variety of drawer configurations provide versatile storage solutions.
- Cabinets stack securely and are wall mountable.
- Dividers won't get lost - molded into cabinet back.



I.D. Size: 4³/₈W x 2H x 5¹/₄L



I.D. Size: 2¹/₈W x 1¹/₂H x 5¹/₄L

Akro-Mils' clarified polypropylene drawers are the best in the industry!

- Unbreakable - no cracked drawers in shipping unlike polystyrene drawers
- Flexible, strong, and see-through
- Chemical-resistant



10116



10126



10144



10164


Storage Cabinets

Model No.	Description	L	Inches			L	mm		Ctn. Qty.
			W	H		W	H		
10116	16-Drawer Cabinet	10 ⁹ / ₁₆	8 ¹ / ₂	6 ³ / ₈	268	216	162	1	
10126	26-Drawer Cabinet	20	10 ¹ / ₂	6 ³ / ₈	508	263	162	1	
10124	24-Drawer Cabinet	20	15 ¹³ / ₁₆	6 ³ / ₈	508	402	162	1	
10144	44-Drawer Cabinet	20	15 ¹³ / ₁₆	6 ³ / ₈	508	402	162	1	
10164	64-Drawer Cabinet	20	15 ¹³ / ₁₆	6 ³ / ₈	508	402	162	1	

16-Drawer Cabinet has 8 dividers. All other cabinets have 8 small and 4 large dividers.

Tote Caddy

- Hand-held tool and supply caddy.
- Deep compartments hold loose parts, cleaning supplies, or tools for easy transport.
- Molded of heavy-duty, industrial-grade polypropylene for lasting durability.
- Color: Blue.

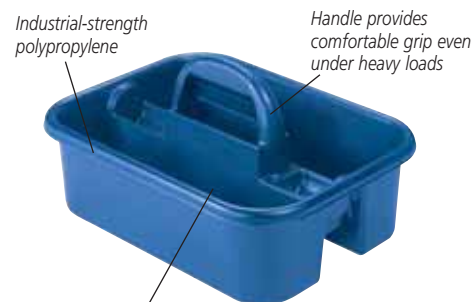

8" deep compartments are ideal for hardware, automotive items, or cleaning supplies

Tote Caddy

Model No.	Description	Size		Ctn. Qty.
		Inches	mm	
09185	Tote Caddy	13 ³ / ₄ x 18 ¹ / ₄ x 8 ³ / ₄	349 x 464 x 222	6

 
Storage Cases

Small Cases




0 Fixed Dividers
4 Adjustable Dividers

Medium Cases




1 Fixed Divider
4 Adjustable Dividers

 Small & Medium Cases



2 Fixed Dividers
4 Adjustable Dividers

 Large Cases



2 Fixed Dividers
5 Adjustable Dividers

- Grid design in lid keeps items from spilling into other compartments.
- Cases available in 3 sizes with different divider configurations.
- Small and medium cases include 4 front-to-back adjustable dividers.
- Large cases include 5 front-to-back adjustable dividers.



05705
Small Case

05905
Large Case

05805
Medium Case

Storage Cases

Model No.	Description	Inches			mm			Maximum Compartments	Ctn. Qty.
		L	W	H	L	W	H		
05705	Small Case (2 Fixed Dividers)	8 ⁵ / ₈	5 ¹ / ₈	1 ⁵ / ₈	219	130	41	15	12
05709	Small Case (0 Fixed Dividers)	8 ⁵ / ₈	5 ¹ / ₈	1 ⁵ / ₈	219	130	41	5	12
05805	Medium Case (2 Fixed Dividers)	11	7	2 ³ / ₈	279	178	60	15	6
05807	Medium Case (1 Fixed Divider)	11	7	2 ³ / ₈	279	178	60	10	6
05905	Large Case (2 Fixed Dividers)	14 ³ / ₈	9 ¹ / ₂	2 ¹ / ₂	365	241	64	18	6

Portable Organizers

- Unique design keeps parts and equipment from migrating to other compartments when lids are shut.
- Separate lid compartment holds small items.
- The main compartment holds larger, bulky items.
- Dividers included for both levels.
- Molded-in "feet" allow case to stand upright.



Portable Organizers

Model No.	Description	No. of Compartments	Inches			mm			Ctn. Qty.
			L	W	H	L	W	H	
06115	Lid Storage Organizer	11 to 46 compartments	15	11 ⁵ / ₁₆	3 ¹ / ₄	381	287	83	1
06118	Large Lid Storage Organizer	12 to 62 compartments	18 ¹ / ₄	13 ³ / ₈	3 ³ / ₈	464	340	92	1
06217	Flat-Bottom Organizer	9 to 32 compartments	11 ¹⁵ / ₁₆	15	3 ⁷ / ₈	303	381	98	6



Roto-Shelf

- Mobile storage unit can easily be moved to different work areas.
- Roto-Shelf is ideal for assembly components.
- 19⁷/₈" wide unit takes up very little floor space.
- Four shelves rotate on an independent central metal shaft.

Roto-Shelf

Model No.	Inches	mm		Ctn. Qty.	
		D	H		W
02420	19 ⁷ / ₈	37 ¹ / ₂	502	953	1

Shelf depth - 2¹/₈" Shelf diameter - 19⁷/₈" 75 lbs. per shelf
300 lb. total wt. capacity

Tilt & Locks

- Locking storage bins make this unit great in vehicles, mounted behind doors, or anywhere a convenient storage center is needed.
- Three sizes stack and lock together to form a customized storage center.

Tilt & Locks

Model No.	Description	Inches			mm			Ctn. Qty.
		L	W	H	L	W	H	
08146	Small	19 ⁵ / ₈	2 ³ / ₄	5 ¹ / ₄	498	70	133	1
08166	Medium	19 ⁵ / ₈	3 ³ / ₄	6 ⁷ / ₈	498	95	175	1
08186	Large	19 ⁵ / ₈	5 ³ / ₄	8 ³ / ₈	498	146	213	1