




TYPE - CF90IP65



Contact your local
Sales Representative
[Click Here for
Printable Version](#)

				NPT	Threaded	Fittings			
Cat #	US Trade Size	MM	NW	Thread Size	Unit Pack	Part #	Standard Carton	Part #	List Price Per 100 Pcs.
CF-140A	1/4"	10	7	PG-7	1	90195	-	-	\$851.00
CF-516A	5/16"	12	10	PG-9	1	90180	-	-	\$694.00
CF-20	3/8"	16	12	1/2" NPT	25	90211	100	90212	\$694.00
CF-21	1/2"	20	17	1/2" NPT	25	90231	50	90232	\$721.00
CF-22	3/4"	25	23	3/4" NPT	10	90251	30	90252	\$1,091.00
CF-23	1"	32	29	1" NPT	10	90271	20	90272	\$1,537.00
CF-24	1-1/4"	40	36	1-1/4" NPT	5	90291	10	90292	\$2,389.00
CF-25	1-1/2"	50	48	1-1/2" NPT	2	90311	10	90312	\$2,688.00

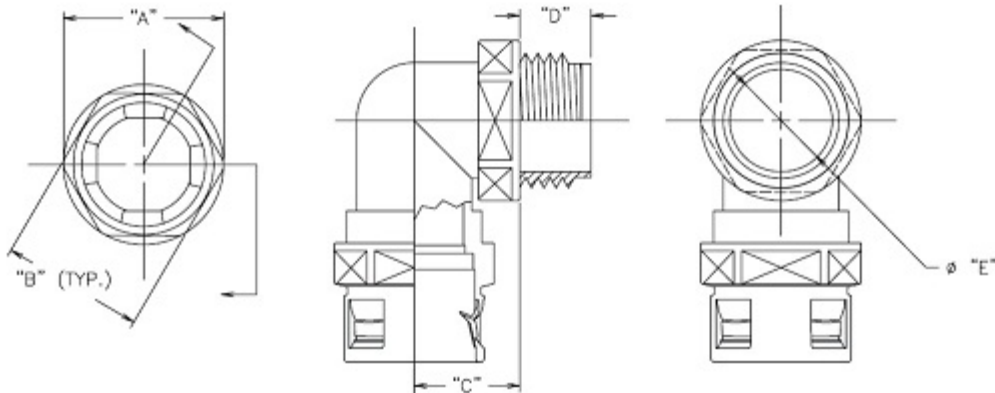

TYPE - CF90IP65

IP 65 is the equivalent to NEMA 4 and can withstand spraying water from entering.

Plastic Used: NYLON [See the Chemical Resistance Guide](#)

High Mech. Strength	Listed For Direct Burial	Halogen Free	Low Fire Hazard	Accepts Standard Liquidtight Fittings	Self Extinguish	EMI/RFI Shielding	Oil Resistance	Acid Resistance

® Electri-Flex Company 1-800-323-6174