




TYPE - CFSStraightIP68



Contact your
local Sales
Representative
[Click Here for
Printable
Version](#)

				NPT	Threaded	Fittings			
Cat #	US Trade Size	MM	NW	Thread Size	Unit Pack	Part #	Standard Carton	Part #	List Price Per 100 Pcs.
CFS-140	1/4"	10	7	PG-7	1	90820	-	-	\$497.00
CFS-516	5/16"	12	10	PG-9	1	90822	-	-	\$507.00
CFS-10	3/8"	16	12	1/2" NPT	25	90831	100	90832	\$494.00
CFS-11	1/2"	20	17	1/2" NPT	25	90841	100	90842	\$514.00
CFS-12	3/4"	25	23	3/4" NPT	25	90851	50	90852	\$624.00
CFS-13	1"	32	29	1" NPT	10	90861	30	90862	\$762.00
CFS-14	1-1/4"	40	36	1-1/4" NPT	5	90871	20	90872	\$1,250.00
CFS-15	1-1/2"	50	48	1-1/2" NPT	2	90881	10	90882	\$1,338.00

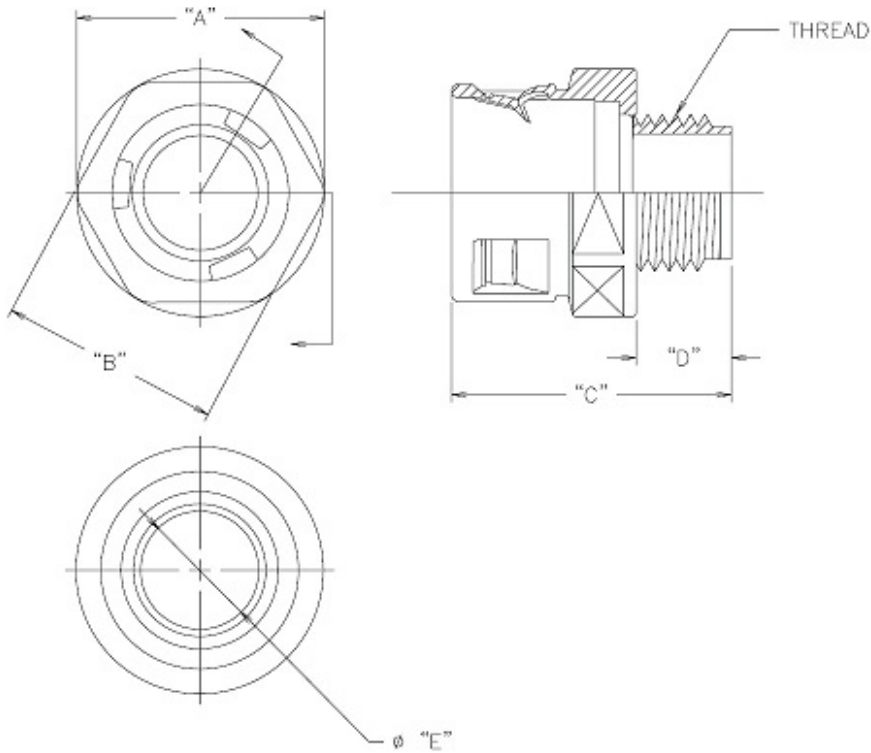

TYPE - CFSStraightIP68

IP 68 is the equivalent to NEMA 6 and can withstand water from entering during submersion

Plastic Used: NYLON [See the Chemical Resistance Guide](#)

High Mech. Strength	Listed For Direct Burial	Halogen Free	Low Fire Hazard	Accepts Standard Liquidtight Fittings	Self Extinguish	EMI/RFI Shielding	Oil Resistance	Acid Resistance