



*Innovations Since 1908*

## PRODUCT FAMILIES

[Pin Headers](#)[and Sockets](#)[Clips and Insulators](#)[Banana Plugs and Jacks](#)[Grabbers, Probes and Spade Terminals](#)[Test Leads and Patch Cords](#)[Coaxial Cable Assemblies](#)[Coaxial Test Leads](#)[Coaxial Break-Outs](#)[DMM Kits](#)

ISO 9001:2000

# Coaxial Break-Outs

## Mini-Micro-Plunger to BNC Male

---



Model# BU-1450-C-\*\*-0

- Material: BNC Male Connector: MIL-C-39012, gold-plated center contact and silver-plated body; Coaxial Cable: shielded RG58C/U, MIL-C-17F, 50 ohm; Plunger: nylon housing, stainless steel spring and beryllium copper contact
- \*\*Length: - 12" (.3m), 24" (.6m), 36" (.9m), 48" (1.2m), 60" (1.5m)
- Rating: Hands free testing at 300 VRMS on center conductor

**CHECK INVENTORY**

## Insulated Alligator Clips to BNC Male With RG58

---



Model# BU-5030-C-\*\*-0

- Material: Alligator Clip: nickel-plated steel with PVC insulator; BNC Male Connector: MIL-C-39012, gold-plated center contact and silver-plated body (RG174/U BNC is a commercial connector with nickel-plated body); Coaxial Cable: shielded RG58C/U, MIL-C-17F, 50 ohm or shielded RG174/U, MIL-C-17D, 50 ohm
- \*\*Length: - 12" (.3m), 24" (.6m), 36" (.9m), 48" (1.2m), 60" (1.5m)
- Rating: Hands free testing at 300 VRMS on center conductor

**CHECK INVENTORY**

#### BNC Male Breakout to Tinned End Wires

---



Model# BU-5100-A-4-0

- Material: BNC Male Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS on center conductor

**CHECK INVENTORY**

#### BNC Male Breakout to Mini-Micro-Grabbers

---



Model# BU-5114-A-4-0

- Material: BNC Male Connector: quality tarnishresistant, plated brass with a gold-plated brass center contact, ABS housing; Mini-Micro-Grabbers (No.208) conductor and abrasion resistant, nylon housing; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 150 VRMS, 5 Amp

**CHECK INVENTORY**

#### **Insulated BNC Male to BNC Female**

---




polyethylene dielectric; Coaxial Cable: RG58, 50 ohm

- \*\*Length: - 12" (.3m), 24" (.6m), 36" (.9m), 48" (1.2m), 60" (1.5m)
- Rating: Hands free testing at 500 VRMS on center conductor

**CHECK INVENTORY**

### BNC Male Breakout to Stackable Single Banana Plugs

---

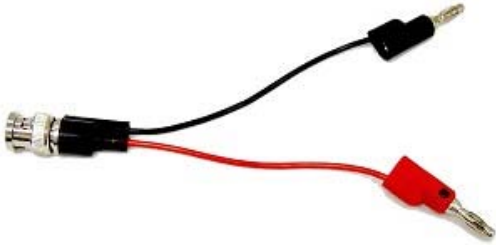

Mode# BU-5120-A-4-0

- Material: BNC Male Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Banana Plug: premium nine-leaf, nickel-plated beryllium copper springs and copper alloy 360 bodies for minimum stacked in multiples, ABS housing; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS, 5 Amp

**CHECK INVENTORY**

### BNC Male Breakout to Insulated Mini-Alligator Clips

---



- Material: BNC Male Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Clip: Mueller No. 30BL with No. 31 insulators; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS, 10 Amp

[CHECK INVENTORY](#)

### BNC Male Breakout to Stackable 0.080" (2.0mm) Pin Plugs

---



Model# BU-5144-A-4-0

- Material: BNC Male Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Pin Tip: nickel-plated brass 0.080" (2.0mm) dia; 0.500" (12.7mm) long; Tip Jack: Accepts 0.080" (2.0mm) dia. pin, nickel-plated, alloy 360 copper body; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS, 5 Amps

[CHECK INVENTORY](#)

### BNC Female Breakout Style to Tinned End Wires

---



Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation

- Rating: Hands free testing at 300 VRMS, 5 Amps

**CHECK INVENTORY**

### BNC Female Breakout to Mini-Micro-Grabbers

---




Model# BU-5214-A-4-0

- Material: BNC Female Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Mini-Micro-Grabbers (No.208): conductor and abrasion resistant, nylon housing; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS, 5 Amps

**CHECK INVENTORY**

### BNC Female Breakout to Stackable Single Banana Plugs

---

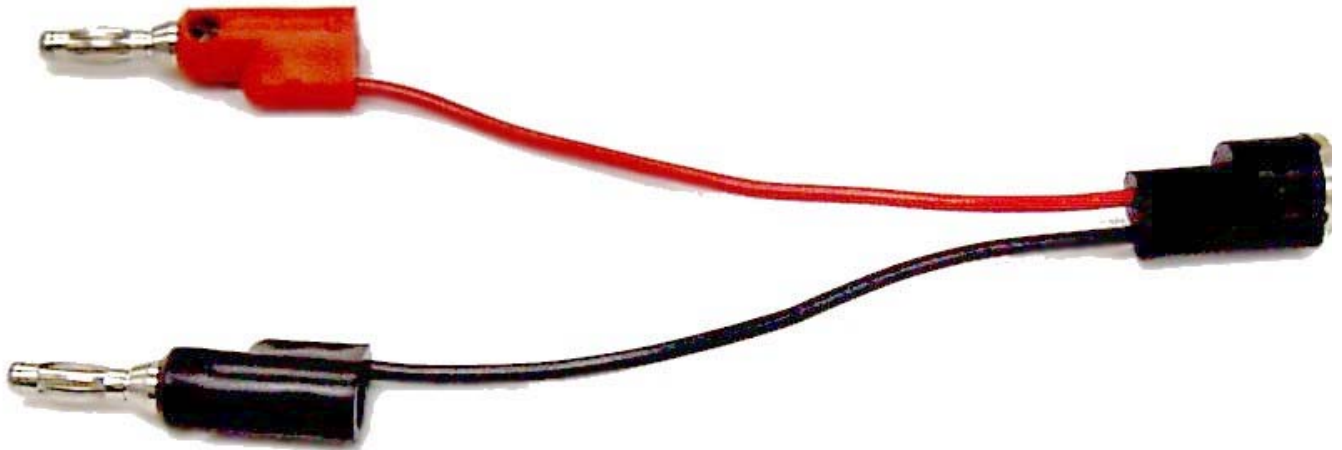

Model# BU-5220-A-4-0

- Material: BNC Female Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Banana Plug: premium nine-leaf, nickel-plated beryllium copper springs and copper alloy 360 bodies for minimum stacked in multiples, ABS housing; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS, 10 Amps

**CHECK INVENTORY**

### BNC Female Breakout to Insulated Mini-Alligator Clips

---



Mode# BU-5231-A-4-0

- Material: BNC Female Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Clip: Mueller No. 30BL with No. 31 insulators; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS, 5 Amps

[CHECK INVENTORY](#)

### BNC Female Breakout to Stackable 0.080" (2.0mm) Pin Plugs

---



Mode# BU-5244-A-4-0

- Material: BNC Female Connector: quality tarnish-resistant, plated brass with a gold-plated brass center contact, ABS housing; Pin Tip: nickel-plated brass 0.080" (2.0mm) dia; 0.500" (12.7mm) long; Tip Jack: accepts 0.080" (2.0mm) dia. pin, nickel-plated, alloy 360 copper body; Hook-up Wire: #20 AWG (41/36) tinned copper with 105°C PVC insulation
- Rating: Hands free testing at 300 VRMS, 5 Amps

[CHECK INVENTORY](#)

### Insulated Alligator Clips to BNC Male With RG174

---



Model# BU-5330-F-\*\*-0

- Material: Alligator Clip: nickel-plated steel with PVC insulator; BNC Male Connector: MIL-C-39012, gold-plated center contact and silver-plated body (RG174/U BNC is a commercial connector with nickel-plated body); Coaxial Cable: shielded RG58C/U, MIL-C-17F, 50 ohm or shielded RG174/U, MIL-C-17D, 50 ohm
- \*\*Length: -12" (.3m), 24" (.6m), 36" (.9m), 48" (1.2m), 60" (1.5m)
- Rating: Hands free testing at 300 VRMS on center conductor

**CHECK INVENTORY**

**TOOL SEARCH TOOLS**  
 MUELLER OR DISTY STK SEARCH /  
 PRODUCT DATA

PART #  **SEARCH**

**TOOL**  
 CROSS COMPETITOR PART #

Choose a Brand

PART #  **SEARCH**

**TOOL**  
 MeterMate® DMM ACCESSORY  
 SELECTOR

Select Meter Make

Select a Make First

**TOOL**  
 BUILD A PCB HEADER OR  
 SOCKET

OVER 10,000 IN STOCK! **GO**

© 2008 Mueller Electric Company, Inc.

[Home](#) | [Products](#) | [Check Order Status](#) | [About Us](#) | [Contact Us](#) | [Request a Catalog](#) | [Site Map](#)