


Subrack

Ripac ECO 3 U, 6 U, sheet steel

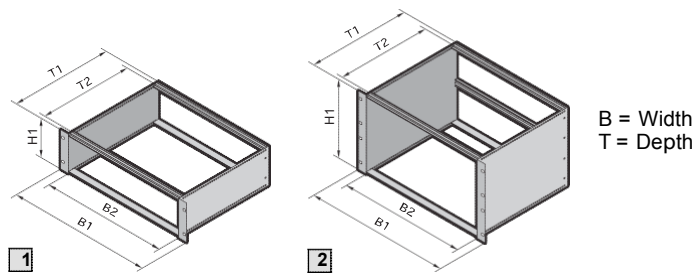

Material/surface finish:

Side panels:
1.5 mm sheet steel, zinc-plated, passivated
Flanges/horizontal rails:
Extruded aluminium section, clear-chromated

Supply includes:

Side panels, flanges, horizontal rails, threaded inserts

Detailed parts lists,

see page 1155.

Tests:


Vibration and shock-tested to:
IEC 600-68-2-6 test Fc
IEC 600-68-2-27 test Ea

Standards:

Ripac subracks are based on the system dimensions of IEC 60 297-3/-5.


Detailed drawing,

see page 1155.



Buy Now
▶

Contact us for more information, to get a **Quote** on this product or for answers to technical questions from our **Technical Support Team**.

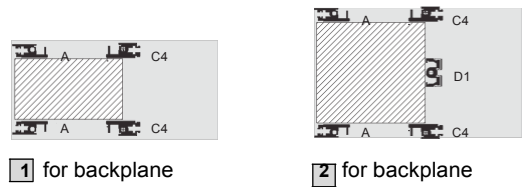

					Model No. RP		Page
					1	2	
U (H1)					3	6	
B1 mm	B2 HP	Side panel (T1) mm	T2 mm	Max. PCB depth mm	For backplane	For backplane	
482.6 (19□)	84	175	150	160	3688.114	3688.116	
		235	210	220	3688.115	3688.117	

Accessories		
Trim section rear, 3 U	3688.112	497
Trim section rear, 6 U	3688.113	497
Z (connector) rail	3684.602	504
Insulating strips	3684.611	505
Cover, perforated, for 175 mm depth	3688.105	518
Cover, perforated, for 210 mm depth	3688.106	518
Cover, solid, for 175 mm depth	3688.107	518
Cover, solid, for 210 mm depth	3688.108	518
Mounting clips for covers	3688.109	518
Assembly screw for mounting clips	9902.188	518
Guide rails		509
Horizontal rails		498