


PRODUCT DATA

Patch Surface Thermocouple, Type K

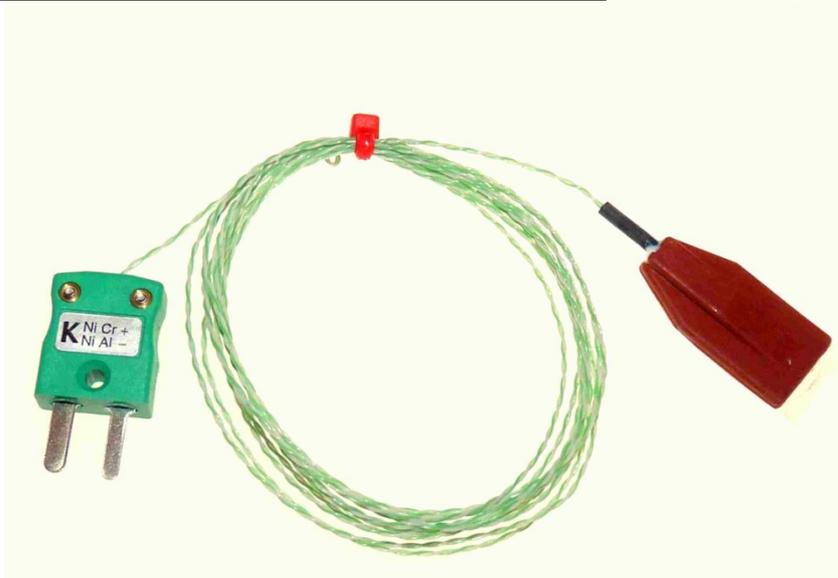

- Type K thermocouple in a moulded silicone rubber patch
- 2 metres PFA Teflon® insulated twin twist 1/0.2mm cable with miniature connector
- Temperature rating -50°C to +150°C
- Self-adhesive aluminium foil backing
- Resistant to many oils & chemicals

Specifications

Sensor type:	Type K thermocouple to IEC 584
Construction:	Thermo-element located within a flexible silicone rubber patch
Patch dimensions:	Length 30mm x Width 5mm x Height 4mm
Lead type:	2 metres 1/0.2mm PFA Teflon® insulated twin twist fitted with miniature plug
Temperature range:	-50°C to + 150°C

Code:

Labfacility code	Stock code	Farnell code
SRS-K-2-C80-MP	XF-580-FAR	NEW