


Item no.: 280-588
Product description: SENSOR TERMINAL BLOCK FOR FUSE PLUGS FOR PNP INDICATORS with end plate for 3- and 4-conductor sensors

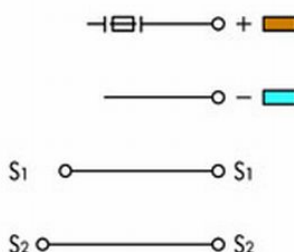

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

Current intensity EN	6.3 A
Measured voltage EN	250 V
Product group	1 (Rail Mounted Terminal Blocks)
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [AWG]	28 - 12 AWG
Connection method	CAGE CLAMP® CONNECTION
Measured voltage EN	125 V
Current intensity EN	5 A
Weight	17.001 g
Color	gray
Wiring type	Angled Type
No. of connection Points	6
No. of potentials	5
Height	63.5 mm
Height	2.5 in
Width	5 mm
Width	0.197 in
Depth	90.5 mm
Depth	3.56 in

Strip length from	8 mm
Strip length to	9 mm
Strip length	0.33 in
Safety information 1	The electrical data is defined by the fuse and empty plug respectively.
Mounting	TS 35



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm²]
280-588	BV	07436/C0			0,08-2,5
280-588	CSA	154112-1536071	300	15	28-12
280-588	UR	E45172	300	6,3	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected