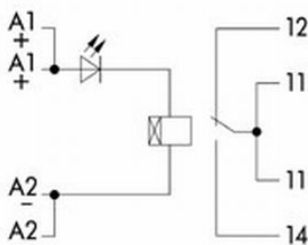

Item no.:	286-602
Product description:	TIME RELAY MODULE WITH STRAIN RELIEF DEVICE FOR ERNI MATING RELAY WITH 1 CHANGEOVER CONTACT (1u) SPECIFIED TIME ACC. TO VDE 0435/ PART 201/5.83



Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Product group	6 (Electronics)
Time range	1 - 10 s
Nominal input voltage (Un) (DC)	DC 24 V
Contact material	AgCdO, with gold flash
max. switching voltage	DC 250V / AC 380V
max. make current	1 s 15 A
max. break current	8 A
max. continuous current	6 A
max. switching power (resistive) VA	2000 VA
max. switching power (resistive) W	150 W
Operating power	300 mW
Drop-out time (typ)	15 ms
Bounce time (typ)	1 ms
Reset time	100 ms
Dielectric strength contact-coil (AC, 1 min)	3 kV
Dielectric strength open contact	1.2 kV
Nominal voltage acc. to VDE 0110/1.89	250 V / 4 kV / 3
Dielectric strength contact-contact (kV)	2 kV

Mechanical life

Mechanical life at max. resistive load AC

Ambient operating temperature

Standards

5×10^7 switching operations

1×10^5 switching operations

-25 °C ... +40 °C

DIN VDE 0160 und IEC 60255; DIN VDE 0435
(entspr. Teile)



Current consumption at UN (20 °C)	12.5 mA
Weight	38.5 g
Color	gray
Height	82.5 mm
Height	3.25 in
Width	20 mm
Width	0.787 in
Depth	50 mm
Depth	1.97 in
Customs Tariff No.	85369010
Country of Origin	Deutschland

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected