


Item no.: 287-824
Product description: SWITCHING RELAY MODULE RELAY IN SOCKET EACH 1
CHANGEOVER CONTACT (1 u) WITH 8 RELAYS WITH
UNIVERSAL MOUNTING CARRIER

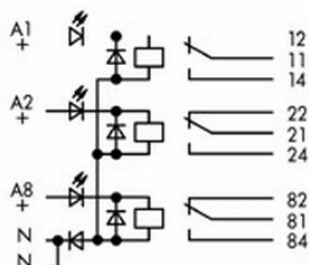

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Product group	6 (Electronics)
Contact material	AgNi 0.15 + HV
Coil voltage DC	24 V
max. switching voltage	AC 250 V / DC 300 V
max. make current	20 A
max. break current	8 A
max. continuous current	6 A
max. switching power (resistive) VA	1500 VA
max. switching power (resistive) W	192 W
Pull-in power	261 mW
Operating power	533 mW
Pull-in time (typ)	9 ms
Drop-out time (typ)	3 ms
Bounce time (typ)	2 ms
Dielectric strength contact / coil (kV)	4 kV
Nominal voltage acc. to VDE 0110/1.89	Safety data
Mechanical life	20 x 10 ⁶ switching operations
Mechanical life at max. resistive load AC	2 x 10 ⁵ switching operations

Ambient operating temperature	-25 °C ... +40 °C
Current consumption at UN (20 °C)	21.8 mA
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [AWG]	28 - 12 AWG



Connection method	CAGE CLAMP® CONNECTION
Weight	277.3 g
Color	gray
Height	58 mm
Height	2.283 in
Width	85 mm
Width	3.346 in
Depth	127 mm
Depth	5 in
Strip length from	5 mm
Strip length to	6 mm
Strip length	0.22 in
Mounting	TS 35

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected