


QMB Series



- QMB-01 S/L
- QMB-06 S/L
- QMB-12 S/L
- QMB-12S/V3.3
- QMB-12S/V3.3 N/L
- Compact Size
- Through Hole Design
- Top Sound Hole
- Dip Solderable and Washable

Specifications:

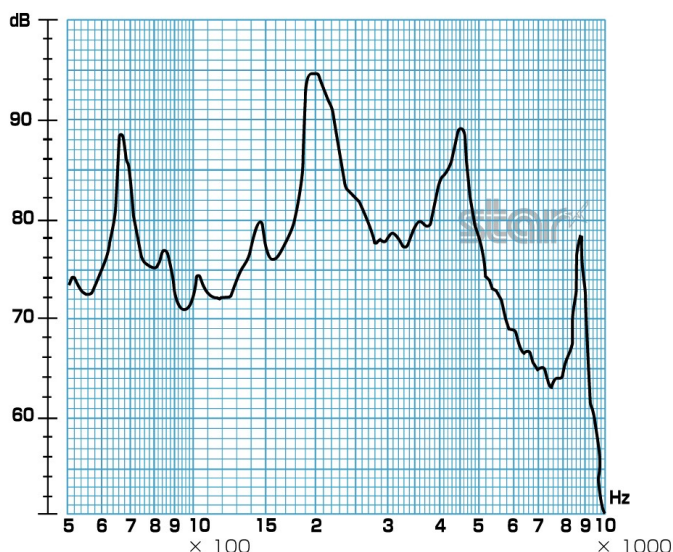

	QMB-01 S/L	QMB-06 S/L	QMB-12 S/L QMB-12S/V3.3 (N/L)
SPL	Min. 80 dB Typ. 89 dB	Min. 85 dB Typ. 94 dB	Min. 85 dB Typ. 97 dB
Rated Voltage	1.5 V _{p-p}	6 V _{p-p}	12 V _{p-p}
Rated Frequency	2,048 Hz		
Mean Current Consumption	Max 15 mA	Max 40 mA	
Operation Temp.	-40°C to +85°C		-40°C to +100°C
External Size	φ16mm x 14mm		
Mass	5g	7g	

Note: QMB-12S/V3.3 and QMB-12S/V3.3-N/L have two 3.3mm pins

