


Magnetic Sounder

TMX-12F N/L



- High Sound Pressure Level
- Low Frequency
- Through Hole Design

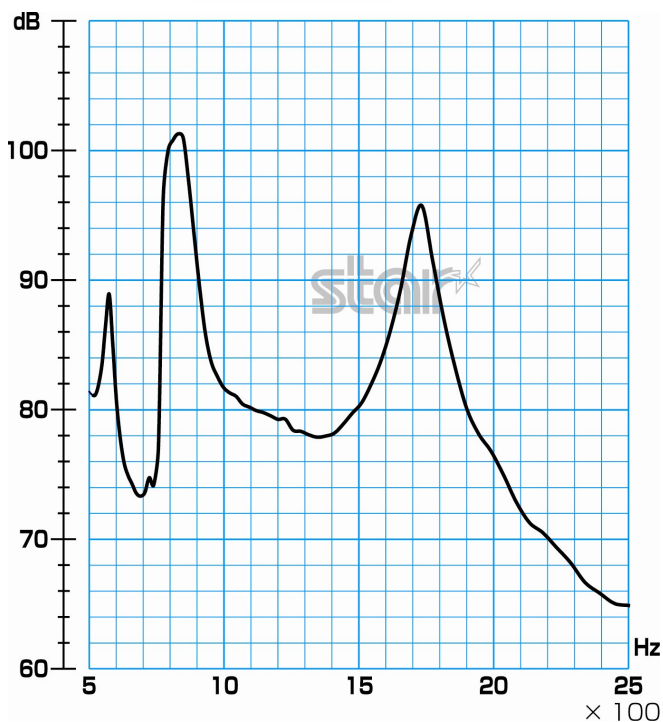

Specifications:

SPL	Min. 95 dB Typ. 99 dB
Rated Voltage	12 V _{p-p}
Rated Frequency	850 Hz
Current Consumption	Mean: max 40mA Peak: max 120 mA
Operation Temp.	-40°C to +85°C
External Size	φ25mm x 18mm
Mass	9 g

