

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0352001000](#)
Status: **Active - Custom**
Description: 3.00mm (.118") Pitch 1.00mm (.039") Diameter Wire-to-Board Receptacle Housing - Dual Row, 10 Circuits

Documents:

[3D Model](#) [Product Specification PS-35354-003 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Housings
Series	35200
Application	Power
Product Name	N/A


Physical

Circuits (maximum)	10
Color - Resin	Natural
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm (.118")
Stackable	No
Temperature Range - Operating	-40°C to +120°C

Material Info

Reference - Drawing Numbers

Product Specification	PS-35354-003
Sales Drawing	SD-35200-1000

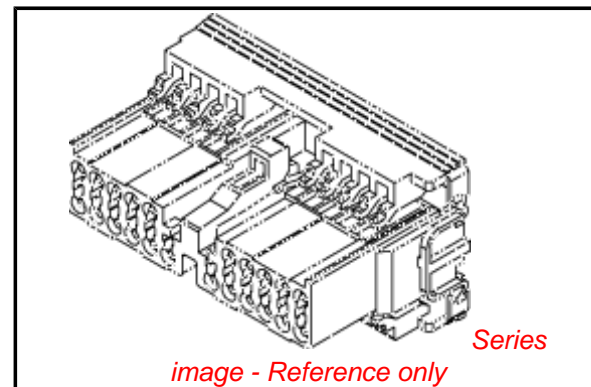

EU RoHS

ELV and RoHS Compliant
REACH SVHC
 Not Reviewed
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[35200Series](#)

Mates With
[35356|35009|35358](#)

Use With
[35403](#)