

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5006782070](#)
Status: **Obsolete**
Description: 0.50mm (.020") Pitch Wire-to-Board Micro Discrete Receptacle, 20 Circuits

Documents:
[Drawing \(PDF\)](#)

General

Product Family	PCB Receptacles
Series	500678
Application	Signal, Wire-to-Board
Product Name	MICRO DISCRETE


Physical

Circuits (Loaded)	20
Color - Resin	Natural
Durability (mating cycles max)	20
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Metal	Brass, Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	High Temperature Thermoplastic
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm (.020")
Plating min - Mating	0.203µm (8µ")
Plating min - Termination	0.051µm (2µ")
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-20°C to +60°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	0.4A
Voltage - Maximum	30V

Material Info

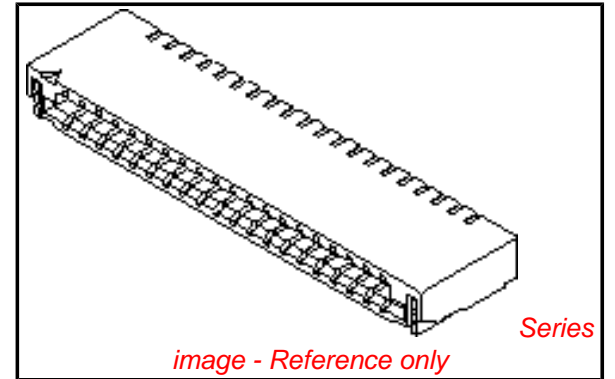

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC
Not Reviewed

Low-Halogen Status
Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[500678Series](#)

Mates With

[59205-9401](#)