

## Products

**A1 series | Single-pole switch 10A quick connection 4.8 black body**



sample image

**PRODUCT CODE: A11131100000**

**Wiring diagrams**



**Terminal type**



**accessories**

**Body colour**



**Actuator colour**



**Marking**



**Rating**

**Approvals**

**10 (4) A / 250 VAC**

ENEC

**6 (6) A / 250 VAC**

UL

**6 (4) A / 250 VAC**

CSA

**- 5E4**

**T125 °C**

**10 A / 125 VAC**

CE

**1/3 HP - 125 VAC**

CB

**10 A / 250 VAC**




CB

**1/2 HP - 250VAC**



RoHS

**T105 °C**


**Dimensions (mm)**

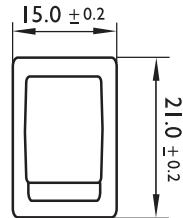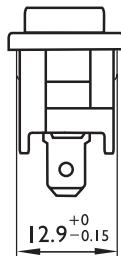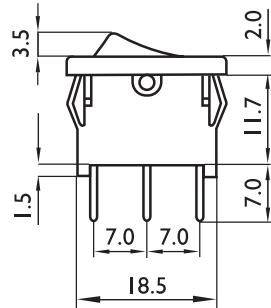

**Cut out (mm)**

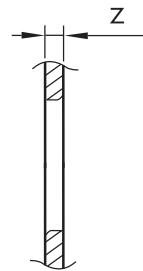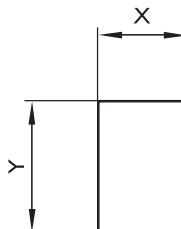

**Termination**

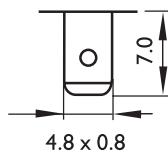

Z	Y	X
0.7-1.25	19.0 $\pm$ 0.1	13.0 $\pm$ 0.1
1.25-2.0	19.3 $\pm$ 0.2	13.0 $\pm$ 0.1
2.0-3.0	19.6 $\pm$ 0.2	13.0 $\pm$ 0.1