

Products

A4 series | Double-pole two-way switch 10A quick connection 4.8 black body



sample image

PRODUCT CODE: A41L31100000

Wiring diagrams



Terminal type



accessories

Body colour



Actuator colour



Marking



Rating




10 (4) A / 250 VAC
6 (4) A / 250 VAC - 5E4
T125/55 °C

10 A / 125 VAC
1/3 HP - 125 VAC
10 A / 250 VAC
1/2 HP - 250VAC
T105 °C



Approvals




Dimensions (mm)

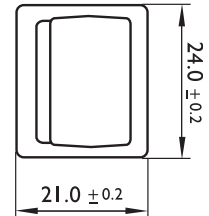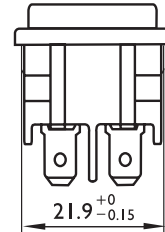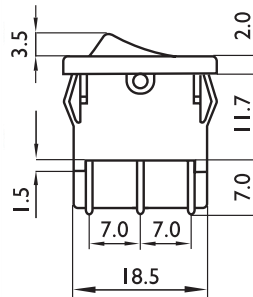

Cut out (mm)

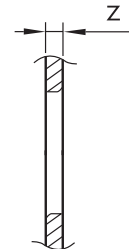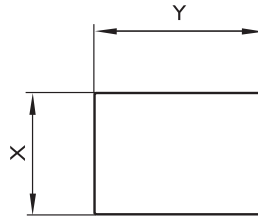

Termination

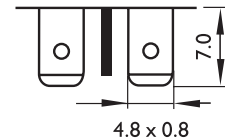

Z	Y	X
0.7-1.25	22.0±0.1	13.0±0.1
1.25-2.0	22.0±0.1	13.0±0.1
2.0-3.0	22.0±0.1	13.0±0.1