

**H0,5/10****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-2083

www.weidmueller.com

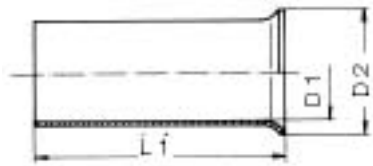

- For conductors from 0.25 to 6,0 mm<sup>2</sup> (AWG 24 - 10)  
tin-plated copper  
dimensional tolerances to DIN 46228 part 1
- supplied loose in polybag

**General ordering data**

Order No.	<a href="#">9004050000</a>
Type	H0,5/10
Version	Wire end ferrule, 0.5 mm <sup>2</sup>
GTIN (EAN)	4008190153052

**H0,5/10****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-2083

www.weidmueller.com

**Technical data****Dimensions**

Length	10 mm
--------	-------

**Product data**

Conductor cross-section	0.5 mm <sup>2</sup>	Contact surface diameter (D1)	1 mm
Collar diameter (D2)	2.1 mm		

**Classifications**

ETIM 2.0	EC000005	ETIM 3.0	EC000005
UNSPSC	31-16-31-02	eClass 4.1	27-06-07-01
eClass 5.1	27-40-02-01	eClass 6.0	27-40-02-01
eClass 7.0	27-40-02-01		

**Product information**

Description of article	Wire end ferrule without plastic collar
------------------------	---