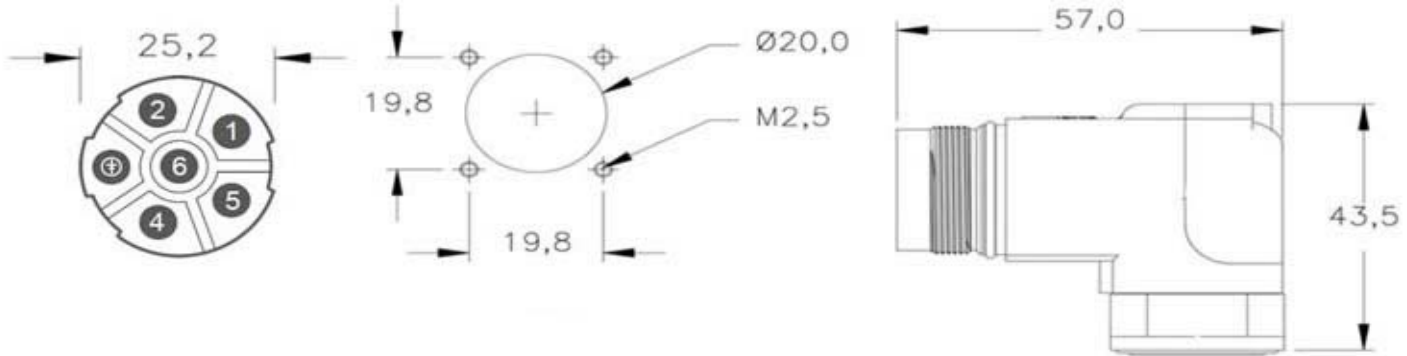


CONFIGURATION	PART NUMBER	CONTACT TYPE
ROTATABLE 90 DEGREE RECEPTACLE, 6 POSITION	MB1RJN0600	PIN
DIMENSIONS		
		
TECHNICAL DATA		
TEMPERATURE RANGE:	-20C to +130C	
PROTECTION:	IP 67 (PLUGGED CONDITION)	
DEGREE OF PROTECTION:	3	
OVER VOLTAGE CATEGORY:	III	
HOUSING BODY:	ZINC DIE-CAST	
COUPLING NUT:	BRASS, NICKEL-PLATED	
INSULATION INSERTS:	PA66 / PBT, UL 94 / VO	
CONTACTS:	BRASS, GOLD-PLATED	
SEALS:	DUPONT VITON	
MAX CURRENT:	28A	
CONTACT SIZE:	6 x 2.0mm	
MAXIMUM VOLTAGE:	630AC/DC	
CONTACT RESISTANCE:	<3	
TEST VOLTAGE: (BETWEEN CONTACTS)	6000V	
MAXIMUM MATING CYCLES:	>50	
NOTES		