



**Quick Reference**

Search by part #

Check distributor part inventory

---

**Products**

Browse Products

-By Device -

-By Product Line-

-Attachment Methods

-Interface Materials-

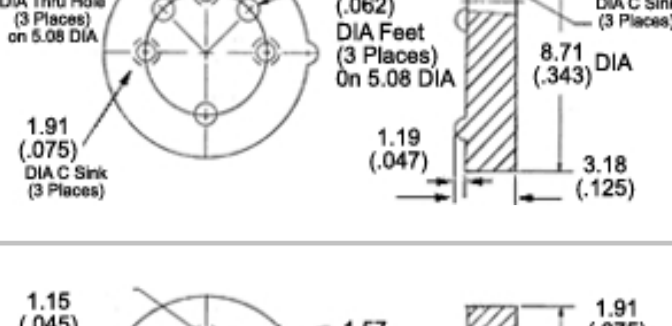
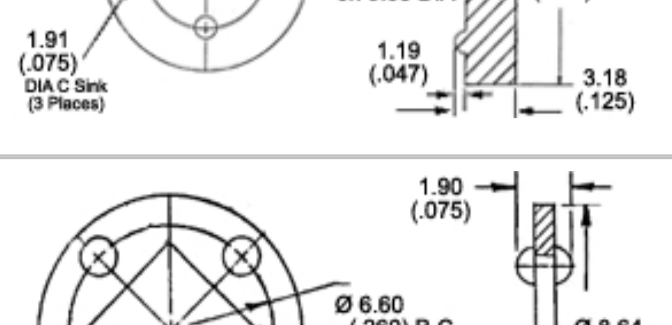
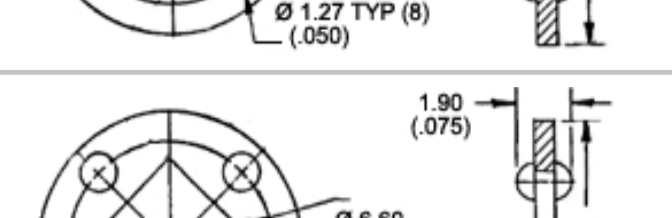
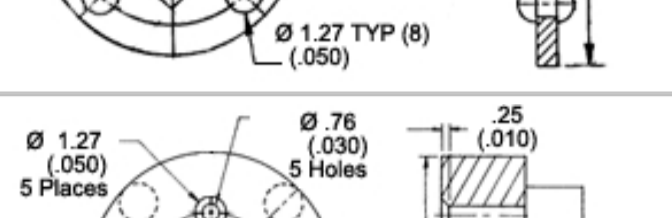


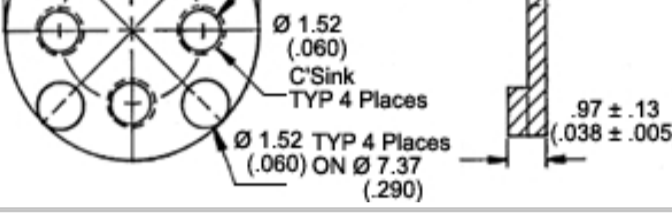
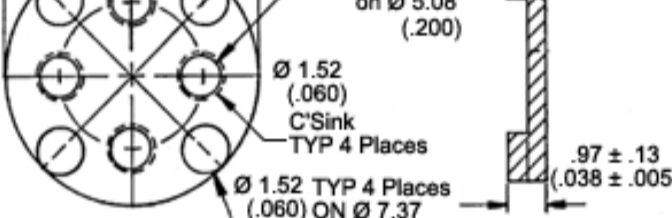

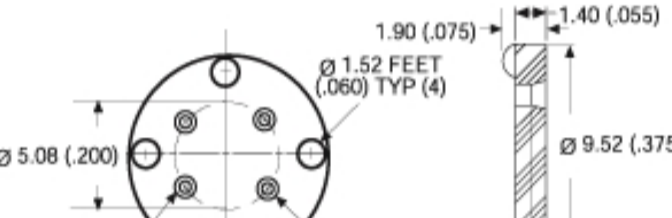
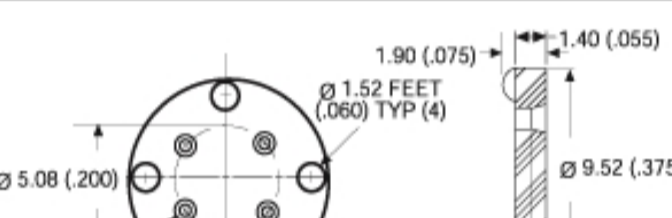
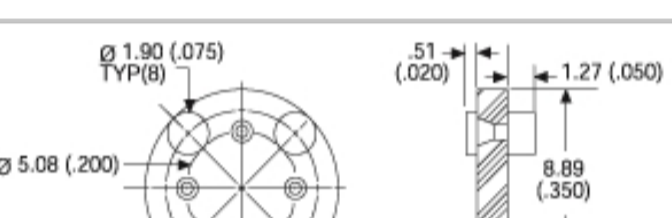
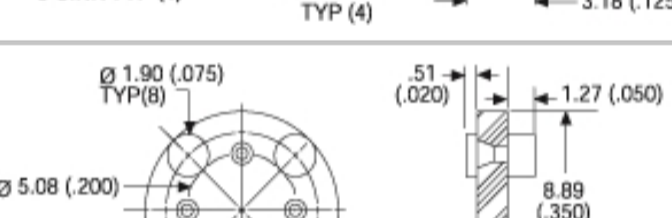
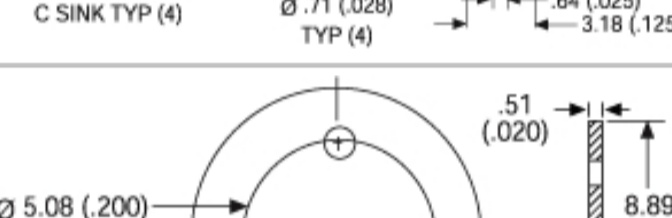
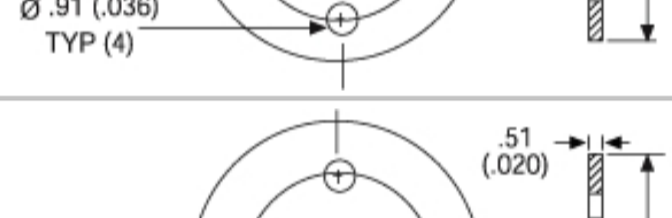

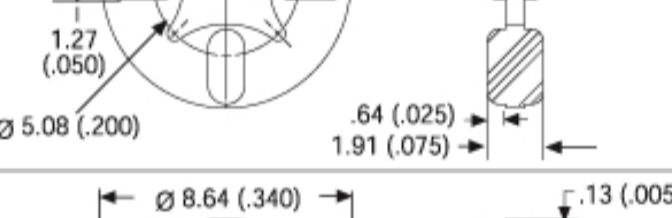
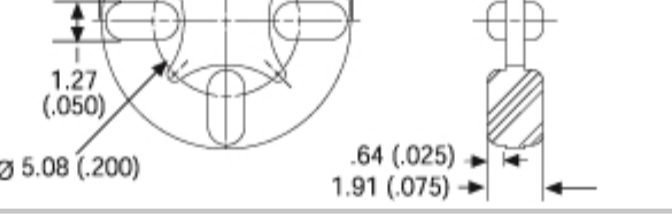

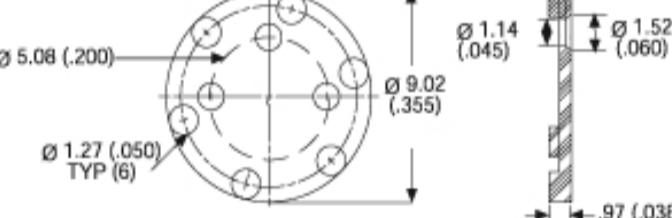



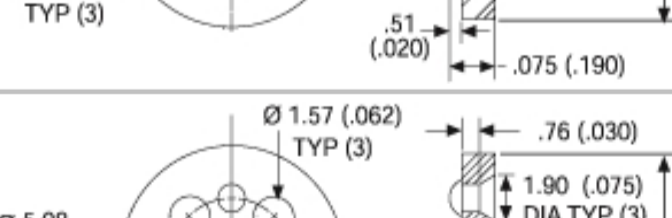
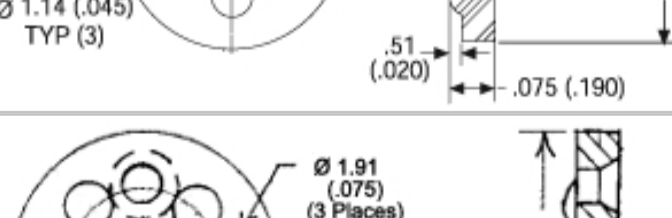
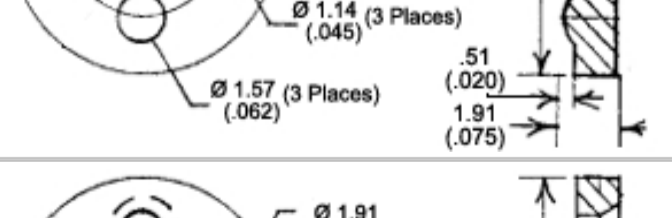
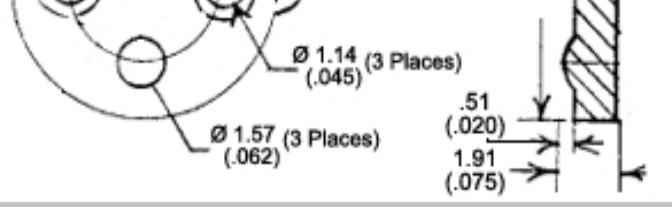
-Accessories -

**Useful Links**

- [MSDS Safety Sheets](#)
- [How to Order?](#)
- [Find Sales Rep](#)
- [Find Distributor](#)
- [Sample Request](#)
- [Quote Request](#)
- [Catalog Request](#)
- [Building a Part #](#)
- [Part # Cross Ref](#)

**Accessories**  
**Standard Mounting Pads**

The following Mounting Pads are for use with TØ

<p><b>7717-167DAPG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 3.18 (0.125)</p>	
<p><b>7717-167NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 3.18 (0.125)</p>	
<p><b>7717-161DAPG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(DAP)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.64 (0.340)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-161NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.64 (0.340)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-159NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 5</p> <p>Outside Diameter mm (in): 9.53 (0.375)</p> <p>Thickness: 5.59 (0.220)</p>	
<p><b>7717-158TG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(Teflon)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 9.91 (0.390)</p> <p>Thickness: 0.25 (0.010)</p>	
<p><b>7717-131DAPG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(DAP)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.97 (0.038)</p>	
<p><b>7717-131NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.97 (0.038)</p>	
<p><b>7717-114NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 9.02 (0.355)</p> <p>Thickness: 1.17 (0.046)</p>	
<p><b>7717-4DAPG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(DAP)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 9.53 (0.375)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-4NG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(nylon)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 9.53 (0.375)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-5DAPG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(DAP)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 3.18 (0.125)</p>	
<p><b>7717-5NG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(nylon)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 3.18 (0.125)</p>	
<p><b>7717-15DAPG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(DAP)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.51 (0.020)</p>	
<p><b>7717-15NG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(nylon)</p> <p>Leads: 4</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.51 (0.020)</p>	
<p><b>7717-3DAPG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(DAP)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-3NG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(nylon)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-79DAPG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 9.02 (0.355)</p> <p>Thickness: 0.97 (0.038)</p>	
<p><b>7717-79NG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 9.02 (0.355)</p> <p>Thickness: 0.97 (0.038)</p>	
<p><b>7717-178DAPG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.53 (0.021)</p>	
<p><b>7717-178NG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.53 (0.021)</p>	
<p><b>7717-86DAPG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-86NG</b> <span style="color: green;">RoHS Compliant</span> <span style="color: red;">Product Change Notice</span></p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-22NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-22DAPG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p><b>7717-238NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 10.16 (0.400)</p> <p>Thickness: 4.06 (0.160)</p>	
<p><b>7717-300NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: Universal</p> <p>Outside Diameter mm (in): 11.18 (0.440)</p> <p>Thickness: 9.65 (0.380)</p>	
<p><b>7717-94NG</b> <span style="color: green;">RoHS Compliant</span></p> <p>(nylon)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.89 (0.350)</p> <p>Thickness: 0.97 (0.038)</p>	