

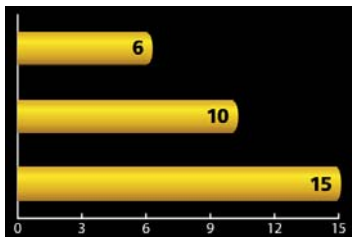
Hi-Speed USB 2.0 Cable A male – A female GX621-XX



This GoldX® PlusSeries® 24 Karat Hi-Speed USB 2.0 cable is used to extend the distance between your USB port and your USB Peripheral. JDI's GoldX® PlusSeries® USB extension cables include a foil and a braid shield for a higher level of protection from electronic interference. 50 Microns of Gold on the connectors ensures the best level of conductivity between the cable and your USB peripherals.

Features:

- Gold connectors
- Premium Quality
- Flexible Cable
- Ergonomic molding for easy connections
- Industry standard color coded for easy installation
- Foil and Braid Shielding to reduce EMI/RFI interference
- Designed for Low, Full and Hi-Speed USB transmissions for optimal performance

HI-SPEED 2.0
TESTED



Connector A		Connector B	
Type	Example Device	Type	Example Device
USB Type A Computer 4 Pin Male		USB Type A Computer 4 Pin Female	

© Copyright 2007 Jo-Dan International, Inc. all rights reserved. Plus Series®, PowerCore®, QuickConnect®, Share Plus®, and GoldX® Products are registered trademarks of Jo-Dan International, Inc. All other trademarks and registered trademarks are the property of their respective owners. Designed in USA. Made in China. One or more of the following patents may apply: D494,935, D494,934, D494,932, D493,453, 6,755,676, D490,702, 6,736,658, 6,726,509, 6,716,047, D485,752, D484,044, D481,629, D481,628, 6,607,408, D478,001, D478,000, D468,635, 6,479,607, D465,223,6,454,584, D462,612, D452,427, D452,426, D451,888, D451,480, D450,303, D448,736, D444,772, D443,862, D443,593, D442,919, D442,556, D442,555, 5,788,521, 5,658,158, 5,334,033, 5,292,257. D503,882; 6,843,684; 6,854,989; 6,872,086; D506,386; 6,905,374; D509,797; 6,991,483; D513,976; 7,004,787; 7,028,114; D519,925; D522,507; 7,258,572. Other patents pending.