

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [35825-0211](#)
Status: **Active**
Description: 5.00mm Pitch Automotive Horn Female Housing, Vertical, 2 Circuits for 2.28mm Tab

Documents:

Drawing (PDF)	Packaging Specification PK-35825-002 (PDF)
Packaging Specification PK-35825-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Housings
Series	35825
Application	Power
Product Name	N/A

Physical

Circuits (maximum)	2
Color - Resin	Black, Yellow
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.00mm
Stackable	No
Temperature Range - Operating	-40°C to +120°C

Material Info

UPC	800755998764
-----	--------------

Reference - Drawing Numbers

Packaging Specification	PK-35825-001, PK-35825-002
Sales Drawing	SD-35825-0211

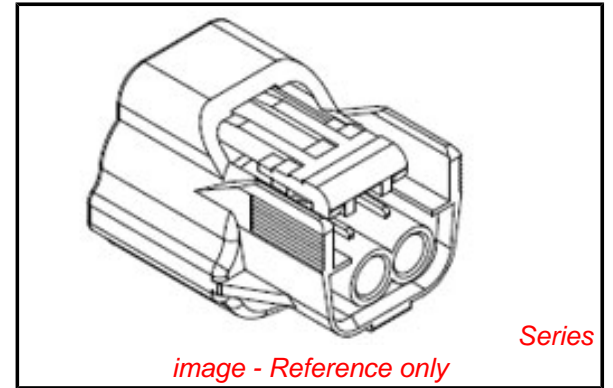


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[35825Series](#)

Mates With

Automotive Filtered Horn Header [68131](#)

Use With

Terminal [35407](#) , [35903](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION