


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [51067-0800](#)  
**Status:** **Active**  
**Description:** 3.50mm Pitch Wire-to-Wire and Wire-to-Board Housing, Positive Lock, 8 Circuits

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-51067-016 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Product Specification PS-51067-017 (PDF)</a>
<a href="#">Product Specification PS-51067-002 (PDF)</a>	<a href="#">Product Specification PS-51067-018 (PDF)</a>
<a href="#">Product Specification PS-51067-003 (PDF)</a>	<a href="#">Product Specification PS-51067-019 (PDF)</a>
<a href="#">Product Specification PS-51067-004 (PDF)</a>	<a href="#">Product Specification PS-51067-020 (PDF)</a>
<a href="#">Product Specification PS-51067-005 (PDF)</a>	<a href="#">Product Specification PS-51067-021 (PDF)</a>
<a href="#">Product Specification PS-51067-006 (PDF)</a>	<a href="#">Product Specification PS-51067-022 (PDF)</a>
<a href="#">Product Specification PS-51067-007 (PDF)</a>	<a href="#">Product Specification PS-51067-023 (PDF)</a>
<a href="#">Product Specification PS-51067-008 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

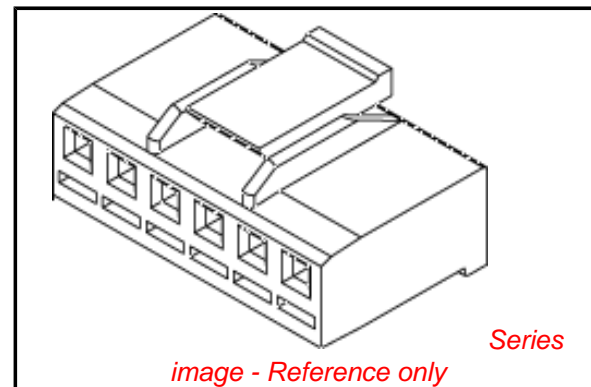

**Agency Certification**

CSA	LR19980
TUV	R72081037
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">51067</a>
Application	Power, Wire-to-Board, Wire-to-Wire
Product Name	N/A

**Physical**

Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.50mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

**Material Info**

UPC	800753574427
-----	--------------

**Reference - Drawing Numbers**

Product Specification	PS-51067-002, PS-51067-003, PS-51067-004, PS-51067-005, PS-51067-006, PS-51067-007, PS-51067-008, PS-51067-016, PS-51067-017, PS-51067-018, PS-51067-019, PS-51067-020, PS-51067-021, PS-51067-022, PS-51067-023, RPS-51067-001, RPS-51067-002, RPS-51067-003, RPS-51067-006, RPS-51067-007, RPS-51067-008, RPS-51067-020, RPS-51067-021, RPS-51067-022, RPS-51067-023, RPS-51067-024, RPS-51067-025, RPS-51067-027, RPS-51067-028, RPS-51067-029, RPS-51067-030, RPS-51067-031, RPS-51067-033, RPS-51067-034, RPS-51067-035, RPS-51067-036,
-----------------------	--

**EU RoHS**  
**ELV and RoHS**  
**Compliant**  
**REACH SVHC**  
**Contains SVHC: No**  
**Low-Halogen Status**  
**Not Reviewed**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**  
[51067Series](#)

**Mates With**  
[51114](#) , [53258](#) , [53259](#) , [53265](#) , [53266](#)

**Use With**  
[50217 Crimp Terminals](#)

Sales Drawing

RPS-51067-037, RPS-51067-039, RPS-51067-040,  
RPS-51067-041  
SD-51067-\*\*-00

This document was generated on 06/20/2012

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**