

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [87369-0900](#)
Status: **Active**
Description: 2.00mm Pitch Crimp Housing, Single Row, 9 Circuits

Documents:
[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	87369
Application	Signal, Wire-to-Board
Product Name	N/A

Physical


Circuits (maximum)	9
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-25°C to +85°C

Material Info

UPC	800754326124
-----	--------------

Reference - Drawing Numbers

Product Specification	RPS-87369-001
Sales Drawing	SD-87369-**0*

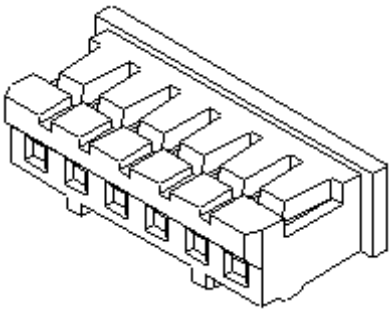

Series
image - Reference only

EU RoHS ELV and RoHS Compliant REACH SVHC Contains SVHC: No Low-Halogen Status Not Reviewed	China RoHS
--	-----------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[87369Series](#)

Mates With
89400 Vertical Header, [89401](#) Right Angle Header

Use With
[50212](#) Crimp Terminals. [104440](#) 2.00mm Pitch Crimp Terminals