

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [10-01-3096](#)  
**Status:** **Active**  
**Overview:** SPOX™  
**Description:** 5.08mm Pitch SPOX™ Crimp Terminal Housing, 9 Circuits

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-5197-005 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-5197-001 (PDF)</a>	

**Agency Certification**

CSA	LR19980
TUV	R72090224
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">5197</a>
Application	Signal, Wire-to-Board
Overview	<u>SPOX™</u>
Product Name	SPOX™

**Physical**


Circuits (maximum)	9
Color - Resin	Natural
Flammability	94V-2
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Nylon
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.08mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

**Material Info**

Old Part Number	5197-09
UPC	800754209656

**Reference - Drawing Numbers**

Product Specification	PS-5197-001, PS-5197-005, RPS-5281-001
Sales Drawing	SD-5197-N

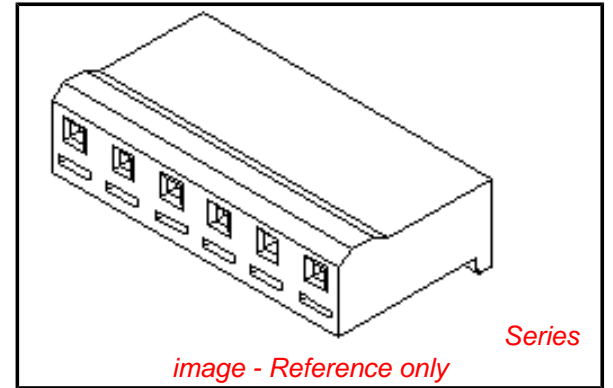

*image - Reference only*

**EU RoHS**

**ELV and RoHS  
Compliant**  
**REACH SVHC  
Contains SVHC: No**  
**Low-Halogen Status  
Not Reviewed**

**China RoHS**



**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of  
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

**Search Parts in this Series**

5197Series

**Mates With**

5279 , 5280 , 5281 , 5282

**Use With**

5194 , 5225