

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [35725-3710](#)
Status: **Active**
Description: 6.35mm Tab Slip-On Wire-to-Wire Terminal, Female, 14-18 AWG, Post-Tin Plated

Documents:

Drawing (PDF)	Product Specification PS-35725-005 (PDF)
Product Specification PS-35166-001 (PDF)	Product Specification PS-35955-001 (PDF)
Product Specification PS-35254-001 (PDF)	Packaging Specification PK-35725-014 (PDF)
Product Specification PS-35725-002 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Terminals
Series	35725
Application	Power
Crimp Quality Equipment	Yes
Product Name	N/A

Physical


Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Packaging Type	Reel
Plating min - Mating	1.016µm
Wire Insulation Diameter	5.00mm max.
Wire Size AWG	14, 16, 18
Wire Size mm ²	N/A

Material Info

UPC	800754258135
-----	--------------

Reference - Drawing Numbers

Packaging Specification	PK-35725-014
Product Specification	PS-35166-001, PS-35254-001, PS-35725-002, PS-35725-005, PS-35955-001
Sales Drawing	SD-35725-3**0

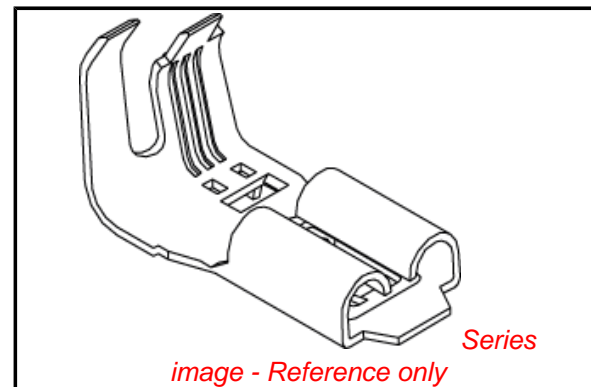

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[35725Series](#)

Mates With

[3572518x0](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Mini-Mac™ Applicator	0638015100