

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

53048-1310

Status:

Active

Overview:

PicoBlade™

Description:

1.25mm Pitch PicoBlade™ Header, Right Angle, 13 Circuits

Documents:

3D Model

Drawing (PDF)

Product Specification PS-51021-010 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E29179

General

Product Family

Series

Application

Overview

Product Name

PCB Headers

53048

Signal, Wire-to-Board

PicoBlade™

PicoBlade™

Physical

Breakaway

Circuits (Loaded)

Circuits (maximum)

Color - Resin

First Mate / Last Break

Glow-Wire Compliant

Guide to Mating Part

Keying to Mating Part

Lock to Mating Part

Mated Height

Material - Plating Mating

Material - Resin

Number of Rows

Orientation

PC Tail Length

PCB Locator

PCB Retention

PCB Thickness - Recommended

Packaging Type

Pitch - Mating Interface

Polarized to PCB

Shrouded

Stackable

Temperature Range - Operating

Termination Interface: Style

No

13

13

Natural

No

No

No

None

Yes

3.50mm

Tin

Nylon

1

Right Angle

2.30mm

No

None

0.80mm

Tray

1.25mm

No

Fully

No

-40°C to +85°C

Through Hole

Electrical

Current - Maximum per Contact

Voltage - Maximum

1A

125V

Material Info


UPC

800753565975

Reference - Drawing Numbers

Product Specification

PS-51021-010, RPS-51021-007, RPS-51021-011, RPS-51021-048, RPS-51021-059, RPS-51021-060, RPS-51021-071, RPS-51021-089, RPS-51021-104

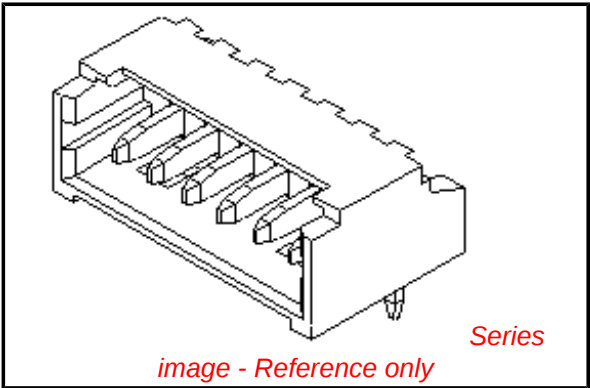

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

53048Series

Mates With

51021 PicoBlade™ Wire-to-Wire

This document was generated on 06/28/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION