


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [19211-0003](#)  
**Status:** **Active**  
**Overview:** [Wire Pins](#)  
**Description:** Krimptite™ Wire Pin Terminal for 22-18 AWG Wire

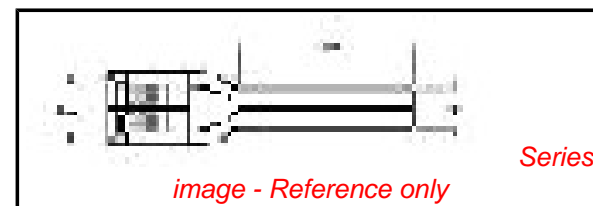

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Product Specification PS-19902-013 (PDF)</a>
<a href="#">Product Specification PS-19902-011 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR18689
UL	E32244

**General**

Product Family	Crimp Terminals
Series	<a href="#">19211</a>
Application	Power
Comments	Pin Length 9.91mm
Crimp Quality Equipment	Yes
Overview	<a href="#">Wire Pins</a>
Product Name	Wire Pin

**Physical**

Gender	Male
Material - Metal	Copper
Material - Plating Mating	Tin
Packaging Type	Bag
Plating min - Mating	1.016µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.52mm max.
Wire Size AWG	18, 19, 20, 22
Wire Size mm²	22-18

**Material Info**

Old Part Number	WP-1218
-----------------	---------

**Reference - Drawing Numbers**

Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	SD-19211-002

**EU RoHS**

**ELV and RoHS  
Compliant**

**REACH SVHC**

**Contains SVHC: No**

**Low-Halogen Status**

**Not Reviewed**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[19211Series](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
Hand Crimp Tool	<a href="#">0640030100</a>
Crimp Head for the AT-200™ Pneumatic Hand Tool	<a href="#">0640070100</a>