


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 19212-0005
Status: Active
Overview: Wire Pins
Description: InsulKrimp™ Wire Pin Terminal for 16-14 AWG Wire

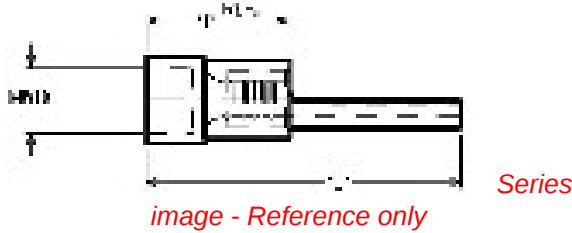

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Crimp Terminals
Series	19212
Application	Power
Comments	Pin Length 9.40mm
Crimp Quality Equipment	Yes
MolexKits	Yes
Overview	Wire Pins
Product Name	Wire Pin

Physical

Flammability	94V-0
Gender	Male
Material - Metal	Copper
Material - Plating Mating	Tin
Packaging Type	Bag
Plating min - Mating	1.016µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.45mm max.
Wire Size AWG	14, 16
Wire Size mm²	N/A

Material Info

Old Part Number	WP-2614X
-----------------	----------

Reference - Drawing Numbers

Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	SD-19212-001

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19212Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
Hand Crimp Tool	0640011400
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
Hand Crimp Tool	0640010100
Hand Crimp Tool	0640010300
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300