

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [85070-0500](#)
Status: **Active**
Description: 4.00mm SRC Heavy Duty Plug Housing, 84 Way, Nylon, Black

Documents:

Drawing (PDF)	Packaging Specification PK-85070-001 (PDF)
Product Specification PS-85070-001 (PDF)	Test Summary STR-1193 (PDF)
Application Specification AS-85070-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Housings
Series	85070
Application	Power, Wire-to-Wire
Comments	Polarized to mating part
Product Name	SRC

Physical

Circuits (maximum)	84
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Number of Rows	14
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	0.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +125°C

Electrical

Current - Maximum per Contact	40A
-------------------------------	-----

Material Info

Reference - Drawing Numbers

Application Specification	AS-85070-001
Packaging Specification	PK-85070-001
Product Specification	PS-85070-001
Sales Drawing	SD-85070-500
Test Summary	STR-1193

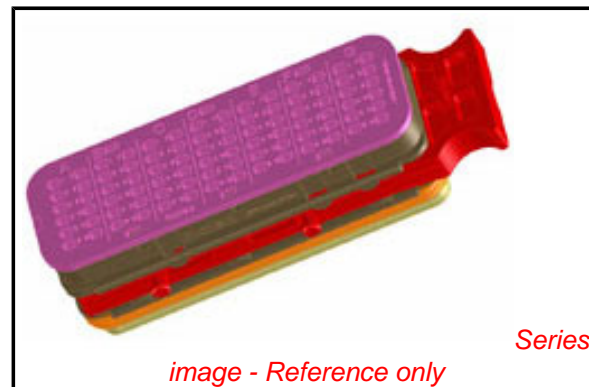


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[85070Series](#)

Mates With

[85071 SRC Heavy Duty Connector](#)

Use With

[33012 Female Terminals, Tin, AWG 1422.](#)
[33001 Female Terminal, Gold, AWG 1422.](#)
[19434 Female Terminal, Tin, AWG 812](#)