

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [502351-0800](#)
Status: **Active**
Overview: [DuraClik™](#)
Description: 2.00mm Pitch DuraClik™ Wire-to-Board Receptacle Housing, Single Row, 8 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-502351-001 \(PDF\)](#)
[Product Specification PS-502351-002 \(PDF\)](#)
[Packaging Specification PK-502351-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Housings
Series [502351](#)
Application Signal, Wire-to-Board
Overview [DuraClik™](#)
Product Name DuraClik™

Physical
Circuits (maximum) 8
Color - Resin White
Gender Receptacle
Glow-Wire Compliant No
Keying to Mating Part Yes
Lock to Mating Part Yes
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.00mm
Polarized to Mating Part Yes
Temperature Range - Operating -40°C to +105°C

Electrical
Current - Maximum per Contact 3A

Material Info
UPC 800756666877

Reference - Drawing Numbers
[Packaging Specification](#) PK-502351-001
[Product Specification](#) PS-502351-001, PS-502351-002, RPS-502351-001, RPS-502351-003, RPS-502351-004, RPS-502351-005
[Sales Drawing](#) SD-502351-001

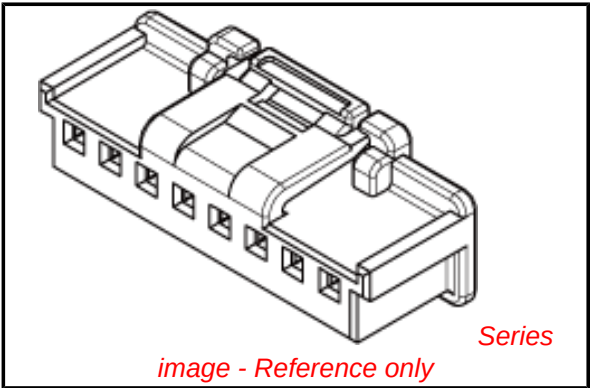

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Reviewed



Need more information on product environmental compliance?
Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)
Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[502351](#)Series

Mates With
[502352](#) PCB Header

Use With
[50212](#) Crimp Terminal . [50372](#) Crimp Terminal