

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [43061-0006](#)
Status: **Active**
Overview: SPOX™
Description: 3.96mm Pitch SPOX™ Housing, 6 Circuits

Documents:

[3D Model](#) [Packaging Specification PK-43061-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [43061](#)
 Application Power, Wire-to-Board
 Comments Glow Wire Equivalent Part Number [430613006](#)
 Overview [SPOX™](#)
 Product Name SPOX™

Physical


Breakaway No
 Circuits (maximum) 6
 Circuits Detail 6
 Color - Resin Natural
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Keying to Mating Part None
 Lock to Mating Part Yes
 Material - Resin Polyester
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 3.96mm
 Pitch - Termination Interface 3.96mm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating 0°C to +75°C

Material Info

UPC 800753629967

Reference - Drawing Numbers

Packaging Specification PK-43061-001
 Sales Drawing SD-43061

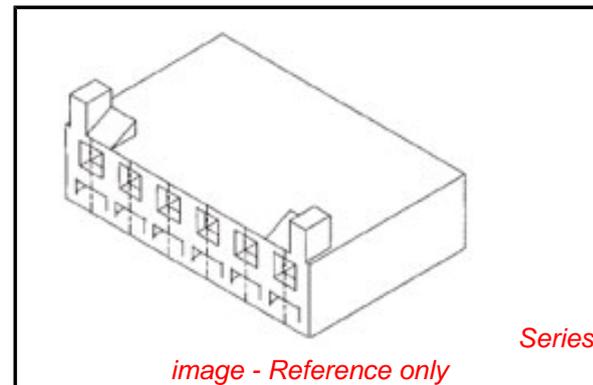

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[43061Series](#)

Mates With

3.96mm Pitch KK® or SPOX® headers

Use With

Spox Terminal [5194](#) , [5225](#)