

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 19070-0143
Status: Active
Overview: Ring Tongue - Spade Terminals
Description: InsulKrimp™ Ring Tongue Terminal for 10-12 AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series 19070
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Ring Tongue - Spade Terminals
Product Name InsulKrimp™
Type Ring

Physical


Barrel Type Closed
Color - Resin Natural
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Packaging Type Bag
Stud Size 5-6 (M3-3.5)
Wire Insulation Diameter 6.40mm max.
Wire Size AWG 10, 12
Wire Size mm² 3.30 - 5.00

Material Info

Old Part Number C-236-06X

Reference - Drawing Numbers

Product Specification PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing SD-19070-007

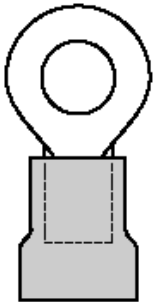

Series
image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19070Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
Hand Crimp Tool	0640010100
Hand Crimp Tool	0640010300
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300