

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

43030-0005

Status:


Active

Overview:

Micro-Fit 3.0™ Connectors

Description:

Micro-Fit 3.0™ Crimp Terminal, Female, with Select Gold (Au) Plated Phosphor Bronze Contact, 26-30 AWG, Reel

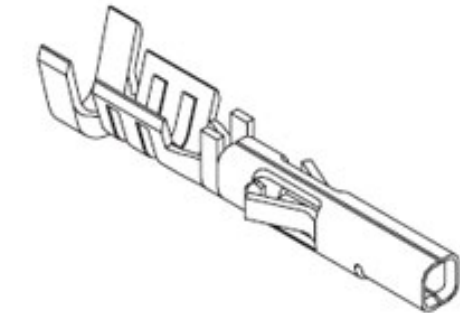

Series

image - Reference only

Documents:

- [3D Model](#)
- [Drawing \(PDF\)](#)
- [Product Specification PS-43045 \(PDF\)](#)
- [Test Summary TS-43045-002 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)
- [Product Literature \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	43030
Application	Power
Crimp Quality Equipment	Yes
Overview	Micro-Fit 3.0™ Connectors
Product Literature Order No	987650-5984
Product Name	Micro-Fit 3.0™

Physical

Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Packaging Type	Reel
Plating min - Mating	0.381µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.27mm max.
Wire Size AWG	26, 28, 30
Wire Size mm²	N/A

Material Info

UPC	800754369206
-----	--------------

Reference - Drawing Numbers

Product Specification	PS-43045, RPS-43045-003, RPS-43045-004
Sales Drawing	SD-43030-****
Test Summary	TS-43045-002

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
43030Series

Mates With
43031

Use With
43025 Receptacle Housing, 43645 Receptacle Housing, 44133 Panel Mount Receptacle Housing

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
FineAdjust™	0639001600
Applicator for insulation OD	
0.63-1.10mm - 26-30 AWG	

Hand Crimp Tool	<u>0638190000</u>
T2 Terminator™	<u>0639104400</u>
for insulation OD	
1.12-1.27mm - 26-30	
AWG	
Insertion Tool for	<u>0638120800</u>
Crimp Terminal	
FineAdjust™	<u>0639004400</u>
Applicator for	
insulation OD	
1.12-1.27mm - 26-30	
AWG	
Extraction Tool	<u>0011030043</u>
Japan	
Description	Product #
Applicator for M211A	<u>0572983000</u>
Bench Press, 20-30	
AWG Wire	

This document was generated on 06/13/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION