


## L2002 FUSEHOLDER



- Miniature panel fuseholder
- Removable membrane in fuseholder head for test probe
- Fuse carrier that screw into the body to achieve a reliable contact
- Fuseholder bodies have a feature to prevent rotation within the panel
- Conforms to IEC 257, BS415 and BS4042
- Accepts 20 x 5mm fuse links

<b>CURRENT RATING:</b>	<b>6.3A</b>
<b>BREAKDOWN VOLTAGE:</b>	<b>&gt;4kV (sea level)</b>
<b>TEMPERATURE RANGE:</b>	<b>-55°C to +70°C (ambient)</b>
<b>INSERTION RESISTANCE:</b>	<b>5 milliohms (average) 10 milliohms (maximum)</b>
<b>INSULATION RESISTANCE:</b>	<b>≥10 megohms</b>
<b>FIXING TORQUE (MAX):</b>	<b>0.68 Nm</b>
<b>FLAMMABILITY:</b>	<b>UL94VO</b>
<b>TERMINATIONS:</b>	<b>Solder</b>
<b>MATERIALS:</b>	<b>Moulding, thermoplastic glass filled polyester (flame retardant) Contacts, brass, silver-plated and phosphor bronze, silver-plated</b>
<b>APPROVALS:</b>	<b>UL, CSA, VDE, SEMKO</b>

**ORDERING REFERENCE: L2002**

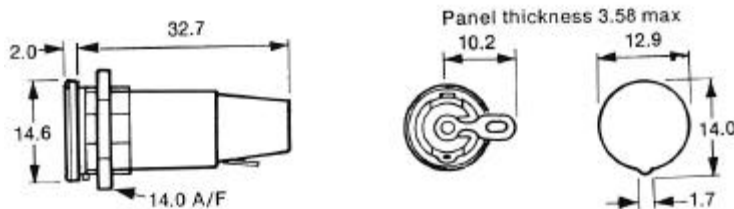

Dialight BLP reserve the right to change without prior notice the information contained within this leaflet

Dialight BLP Ltd., Exning Road, Newmarket, Suffolk, CB8 0AX, England  
Tel: +44 (0)1638 665161 Fax: +44 (0)1638 660718 email: [sales@blpcomp.com](mailto:sales@blpcomp.com) <http://www.blpcomp.com>