

- Suitable replacement for 40 W incandescent lamps
- Dimmable
- Up to 80% energy saving
- Lifetime of 25,000 hrs



Order Code 52019

General Data

Lamp Socket E27
Design Frosted

Geometric Data



Diameter (mm) 58.0
Length (mm) 108.4
Weight (g) 145


Electric Data

Wattage 9 W
Voltage 220-240 V
Power Factor 0.85
Operating Frequency 50/60 Hz

Photometric Data

Luminous Flux (lm) 440
CRI >80
CCT 2700 K – warm white
Luminous Intensity (cd) N/A
Beam Angle (°) 180
Lifetime 25 000hrs

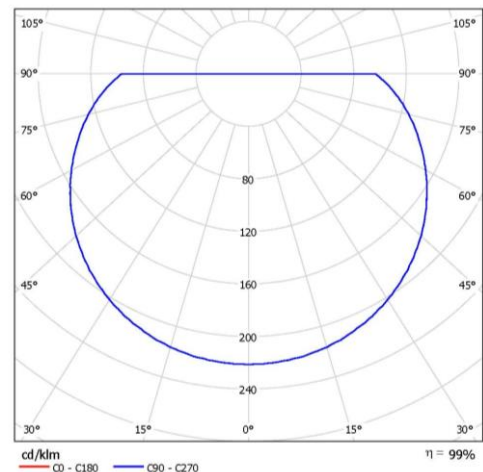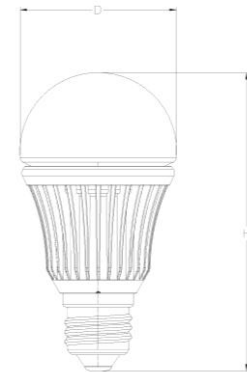

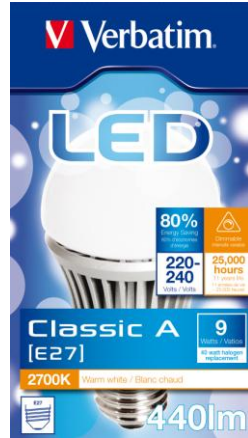

Order Code 52019
Product Description LED CLASSIC A E27 9W 2700K WW 440LM DIM

Technical Packaging Details

Barcode	023942520191
EAN 128	(02)00023942520191(37)10(91)53
EAN 14	20023942520195
Pack Dimensions	130 mm x 74 mm x 74 mm
Pack Weight	175 g
Carton Qty (Shipping Unit)	20
Carton Dimensions	388 mm x 323 mm x 159 mm
Cartons/Layer	6
Layers/Pallet	5
Units/Pallet	600