

- Replacement for low voltage 35 W halogen lamp
- Dimmable
- Lifetime of 25,000 hrs
- Ideal for accent lighting in hotels, hospitals, shops, restaurants or museums



Order Code 52028

General Data

Lamp Socket GU5.3
Design Lens

Geometric Data

Length (mm) 48.6
Diameter (mm) 50.2
Weight (g) 53


Electric Data

Wattage 7 W
Voltage 12 V AC/DC
Power Factor ≥ 0.70
Operating Frequency 50/60 Hz

Photometric Data

Luminous Flux (lm) 450
CRI ≥ 80
CCT 2700 K – warm white
Luminous Intensity (cd) 1100
Beam Angle (°) 30°
Lifetime 25 000hrs

Equivalent to (W) 35 W

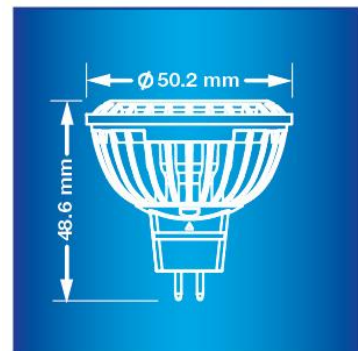



Order Code 52028

Product Description LED MR16 GU5.3 7W 12V AC/DC 2700K WW 450LM DIM Box

Technical Packaging Details

Barcode	023942520283
EAN 128	(02)00023942520283(37)10(91)53
EAN 14	20023942520287
Pack Dimensions	75 mm x 57 mm x 57 mm
Pack Weight	76
Carton Qty (Shipping Unit)	10
Carton Dimensions (HxWxL)	611 mm x 303 mm x 189 mm
Cartons/Layer	3
Layers/Pallet	4
Units/Pallet	1200

Photometric Diagram

52028

