


2-way Cabinet Speakers

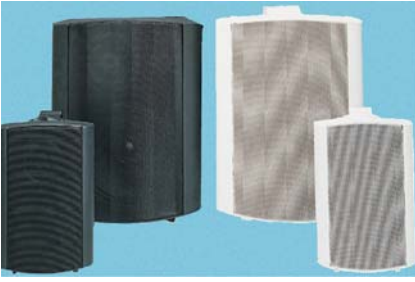

A range of 2-way, bass reflex cabinet speakers with either black or white moulded plastic cases. The speakers have a trapezoidal shape, allowing them to be mounted neatly in the corner of a room. Supplied with adjustable mounting brackets. Cable termination is via screw terminals. Available in both low impedance (4Ω) and 100V Line versions. The 100V line versions have an integral 6-way power matching rotary switch, with an Off position.

Low Impedance Models	102-6740 / 102-6741	102-6742 / 102-6743
Drive Units		
Bass/mid-range	∅80mm	∅140mm
Tweeters	∅65mm	∅80mm
Impedance	4Ω	4Ω
Frequency Range	60Hz to 20kHz	40Hz to 20kHz
Music Power RMS	45W max./30W	90W max./60W
SPL (1W/1m)	87dB	89dB
Dimensions (WxHxD)mm	130x192x115	215x290x172
Weight	2.6kg	6.7kg
100V Line Models	102-6746 / 102-6747	102-6748 / 102-6749
Power Tappings	15/7.5/4/2/1W RMS	30/15/7.5/4/2W RMS
Frequency Range	60Hz to 20kHz	40 to 20kHz
SPL (1W/1m)	87dB (98dB max.)	89dB, (103dB max.)
Dimensions (WxHxD)	130x192x115mm	270x370x220mm
Weight	1.4kg	5.4kg

417080

Description	Order Code	Price/Pair
Low Impedance		
45W Black	102-6740	
45W White	102-6741	
90W Black	102-6742	
90W White	102-6743	
100V Line		
15W Black	102-6746	
15W White	102-6747	
30W Black	102-6748	
30W White	102-6749	