

T18R9M4

Cable Tie, 18lb., 4", Max. Bun. Dia .87" PA66, Natural, 1000/pk

Article Number: 111-01872

Part Number: T18R9M4

Type: T18R


Website Feedback



Base Data


Part No.	T18R9M4
Type	T18R
Color	Natural (NA)
Features	Available in a wide range of materials, these cable ties all feature internal serrations allowing for a positive hold onto cable and pipe bundles. The design of the head guarantees a high tensile strength while allowing a very low insertion force, this, combined with the bent tail design of many of the ties ensures a simple and quick installation. While easily installed by hand, - manual and pneumatic (for high volume applications) tensioning tools are available to ensure consistency of installation.
Application	Used to bundle and secure wire and cable.
Application Method	Quick, simple application by hand or with HellermannTyton tensioning tools
Identification Plate Position	none
Releasable Closure (Yes/No)	No
Tie Closure	plastic pawl
Variant	Inside Serrated

Product Dimensions

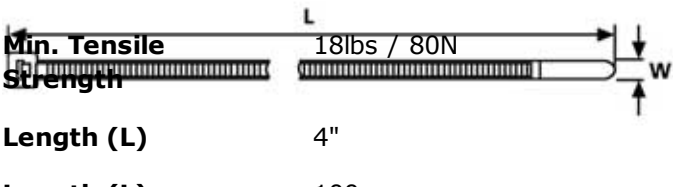

Length (L)	100mm
Width (W)	.10"
Width (W)	2.5mm
Min. Ø Bundle	.06" / 1.5mm
Max. Ø Bundle	.87" / 22.0mm

Material and Specifications

Material	Polyamide 6.6 (PA66)
US MILSPEC	MS3367-4-9
CSA Certified	No
Flammability	UL94 V2
Material Specification	HF
Operating Temperature	-40 °C to +85 °C, intermittent +105 °C (for 500 h)
ROHS Conformity	
Specification	UL ZODZ2.E64139
UL Listed (US and Canada)	Yes
UL Recognized (US and Canada)	Yes

Logistic and Packaging

Packaging Type	bag
Pkg. Qty.	1000
Carton Qty.	10000
EAN code	4031026274522
UPC	089306071280