

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0393550006**
Status: **Obsolete**
Description: 3.5mm (.138") Beau™ Eurostyle™ Right Angle PCB Header, Closed Ends, 6 Circuits
Replacement Part Number: 39502-1006

Documents:
[Drawing \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	39355
Application	Wire-to-Board
Comments	Available in green, blue or orange and gold plated contacts
Component Type	PCB Header
Product Name	Eurostyle™ Pluggable
Replacement Part Number	39502-1006
Type	Euro Block

Physical

Circuits (Loaded)	6
Color - Resin	Black
Entry Angle	N/A
Flammability	94V-0
Lock to Mating Part	None
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Orientation	Right Angle
PC Tail Length	3.45mm (.136")
PCB Retention	N/A
Panel Mount	No
Pitch - Mating Interface	3.50mm (.138")
Pitch - Termination Interface	3.50mm (.138")
Plating min - Mating	3.810µm (150µ")
Plating min - Termination	3.810µm (150µ")
Polarized to Mating Part	Yes
Shrouded	Closed Ends
Stackable	No
Temperature Range - Operating	140°C
Wire Size AWG	N/A

Electrical

Current - Maximum per Contact	10A
Voltage - Maximum	300V

Solder Process Data

Lead-free Process Capability Wave Capable (TH only)

Material Info

Old Part Number 351906

Reference - Drawing Numbers

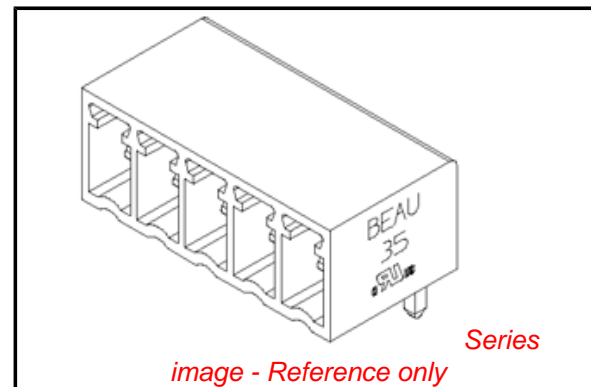


image - Reference only

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

39355Series

Mates With

39351 Plugs

This document was generated on 01/27/2011

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION