




ASPIRE X1930

Robust performance, slim form

- Efficient computing
- Essential features
- Trendy design



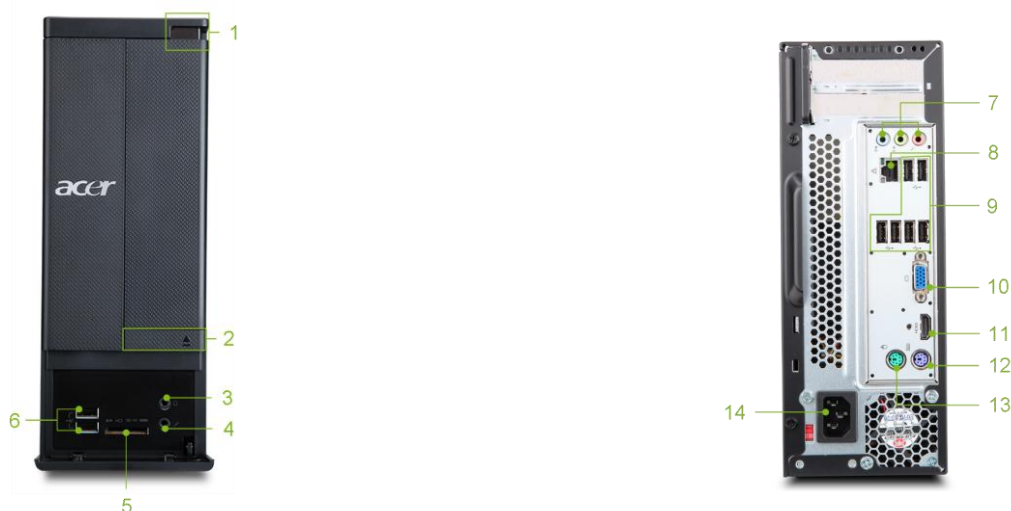

Product views	1 Power button 2 ODD eject button 3 Headphone jack 4 Microphone jack 5 Multi-in-1 card reader	6 Two USB 2.0 ports 7 Three audio jacks 8 Ethernet (RJ-45) port 9 Six USB 2.0 port 10 D-Sub VGA port	11 HDMI® port 12 PS/2 keyboard port 13 PS/2 mouse port 14 Power connector
Operating system¹	Genuine Windows® 7 Home Premium 64-bit ² Genuine Windows® 7 Home Basic 64-bit ² Genuine Windows® 7 Starter		
Processor^{1,3}	2nd generation Intel® Core™ i7 processor	2nd generation Intel® Core™ i5 processor	2nd generation Intel® Core™ i3 processor
Chipset¹	Intel® H61 Express Chipset		
Memory¹	Up to 8 GB of DDR3 1333 MHz SDRAM (dual-channel support on two DIMMs)		
Hard drive¹	Serial ATA hard disk up to 1.5 TB		
Optical drive¹	SuperMulti DVD-ROM		
Card reader⁴	Multi-in-1 card reader, supporting: • MultiMediaCard™ (MMC) • Secure Digital™ (SD) Card • xD-Picture Card™ • Memory Stick™ • Memory Stick PRO™		
Expansion bays	External 5.25" drive bay Internal 3.5" drive bay		
Graphics	Intel® HD Graphics		
Audio	High-definition audio with stereo support		
Networking	LAN: Gigabit Ethernet WLAN: ^{1,4,5} 802.11b/g/n Wi-Fi CERTIFIED™		
I/O expansion	PCI Express® 2.0 x16 slot PCI Express® 2.0 x1 slot		
Software	Acer clear.fi Acer eRecovery Management Adobe® Reader® Bing™ Bar McAfee® Internet Security Suite Trial ⁷	Microsoft® Office 2010 preloaded (purchase a product key to activate) ⁸ Microsoft® Office Starter 2010 ⁹ MyWinLocker®	Nero® 10 Essentials newsXpresso™ Oberon GameZone ¹ WildTangent® ¹
Dimensions	100 (W) x 367.8 (D) x 268.5 (H) mm		
Power supply¹	220 W (PFC/non-PFC)		
System compliance	PC 2001		
Certification	CE, CCC, CB		
Optional accessories	Acer USB or PS/2 keyboard and mouse Remote control		

Windows®, Life without Walls™, Acer recommends Windows 7.

1. Specifications vary depending on model.

2. 64-bit software is required to enjoy the advantages of 64-bit processing.

3. 2nd generation Intel® Core™ processors support Intel® Hyper-Threading Technology, enabling them to handle eight processing threads on four cores for the fastest processing available.

4. Optional

5. Actual throughput may vary depending on network conditions and environmental factors such as network traffic or overhead, building construction and access point settings.

6. Bundled software may vary depending on hardware configuration, OS, and regional availability.

7. Trial periods vary depending on the geographic region and specifications: 365-day trial for China, Taiwan, Hong Kong and Singapore (Simplified Chinese and Traditional Chinese OS models); 60-day trial for other regions

8. Purchase an Office 2010 product key to activate one of the following Office 2010 suites preloaded on this PC: Office Home and Student 2010, Office Home and Business 2010, Office Professional 2010.

9. Includes limited-functionality Microsoft® Word and Excel with advertising; no PowerPoint or Outlook. Purchase Office 2010 to activate full-featured Office.

As a phenomenon known to thin-film transistors (TFTs), liquid crystal displays (LCDs) commonly exhibit a small number of discoloration dots, as so-called "non-conforming pixels." This phenomenon is a limitation of TFT LCD technology, not a product defect, and as such is not covered by Acer's warranty.

© 2011. All rights reserved. Acer Inc. All other trademarks are the property of their respective owners. All specifications are subject to change. Pictures are not contractual.

Microsoft and Windows are registered trademarks of Microsoft Corporation. Intel, Core, and Core Inside are registered trademarks of Intel Corporation in the U.S. and other countries.

Please visit www.acer.com for more information.