



Tools That Work



2012 Catalog





Who We Are

Bondhus Corporation is located in Monticello, Minnesota - USA; about 40 minutes from Minneapolis. Bondhus employees are proud of our Company and the tools we make. Our Ball, Hex, and Star Tip tools are made in our Monticello manufacturing facility, just across the street from the Mighty Mississippi River.




In 1964, John Bondhus began manufacturing the original "Balldriver®" ball end hex tool which he invented. Since that time, we have taken great pride in being the industry leader in designing and manufacturing innovative, timesaving tools. We have built our business by providing Bondhus customers (professional tool users) with the highest quality products and customer support in the industry.

With some 70 competitors worldwide, no one seriously disputes the overwhelming dominance of Bondhus Corporation in the world of ball end hex tools. Bondhus tools turn up everywhere! They can be found in tool boxes around the globe, on every continent and in over 80 countries from Taiwan to Venezuela and from Sweden to Japan. Machinists and automotive repair shops find them indispensable. Printing press operators use them in Singapore, South Dakota, and Saudi Arabia - so do dentists and the makers of artificial limbs. Bicycle repair kits everywhere contain some version of our tools. Jazz, rock, and pop musicians who play guitars also use Bondhus tools.

When NASA needed special hand tools to repair the International Space Station and the Hubble Space Telescope, they called Bondhus. They needed the very best tool for the most demanding of applications. NASA discovered what millions of professional tool users around the world already know - Bondhus tools work in even the most difficult circumstances.

Bondhus tool strength and consistent high quality are the standards by which other hand tools are judged. Whether the tool user works in outer space or on an oil rig in the middle of the ocean, the tools they use must work the first time... they do not have time to go back for a replacement. Bondhus tools are built to work hard, built to save time and built to last. In independent laboratory torque tests (just one of several means of evaluating tools), Bondhus consistently out performs competitors.

Bondhus manufactures the highest quality Ball End, Hex and Star tools available, and every tool is backed by an unconditional lifetime warranty. A warranty is only as good as the company standing behind it, and Bondhus has been the leading innovator in the Hex and Star tool industry for more than forty years.

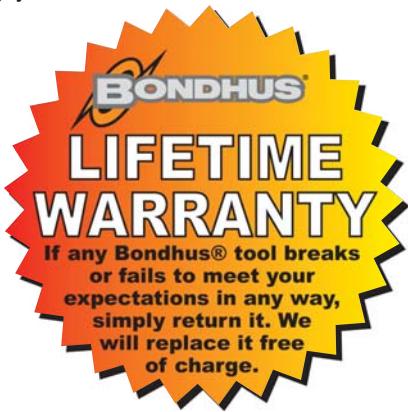

Contents

Bondhus Professional Quality Tools Provide Superior Value

Time is money, and the real cost of using an inferior tool is realized when something goes wrong. As anyone who works with mechanical devices knows, bad things occasionally happen. It is not a question of "if", but rather "when".

Stripped screw heads are one of those bad things that happen. A screw with a stripped head can no longer be removed with a hex tool. If it is in a difficult to reach location, where a clamping device cannot grip it, the task becomes particularly problematic.

The cost of a high quality hex tool is negligible compared to the cost of removing a broken or stripped screw. Will the removal take a few hours? An entire day? What is the real cost of an inexpensive, poorly performing hex tool?

Bondhus quality hex tools are made from Protanium® high torque steel and have sharper corners to generate maximum holding and turning forces within the screw to virtually eliminate stripped screw heads.

Professional hex tools deliver a level of performance not attainable by consumer grade tools. In addition, safety is a factor that can impact the "actual" cost of ownership. As a result, knowledgeable buyers and professionals alike recognize the serious dangers of inferior tools that shatter instead of breaking clean.

The purpose of a high quality tool is to provide a faster, easier, and less costly means of performing a task. Bondhus strives to provide not just "good" tools, but the strongest tools available anywhere. Customer satisfaction is what we strive for.




L-Wrench Multipacks	5
A photograph of two yellow and red tool boxes, likely containing L-wrench sets.	
ProGuard™ L-Wrenches	6-14
A photograph of several blue and yellow ProGuard L-wrenches of various sizes.	
BriteGuard™ L-Wrenches	15-17
A photograph of several blue and red BriteGuard L-wrenches.	
GoldGuard™ L-Wrenches	18-19
A photograph of several gold-colored GoldGuard L-wrenches.	
Star Tip L-Wrenches	20-22
A photograph of several green and black Star Tip L-wrenches.	
Wing and Flag Tools	23
A photograph of two black Wing and Flag tools.	
Fold Ups	24-27
A photograph of three colorful fold-up tools (black, red, and green).	
T-Handles	28-33
A photograph of three T-handle tools with different colored handles (red, yellow, and black).	
Screwdrivers	34-40
A photograph of a set of screwdrivers with black and yellow handles.	
Nut Drivers	41
A photograph of a set of nut drivers with black and yellow handles.	
Socket Bits	42-46
A photograph of a set of socket bits with black and yellow handles.	
Hextenders	46
A photograph of a set of hextender tools with black and yellow handles.	
Blades and Bits	47-48
A photograph of a set of blades and bits with black and yellow handles.	

L-Wrenches



Color Coded

- Inch
- Metric
- Star

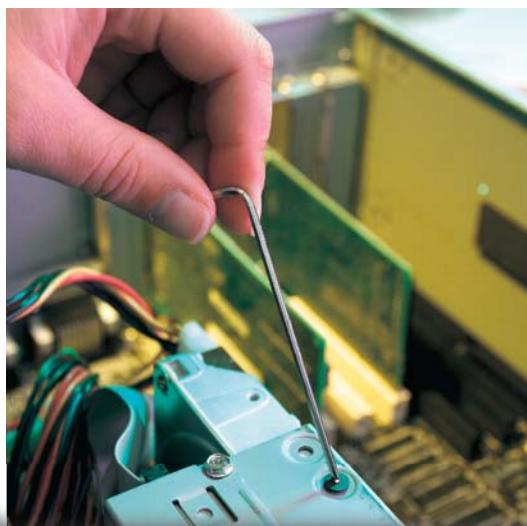

High Torque Steel:

Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel.

FINISH OPTIONS:



Corrosion-resistant finish:

Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes.



Next generation chrome finish:

Traditional plated tool look with superior protection and durability.




Real 14 karat gold finish:

Superior protection and durability over traditional chrome and the look and shine of real gold.

More than just another L-Wrench


Bondhus is committed to making the best tools on the market. Bondhus is constantly working to improve our tools. We are never satisfied with "good enough." We work hard to make sure your new Bondhus L-Wrench is always the best tool for the job.

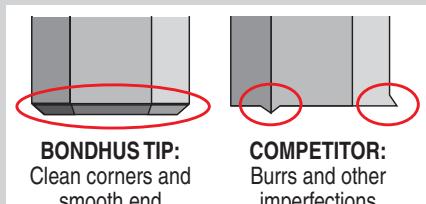

BONDHUS TIP:
Clean corners and
smooth end

COMPETITOR:
Burr and other
imperfections

Bondhus chamfers every Hex and Star Tip tool we make. This process eliminates burrs and imperfections in the tool's tip that can prevent the tool from fitting properly or seating fully within the screw head.

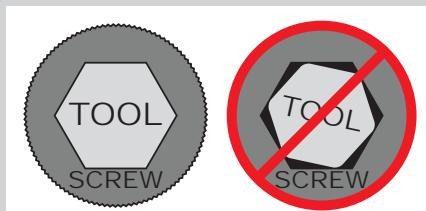

Every Bondhus tool is designed and machined to achieve an optimal fit between tool and fastener. Tools insert quickly and easily into screw head and fit snug to generate greater torque and minimize slippage and stripping.



Bondhus custom heat-treating produces tools that are highly resistant to breakage and shattering.



- Assembled from our most popular sets
- Multiple sets per package
- Tip selections include Ball End, Star Tip, Hex End, and ProHold® Tip Ball End.

ProGuard™ Ball End



PART# MODEL# PCS CONTENTS

QTY LIST

20196	BLX21	21	10936 (.050-5/16") + 10999 (1.5-10mm)	1
20199	BLX22	22	10937 (.050-3/8") + 10999 (1.5-10mm)	1



ProGuard™ Ball End Stubby



PART# MODEL# PCS CONTENTS

QTY LIST

20599	SBLX22	22	16537 (.050-3/8") + 16599 (1.5-10mm)	1
-------	--------	----	--------------------------------------	---




ProGuard™ ProHold® Tip Ball End



PART# MODEL# PCS CONTENTS

QTY LIST

20499	PBLX22	22	74937 (.050-3/8") + 74999 (1.5-10mm)	1
-------	--------	----	--------------------------------------	---

 

ProGuard™ Hex End



PART# MODEL# PCS CONTENTS

QTY LIST

22199	HLX22	22	12137 (.050-3/8") + 12199 (1.5-10mm)	1
-------	-------	----	--------------------------------------	---



ProGuard™ Ball End and Hex End



PART# MODEL# PCS CONTENTS

QTY LIST

14130	BLF34	34	10937 (.050-3/8") + 10999 (1.5-10mm) + 12550 (Hex Fold Up 5/64-5/32", 1.5-5mm)	1
14187	BLF16M	16	10999 (1.5-10mm) + 12587 (Hex Fold Up 2-8mm)	1
14189	BLF22	22	10937 (.050-3/8") + 12589 (Hex Fold Up 5/64-1/4")	1



ProGuard™ Ball End and Star Tip



PART# MODEL# PCS CONTENTS

QTY LIST

14132	BLF30TS	30	10937 (.050-3/8") + 10999 (1.5-10mm) + 12632 (Star Fold Up T6-T25)	1
14138	BLF30T	30	10937 (.050-3/8") + 10999 (1.5-10mm) + 12634 (Star Fold Up T9-T40)	1
14126	BLF17S	17	10999 (1.5-10mm) + 12632 (Star Fold Up T6-T25)	1
14128	BLF17	17	10999 (1.5-10mm) + 12634 (Star Fold Up T9-T40)	1



BriteGuard™ and GoldGuard™ Ball End



PART# MODEL# PCS CONTENTS

QTY LIST

20399	BLX22GB	22	26937 (.050-3/8") + 38099 (1.5-10mm)	1
-------	---------	----	--------------------------------------	---



GoldGuard™ Ball End



PART# MODEL# PCS CONTENTS

QTY LIST

20899	BLX22G	22	37937 (.050-3/8") + 38099 (1.5-10mm)	1
-------	--------	----	--------------------------------------	---



 
Ball End L-Wrenches

- ProGuard™ Finish -

L-Wrenches


- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- 25° angle allows natural hand and wrist movement
- Superior Ball End strength and working angle
- Works in hard to reach places

ProGuard™ finish
delivers superior
corrosion protection



Ball End Tips

Yellow=Inch
Red=Metric

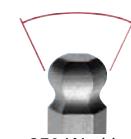

25° Working angle

QTY LIST



10937



10935

Sets PART# MODEL# PCS LENGTH CONTENTS

Inch

10945	BLX7	7	Long	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"	1
10932	BLX8	8	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1
10938	BLX10	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1
10936	BLX12	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1
10937	BLX13	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1
10935	BLX15	15	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 7/16, 1/2" (in vinyl roll up pouch)	1
10933	MBLX13	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8" (in metal box)	1
16037	BLX13XL	13	Extra Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1

Singles



SINGLE PACKAGING

PACKAGED

BULK



TAGGED/BARCODED

SIZE INCH MM INCH MM PART# QTY LIST EA PART# QTY LIST EA PART# QTY LIST EA

LONG
Inch

.050	2.8	72	0.53	13	10902	10	12902	100	15702	10
1/16	3.0	76	0.56	14	10903	10	12903	100	15703	10
5/64	3.2	81	0.61	15	10904	10	12904	100	15704	10
3/32	3.4	86	0.65	16	10905	10	12905	100	15705	10
7/64	3.6	90	0.70	18	10906	10	12906	100	15706	10
1/8	3.8	95	0.75	19	10907	10	12907	100	15707	10
9/64	4.0	101	0.80	20	10908	10	12908	100	15708	10
5/32	4.2	107	0.84	21	10909	10	12909	100	15709	10
3/16	4.5	114	0.94	24	10910	10	12910	100	15710	10
7/32	4.9	124	1.03	26	10911	5	12911	50	15711	5
1/4	5.6	141	1.13	29	10912	5	12912	50	15712	5
5/16	6.0	152	1.25	32	10913	5	12913	50	15713	5
3/8	6.8	171	1.38	35	10914	5	12914	50	15714	5
7/16	7.5	191	1.50	38	10915	1	12915	25	15715	1
1/2	8.3	210	1.63	41	10916	1	12916	25	15716	1
9/16	9.0	229	1.75	44	10917	1	12917	10	15717	1
5/8	9.8	248	1.88	48	10918	1	12918	10	15718	1
3/4	11.3	286	2.13	54	10919	1	12919	5	15719	1
7/8	12.8	325	2.37	60	10920	1				
1	14.2	362	2.62	67	10921	1				

Singles



SINGLE PACKAGING

PACKAGED

SIZE INCH MM INCH MM PART# QTY LIST EA

EXTRA
LONG
Inch

.050	3.1	77	0.53	13	16002	10
1/16	3.3	85	0.56	14	16003	10
5/64	3.6	92	0.61	15	16004	10
3/32	3.9	99	0.65	16	16005	10
7/64	4.1	105	0.70	18	16006	10
1/8	4.5	114	0.75	19	16007	10
9/64	4.8	122	0.80	20	16008	10
5/32	5.1	131	0.84	21	16009	10
3/16	5.2	132	0.94	24	16010	10
7/32	5.6	143	1.03	26	16011	5
1/4	6.5	164	1.13	29	16012	5
5/16	7.1	180	1.25	32	16013	5
3/8	7.8	199	1.38	35	16014	5

Did you know...?

Bondhus Ball End tips are designed to be the perfect balance between angle and strength. Ball End strength is maximized, while still providing a consistent full 25° working angle.

 
Ball End L-Wrenches

- ProGuard™ Finish -

L-Wrenches


- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- 25° angle allows natural hand and wrist movement
- Superior Ball End strength and working angle
- Works in hard to reach places

ProGuard™ finish
delivers superior
corrosion protection



Ball End Tips

Yellow=Inch
Red=Metric

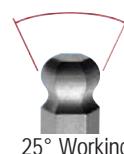

25° Working angle

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Metric	10946	BLX6M	6	Long	1.5, 2, 2.5, 3, 4, 5mm	1	
	10992	BLX7M	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	10999	BLX9M	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	10995	BLX15M	15	Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1	
	10989	MBLX13	13	Long	1.27, 1.5, 2, 2.5, 3, 4, 5, 6, 8, 10, 12, 14, 17mm (in metal box)	1	
	16099	BLX9MXL	9	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

10999



10989

Singles	SIZE	INCH		MM		PART#	PACKAGED		BULK		TAGGED/BARCODED	
		INCH	MM	INCH	MM		QTY	LIST EA	PART#	QTY		
LONG Metric	1.27	2.8	72	0.53	13	10949	10		12949	100	15749	10
	1.5	3.0	77	0.53	14	10950	10		12950	100	15750	10
	2.0	3.2	82	0.61	16	10952	10		12952	100	15752	10
	2.5	3.5	88	0.69	17	10954	10		12954	100	15754	10
	3.0	3.9	98	0.75	19	10956	10		12956	100	15756	10
	3.5	3.9	100	0.85	21	10958	1		12958	100	15758	1
	4.0	4.3	110	0.87	22	10960	10		12960	100	15760	10
	4.5	4.5	114	1.00	25	10962	1		12962	100	15762	1
	5.0	4.7	119	1.06	27	10964	5		12964	100	15764	5
	5.5	4.9	124	1.14	29	10966	1		12966	50	15766	1
	6	5.5	139	1.22	31	10968	5		12968	50	15768	5
	7	5.5	140	1.30	33	10970	1		12970	50	15770	1
	8	6.0	152	1.38	35	10972	5		12972	50	15772	5
	9	6.2	159	1.46	37	10974	1		12974	50	15774	1
	10	6.7	171	1.54	39	10976	5		12976	50	15776	5
	11	7.9	200	1.63	42	10978	1		12978	25	15778	1
	12	8.7	220	1.73	44	10980	1		12980	25	15780	1
	14	10.2	260	2.15	55	10984	1		12984	10	15784	1
	17	11.0	280	2.42	61	10986	1		12986	10	15786	1
	19	11.6	295	2.70	69	10988	1		12988	5	15788	1
	22	13.0	330	3.07	78	10991	1				-	-
	24	14.5	370	3.47	88	10993	1				-	-

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
EXTRA LONG Metric	1.5	3.5	90	0.53	14	16050	10	
	2.0	3.9	100	0.61	16	16052	10	
	2.5	4.4	112	0.69	17	16054	10	
	3.0	5.0	126	0.75	19	16056	10	
	4.0	5.6	142	0.87	22	16060	10	
	5.0	6.3	160	1.06	27	16064	5	
	6	6.8	172	1.22	31	16068	5	
	8	7.7	195	1.38	35	16072	5	
	10	8.4	213	1.54	39	16076	5	

Did you know...?

Bondhus' extremely precise manufacturing methods create Ball End tools that work very well, even in sizes as small as .050", 1.27mm, and T6 (BallStar™ Tip).

ProHold® Tip Ball End L-Wrenches

L-Wrenches

 
- ProGuard™ Finish -

- Holds screw tight on the tool EVERY TIME
- Button is non-magnetic
- Super smooth rotational action, with no interference from the ProHold® button
- Tool strength is not compromised by the ProHold® button

ProGuard™ finish
delivers superior
corrosion protection



Yellow=Inch
Red=Metric




ProHold® Tip holds
screws securely

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	74938	PBLX10	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	74937	PBLX13	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	74992	PBLX7M	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	74999	PBLX9M	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	



 74999




Singles	SIZE	INCH		MM		PART#	QTY	LIST EA	PART#	QTY	LIST EA
		INCH	MM	INCH	MM						
LONG Inch	.050	2.8	72	0.53	13	75902	25		75702	5	
	1/16	3.0	76	0.56	14	75903	25		75703	5	
	5/64	3.2	81	0.61	15	75904	25		75704	5	
	3/32	3.4	86	0.65	16	75905	25		75705	5	
	7/64	3.6	90	0.70	18	75906	25		75706	5	
	1/8	3.8	95	0.75	19	75907	25		75707	5	
	9/64	4.0	101	0.80	20	75908	25		75708	5	
	5/32	4.2	107	0.84	21	75909	25		75709	5	
	3/16	4.5	114	0.94	24	75910	25		75710	5	
	7/32	4.9	124	1.03	26	75911	10		75711	2	
	1/4	5.6	141	1.13	29	75912	10		75712	2	
	5/16	6.0	152	1.25	32	75913	10		75713	2	
LONG Metric	3/8	6.8	171	1.38	35	75914	10		75714	2	
	1.27	2.8	72	0.53	13	75949	25		75749	5	
	1.5	3.0	77	0.53	14	75950	25		75750	5	
	2.0	3.2	82	0.61	16	75952	25		75752	5	
	2.5	3.5	88	0.69	17	75954	25		75754	5	
	3.0	3.9	98	0.75	19	75956	25		75756	5	
	4.0	4.3	110	0.87	22	75960	25		75760	5	
	5.0	4.7	119	1.06	27	75964	25		75764	2	
	6	5.5	139	1.22	31	75968	10		75768	2	
	8	6.0	152	1.38	35	75972	10		75772	2	
	10	6.7	171	1.54	39	75976	10		75776	2	

Did you know...?

ProHold® buttons are non-magnetic and work on all fasteners. They are safe to use on sensitive equipment. They will not rust and will hold non-magnetic screws (aluminum, stainless and plastic).



ProHold® button holds screw
tight on the tool EVERY TIME

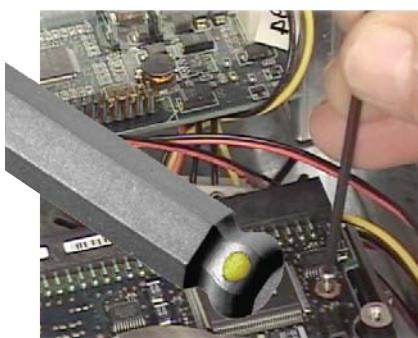


ProHold® buttons are non-magnetic and
safe for use in electronic applications

Stubby Ball End L-Wrenches

- ProGuard™ Finish -

- Fits into tight spaces standard hex keys can not
- Eliminates the need to trim and file the short arm
- Tighter inside radius means full smooth entry into screw head
- Chamfered short arm eliminates burrs
- Ball End inserts into a screw at a 25° angle

 ProGuard™ finish delivers superior corrosion protection



L-Wrenches

Yellow=Inch
Red=Metric

Stubby fits where others can not

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	16538	SBLX10	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	16537	SBLX13	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	16592	SBLX7M	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	16599	SBLX9M	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	



SINGLE PACKAGING
BULK





TAGGED/BARCODED



16599

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA
LONG Inch	.050	2.8	72	0.14	4	26502	50		16502	5	
	1/16	3.0	76	0.16	4	26503	50		16503	5	
	5/64	3.2	81	0.27	7	26504	50		16504	5	
	3/32	3.4	86	0.29	7	26505	50		16505	5	
	7/64	3.6	90	0.30	8	26506	50		16506	5	
	1/8	3.8	95	0.32	8	26507	50		16507	5	
	9/64	4.0	101	0.33	8	26508	50		16508	5	
	5/32	4.2	107	0.35	9	26509	50		16509	5	
	3/16	4.5	114	0.39	10	26510	50		16510	5	
	7/32	4.9	124	0.46	12	26511	25		16511	2	
	1/4	5.3	133	0.46	12	26512	25		16512	2	
	5/16	6.0	152	0.57	14	26513	25		16513	2	
	3/8	6.8	171	0.71	18	26514	25		16514	2	
LONG Metric	1.27	2.8	72	0.14	4	26549	50		16549	5	
	1.5	3.0	77	0.19	5	26550	50		16550	5	
	2.0	3.2	82	0.27	7	26552	50		16552	5	
	2.5	3.5	88	0.28	7	26554	50		16554	5	
	3.0	3.9	98	0.32	8	26556	50		16556	5	
	4.0	4.3	110	0.35	9	26560	50		16560	5	
	5.0	4.7	119	0.40	10	26564	25		16564	2	
	6	5.5	139	0.47	12	26568	25		16568	2	
	8	6.0	152	0.57	14	26572	25		16572	2	
	10	6.7	171	0.78	20	26576	25		16576	2	

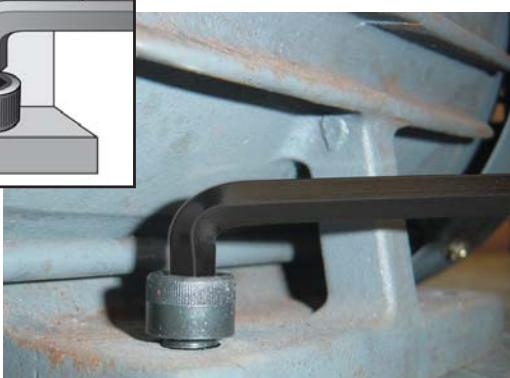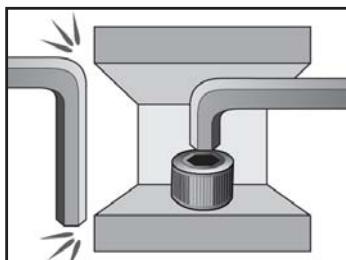


Stubby tools fit in tight spaces where there is not enough overhead clearance for a standard hex key

Hex End L-Wrenches

- ProGuard™ Finish -

- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit


ProGuard™ finish delivers superior corrosion protection

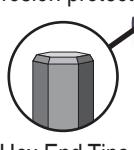

Long

Yellow=Inch

Red=Metric

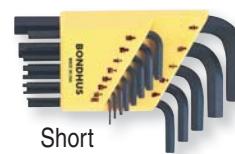

Short

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	12145	HLX7	7	Long	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"	1	
	12132	HLX8	8	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1	
	12138	HLX10	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	12136	HLX12	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	12137	HLX13	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	12245	HLX7S	7	Short	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"	1	
	12232	HLX8S	8	Short	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1	
	12238	HLX10S	10	Short	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	12236	HLX12S	12	Short	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	12237	HLX13S	13	Short	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	

In Metal Box

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	12342	MHLX13	13	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2"	1	
	12344	MHLX15S	15	Short	.028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	12339	MHLX18S	18	Short	.028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2, 9/16, 5/8"	1	12344

In Pouch

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	12335	PHLX9	9	Long	5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	12333	PHLX11	11	Long	.050, 1/16, 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	12351	PHLX15	15	Long	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2 9/16, 5/8, 3/4"	1	
	12345	PHLX7S	7	Short	5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4"	1	
	12338	PHLX10S	10	Short	.035, .050, 1/16, 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4 "	1	
	12341	PHLX11SS	11	Short	.050, 1/16, 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	12343	PHLX11S	11	Short	5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2, 9/16"	1	
	12347	PHLX15S	15	Short	.028, .035, .050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	12347
	22789	PHLX9-6	9	6" Long Arm	5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	25445	PHLX7-12	7	12" Long Arm	5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4"	1	

Singles	SIZE	INCH	MM	INCH	MM	SINGLE PACKAGING		
						PART#	QTY	LIST EA
6" LONG ARM Inch	5/64	5.9	150	0.61	15	22704	5	
	3/32	5.9	150	0.65	16	22705	5	
	7/64	5.9	150	0.70	18	22706	5	
	1/8	5.9	149	0.75	19	22707	5	
	9/64	5.9	149	0.80	20	22708	5	
	5/32	5.8	148	0.84	21	22709	5	
	3/16	5.8	148	0.94	24	22710	5	
	7/32	5.8	147	1.03	26	22711	5	
	1/4	5.8	146	1.13	29	22712	5	
	5/16	5.7	144	1.25	32	22713	5	
	3/8	5.6	143	1.38	35	22714	5	

Singles	SIZE	INCH	MM	INCH	MM	SINGLE PACKAGING		
						PART#	QTY	LIST EA
12" LONG ARM Inch	5/64	11.9	303	0.61	15	25404	5	
	3/32	11.9	302	0.65	16	25405	5	
	7/64	11.9	302	0.70	18	25406	5	
	1/8	11.9	302	0.75	19	25407	5	
	9/64	11.9	301	0.80	20	25408	5	
	5/32	11.8	301	0.84	21	25409	5	
	3/16	11.8	300	0.94	24	25410	5	
	7/32	11.8	299	1.03	26	25411	5	
	1/4	11.8	298	1.13	29	25412	5	

For more individual sizes available packaged, in bulk, or singles
see page 11

Hex End L-Wrench Singles

 
- ProGuard™ Finish -

- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish
delivers superior
corrosion protection



L-Wrenches



Hex End Tips



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA	PART#	QTY	LIST EA
LONG Inch	.028	2.6	66	0.22	6	12100	10		13900	100		15900	10	
	.035	2.7	68	0.34	9	12101	10		13901	100		15901	10	
	.050	2.8	72	0.53	13	12102	10		13902	100		15902	10	
	1/16	3.0	76	0.56	14	12103	10		13903	100		15903	10	
	5/64	3.2	81	0.61	15	12104	10		13904	100		15904	10	
	3/32	3.4	86	0.65	16	12105	10		13905	100		15905	10	
	7/64	3.6	90	0.70	18	12106	10		13906	100		15906	10	
	1/8	3.8	95	0.75	19	12107	10		13907	100		15907	10	
	9/64	4.0	101	0.80	20	12108	10		13908	100		15908	10	
	5/32	4.2	107	0.84	21	12109	10		13909	100		15909	10	
	3/16	4.5	114	0.94	24	12110	10		13910	100		15910	10	
	7/32	4.9	124	1.03	26	12111	5		13911	50		15911	5	
	1/4	5.3	133	1.13	29	12112	5		13912	50		15912	5	
	5/16	6.0	152	1.25	32	12113	5		13913	50		15913	5	
	3/8	6.8	171	1.38	35	12114	5		13914	50		15914	5	
	7/16	7.5	191	1.50	38	12115	1		13915	25		15915	1	
	1/2	8.3	210	1.63	41	12116	1		13916	25		15916	1	
	9/16	9.0	229	1.75	44	12117	1		13917	10		15917	1	
	5/8	9.8	248	1.88	48	12118	1		13918	10		15918	1	
	3/4	11.3	286	2.13	54	12119	1		13919	5		15919	1	
	7/8	12.7	322	2.37	60	12120	1		-	-		-	-	
	1	14.1	359	2.62	67	12121	1		-	-		-	-	
	1 1/4	17.0	432	3.00	76	12125	1		-	-		-	-	
	1 1/2	20.3	514	3.50	89	12129	1		-	-		-	-	



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA	PART#	QTY	LIST EA
SHORT Inch	.028	1.2	31	0.22	6	12200	10		13800	100		15800	10	
	.035	1.2	31	0.34	9	12201	10		13801	100		15801	10	
	.050	1.6	42	0.53	13	12202	10		13802	100		15802	10	
	1/16	1.8	45	0.56	14	12203	10		13803	100		15803	10	
	5/64	1.9	48	0.61	15	12204	10		13804	100		15804	10	
	3/32	2.0	51	0.65	16	12205	10		13805	100		15805	10	
	7/64	2.1	54	0.70	18	12206	10		13806	100		15806	10	
	1/8	2.3	58	0.75	19	12207	10		13807	100		15807	10	
	9/64	2.4	61	0.80	20	12208	10		13808	100		15808	10	
	5/32	2.5	64	0.84	21	12209	10		13809	100		15809	10	
	3/16	2.8	70	0.94	24	12210	10		13810	100		15810	10	
	7/32	3.0	77	1.03	26	12211	5		13811	50		15811	5	
	1/4	3.3	83	1.13	29	12212	5		13812	50		15812	5	
	5/16	3.8	96	1.25	32	12213	5		13813	50		15813	5	
	3/8	4.3	108	1.38	35	12214	5		13814	50		15814	5	
	7/16	4.8	121	1.50	38	12215	1		13815	50		15815	1	
	1/2	5.3	133	1.63	41	12216	1		13816	50		15816	1	
	9/16	5.8	146	1.75	44	12217	1		13817	25		15817	1	
	5/8	6.3	159	1.88	48	12218	1		13818	20		15818	1	
	3/4	7.3	184	2.13	54	12219	1		13819	15		15819	1	
	7/8	8.2	207	2.37	60	12220	1		-	-		-	-	
	1	9.2	232	2.62	67	12221	1		-	-		-	-	
	1 1/4	11.0	279	3.00	76	12225	1		-	-		-	-	
	1 1/2	13.0	330	3.50	89	12229	1		-	-		-	-	
	1 3/4	13.3	337	4.00	102	12231	1		-	-		-	-	
	2	15.0	381	4.50	114	12233	1		-	-		-	-	


For sets and 6" and 12" Long Arm singles see page 10

Hex End L-Wrenches

- ProGuard™ Finish -

- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish
delivers superior
corrosion protection

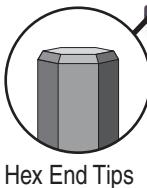

Long

Yellow=Inch
Red=Metric



Short

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Metric	12146	HLX6M	6	Long	1.5, 2, 2.5, 3, 4, 5mm	1	
	12192	HLX7M	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	12199	HLX9M	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	12195	HLX15M	15	Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1	
	12246	HLX6MS	6	Short	1.5, 2, 2.5, 3, 4, 5mm	1	
	12292	HLX7MS	7	Short	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	12299	HLX9MS	9	Short	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

In Metal Box

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Metric	12396	MHLX10M	10	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10, 12mm	1	
	12393	MHLX12MS	12	Short	.71, .89, 1.27, 1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	12394	MHLX15MS	15	Short	.71, .89, 1.27, 1.5, 2, 2.5, 3, 4, 5, 6, 8, 10, 12, 14, 17mm	1	



12394

In Pouch

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Metric	12349	PHLX15M	15	Long	.89, 1.27, 1.5, 2, 2.5, 3, 4, 5, 6, 8, 10, 12, 14, 17, 19mm	1	
	12392	PHLX7MS	7	Short	2, 2.5, 3, 4, 5, 6, 8mm	1	
	12399	PHLX9MS	9	Short	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	12391	PHLX11MS	11	Short	2, 2.5, 3, 4, 5, 6, 7, 8, 9, 10, 12mm	1	
	12397	PHLX14MS	14	Short	2, 2.5, 3, 4, 5, 6, 7, 8, 9, 10, 12, 14, 17, 19mm	1	



12397

Did you know...?

Bondhus tools are harder and more ductile than competitors' tools. They wear longer, generate greater torque and resist breakage and shattering.

For individual sizes available packaged, in bulk, or singles
see page 13

Hex End L-Wrench Singles

- ProGuard™ Finish -

- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish
delivers superior
corrosion protection



L-Wrenches



Hex End Tips

Singles	SIZE	INCH		MM		PART#	QTY	LIST EA	PART#	QTY	LIST EA	PART#	QTY	LIST EA
		PACKAGED	SINGLE PACKAGING	BULK	TAGGED/BARCODED									
LONG Metric	0.71	2.6	66	0.22	6	12147	10		13947	100		15947	10	
	0.89	2.7	68	0.34	9	12148	10		13948	100		15948	10	
	1.27	2.8	72	0.53	13	12149	10		13949	100		15949	10	
	1.5	3.0	77	0.53	14	12150	10		13950	100		15950	10	
	2.0	3.2	82	0.61	16	12152	10		13952	100		15952	10	
	2.5	3.5	88	0.69	17	12154	10		13954	100		15954	10	
	3.0	3.9	98	0.75	19	12156	10		13956	100		15956	10	
	3.5	3.9	100	0.85	21	12158	1		13958	100		15958	1	
	4.0	4.3	110	0.87	22	12160	10		13960	100		15960	10	
	4.5	4.5	114	1.00	25	12162	1		13962	100		15962	1	
	5.0	4.7	119	1.06	27	12164	5		13964	100		15964	5	
	5.5	4.9	124	1.14	29	12166	1		13966	50		15966	1	
	6	5.5	139	1.22	31	12168	5		13968	50		15968	5	
	7	5.5	140	1.30	33	12170	1		13970	50		15970	1	
	8	6.0	152	1.38	35	12172	5		13972	50		15972	5	
	9	6.2	159	1.46	37	12174	1		13974	50		15974	1	
	10	6.7	171	1.54	39	12176	5		13976	50		15976	5	
	11	7.9	200	1.63	42	12178	1		13978	25		15978	1	
	12	8.7	220	1.73	44	12180	1		13980	25		15980	1	
	14	10.2	260	2.15	55	12184	1		13984	10		15984	1	
	17	11.0	280	2.42	61	12186	1		13986	10		15986	1	
	19	11.6	295	2.70	69	12188	1		13988	5		15988	1	
	22	12.8	325	3.07	78	12191	1		-	-		-	-	
	24	14.3	364	3.47	88	12193	1		-	-		-	-	
	32	17.0	432	4.80	122	12196	1		-	-		-	-	
	36	20.3	516	5.37	137	12198	1		-	-		-	-	

Singles	SIZE	INCH		MM		PART#	QTY	LIST EA	PART#	QTY	LIST EA	PART#	QTY	LIST EA
		PACKAGED	SINGLE PACKAGING	BULK	TAGGED/BARCODED									
SHORT Metric	0.71	1.2	31	0.22	6	12247	10		13847	100		15847	10	
	0.89	1.2	31	0.34	9	12248	10		13848	100		15848	10	
	1.27	1.6	42	0.53	13	12249	10		13849	100		15849	10	
	1.5	1.7	44	0.53	14	12250	10		13850	100		15850	10	
	2.0	1.9	49	0.61	16	12252	10		13852	100		15852	10	
	2.5	2.1	54	0.69	17	12254	10		13854	100		15854	10	
	3.0	2.4	61	0.75	19	12256	10		13856	100		15856	10	
	3.5	2.6	65	0.85	21	12258	1		13858	100		15858	1	
	4.0	2.7	68	0.87	22	12260	10		13860	100		15860	10	
	4.5	2.9	73	1.00	25	12262	1		13862	100		15862	1	
	5.0	3.1	78	1.06	27	12264	5		13864	100		15864	5	
	5.5	3.3	83	1.14	29	12266	1		13866	50		15866	1	
	6	3.5	88	1.22	31	12268	5		13868	50		15868	5	
	7	3.7	93	1.30	33	12270	1		13870	50		15870	1	
	8	3.9	98	1.38	35	12272	5		13872	50		15872	5	
	9	4.0	102	1.46	37	12274	1		13874	50		15874	1	
	10	4.3	109	1.54	39	12276	5		13876	50		15876	5	
	11	4.5	115	1.63	42	12278	1		13878	50		15878	1	
	12	4.8	122	1.73	44	12280	1		13880	50		15880	1	
	14	5.4	136	2.15	55	12284	1		13884	25		15884	1	
	17	6.1	156	2.42	61	12286	1		13886	20		15886	1	
	19	6.9	175	2.72	69	12288	1		13888	15		15888	1	
	22	7.5	190	3.07	78	12291	1		-	-		-	-	
	24	8.4	213	3.47	88	12293	1		-	-		-	-	
	27	9.4	238	3.84	98	12295	1		-	-		-	-	
	32	11.8	300	4.80	122	12296	1		-	-		-	-	
	36	13.3	338	5.37	137	12298	1		-	-		-	-	

For sets see page 12

Tamper Resistant Hex End L-Wrenches

- ProGuard™ Finish -

- Fits all tamper resistant hex screws
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish
delivers superior
corrosion protection



Tamper Resistant
Hex Tips



Tamper Resistant
Hex Tips

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	48332	HTR8	8	Long	3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	48386	HTR6M	6	Long	2.5, 3, 4, 5, 6, 8mm	1	



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
LONG Inch	3/32	3.4	86	0.65	16	48305	5	
	1/8	3.8	95	0.75	19	48307	5	
	5/32	4.2	107	0.84	21	48309	5	
	3/16	4.5	114	0.94	24	48310	5	
	7/32	4.9	124	1.03	26	48311	5	
	1/4	5.3	133	1.13	29	48312	5	
	5/16	6.0	152	1.25	32	48313	5	
	3/8	6.8	171	1.38	35	48314	2	
LONG Metric	2.5	3.5	88	0.69	17	48354	5	
	3.0	3.9	98	0.75	19	48356	5	
	4.0	4.3	110	0.87	22	48360	5	
	5.0	4.7	119	1.06	27	48364	5	
	6	5.5	139	1.22	31	48368	5	
	8	6.0	152	1.38	35	48372	5	
	10	6.7	171	1.54	39	48376	2	



48332

Tamper Resistant Star Tip L-Wrenches

- ProGuard™ Finish -

- Fits all Star and TORX® brand tamper resistant screws
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish
delivers superior
corrosion protection



Tools are in color
coded cases for easy
recognition
Green=Star



Tamper Resistant
Star Tips



Tamper Resistant
Star Tips

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Star	32432	TR-TL8S	8	Long	TR6, TR7, TR8, TR9, TR10, TR15, TR20, TR25	1	
	32434	TR-TL8	8	Long	TR9, TR10, TR15, TR20, TR25, TR27, TR30, TR40	1	



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA
LONG Star	TR6	2.1	55	0.65	16	33406	25		32406	2	
	TR7	2.4	61	0.65	16	33407	25		32407	2	
	TR8	2.6	67	0.65	16	33408	25		32408	2	
	TR9	2.9	74	0.65	16	33409	25		32409	2	
	TR10	3.2	80	0.73	19	33410	25		32410	2	
	TR15	3.3	84	0.78	20	33415	25		32415	2	
	TR20	3.6	91	0.78	20	33420	25		32420	2	
	TR25	3.8	98	0.88	22	33425	25		32425	2	
	TR27	4.2	106	0.95	24	33427	25		32427	2	
	TR30	4.6	116	1.03	26	33430	25		32430	2	
	TR40	4.9	125	1.11	28	33440	25		32440	2	

Did you know...?

 
ProGuard™ Dry Surface Technology is the world's best corrosion protection. The tool user does not have to work with rusty tools. ProGuard™ protection delivers up to 5 times the corrosion resistance of any other Hex or Star Tip tool finish.

*TORX® is a registered trademark of Acument Intellectual Properties, LLC

Ball End L-Wrenches

- BriteGuard™ Finish -

- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- 25° angle allows natural hand and wrist movement
- Superior Ball End strength and working angle
- Works in hard to reach places



BriteGuard™ finish delivers superior corrosion protection



L-Wrenches

Yellow=Inch
Red=Metric




25° Working angle

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	16938	BLX10B	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	16936	BLX12B	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	16937	BLX13B	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	17046	BLX6MB	6	Extra Long	1.5, 2, 2.5, 3, 4, 5mm	1	
	17092	BLX7MB	7	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	17099	BLX9MB	9	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	17095	BLX15MB	15	Extra Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1	



Singles	SIZE	INCH		MM		PART#	QTY	LIST EA	SINGLE PACKAGING			TAGGED/BARCODED			
		BULK	TAGGED	INCH	MM				BULK	TAGGED	INCH	MM	PART#	QTY	LIST EA
LONG Inch	.050	2.8	72	0.53	13	26902	50				16902	10			
	1/16	3.0	76	0.56	14	26903	50				16903	10			
	5/64	3.2	81	0.61	15	26904	50				16904	10			
	3/32	3.4	86	0.65	16	26905	50				16905	10			
	7/64	3.6	90	0.70	18	26906	50				16906	10			
	1/8	3.8	95	0.75	19	26907	50				16907	10			
	9/64	4.0	101	0.80	20	26908	50				16908	10			
	5/32	4.2	107	0.84	21	26909	50				16909	10			
	3/16	4.5	114	0.94	24	26910	50				16910	10			
	7/32	4.9	124	1.03	26	26911	25				16911	5			
	1/4	5.6	141	1.13	29	26912	25				16912	5			
	5/16	6.0	152	1.25	32	26913	25				16913	5			
	3/8	6.8	171	1.38	35	26914	25				16914	5			
	7/16	7.5	191	1.50	38		-	-			16915	1			
	1/2	8.3	210	1.63	41		-	-			16916	1			
	9/16	9.0	229	1.75	44		-	-			16917	1			
	5/8	9.8	248	1.88	48		-	-			16918	1			
	3/4	11.3	286	2.13	54		-	-			16919	1			
EXTRA LONG Metric	1.27	2.8	72	0.53	13	27049	50				17049	10			
	1.5	3.5	90	0.53	14	27050	50				17050	10			
	2.0	3.9	100	0.61	16	27052	50				17052	10			
	2.5	4.4	112	0.69	17	27054	50				17054	10			
	3.0	5.0	126	0.75	19	27056	50				17056	10			
	3.5	5.2	133	0.85	21	27058	50				17058	1			
	4.0	5.6	142	0.87	22	27060	50				17060	10			
	4.5	5.9	151	1.00	25	27062	50				17062	1			
	5.0	6.3	160	1.06	27	27064	50				17064	5			
	5.5	6.8	172	1.14	29	27066	25				17066	1			
	6	6.8	172	1.22	31	27068	25				17068	5			
	7	7.2	184	1.30	33	27070	25				17070	1			
	8	7.7	195	1.38	35	27072	25				17072	5			
	9	8.0	202	1.46	37	27074	25				17074	1			
	10	8.4	213	1.54	39	27076	10				17076	5			
	11	7.9	200	1.63	42	27078	10				17078	1			
	12	8.7	220	1.73	44	27080	10				17080	1			
	14	10.2	260	2.15	55		-	-			17084	1			
	17	11.0	280	2.42	61		-	-			17086	1			
	19	11.6	295	2.70	69		-	-			17088	1			

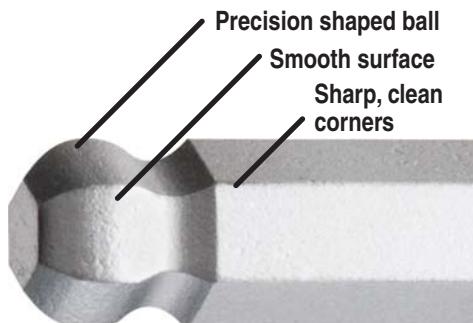

Did you know...?

Bondhus Ball End tools feature a consistent 25° working angle. The Ball End feature saves time and tool users can absolutely count on every Bondhus Ball End tool to provide a 25° working angle. Period!

Stubby Ball End L-Wrenches

- BriteGuard™ Finish -

- Fits into tight spaces standard hex keys can not
- Eliminates the need to trim and file the short arm
- Tighter inside radius means full smooth entry into screw head
- Chamfered short arm eliminates burrs
- Ball End inserts into a screw at a 25° angle

BriteGuard™ finish delivers superior corrosion protection



L-Wrenches

Yellow=Inch

Red=Metric



Ball End Tips



Stubby fits where others can not

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	16738	SBLX10B	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	16737	SBLX13B	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	16792	SBLX7MB	7	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	16799	SBLX9MB	9	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

SINGLE PACKAGING

BULK



TAGGED/BARCODED


Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA
LONG Inch	.050	2.7	69	0.14	4	26702	50		16702	5	
	1/16	2.8	72	0.16	4	26703	50		16703	5	
	5/64	2.9	74	0.27	7	26704	50		16704	5	
	3/32	3.1	78	0.29	7	26705	50		16705	5	
	7/64	3.3	83	0.30	8	26706	50		16706	5	
	1/8	3.4	87	0.32	8	26707	50		16707	5	
	9/64	3.6	92	0.33	8	26708	50		16708	5	
	5/32	3.9	98	0.35	9	26709	50		16709	5	
	3/16	4.1	104	0.39	10	26710	50		16710	5	
	7/32	4.4	112	0.46	12	26711	25		16711	2	
	1/4	5.1	129	0.46	12	26712	25		16712	2	
	5/16	5.4	138	0.57	14	26713	25		16713	2	
	3/8	6.0	153	0.71	18	26714	25		16714	2	
EXTRA LONG Metric	1.27	2.7	69	0.14	4	26749	50		16749	5	
	1.5	3.5	90	0.19	5	26750	50		16750	5	
	2.0	3.9	100	0.27	7	26752	50		16752	5	
	2.5	4.4	112	0.28	7	26754	50		16754	5	
	3.0	5.0	126	0.32	8	26756	50		16756	5	
	4.0	5.6	142	0.35	9	26760	50		16760	5	
	5.0	6.3	160	0.40	10	26764	25		16764	2	
	6	6.8	172	0.47	12	26768	25		16768	2	
	8	7.7	195	0.57	14	26772	25		16772	2	
	10	8.4	213	0.78	20	26776	25		16776	2	



16799

Did you know...?

Stubby tools have a tighter inside radius than standard hex keys, which saves time because the tight radius design reaches screws that even a hex key with a cut down short arm can not.

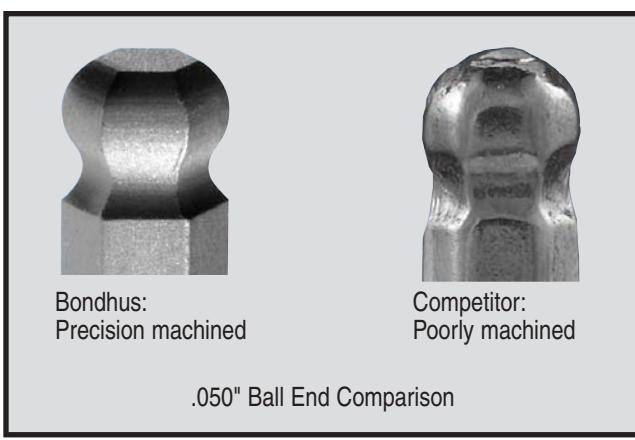

.050" Ball End Comparison

Hex End L-Wrenches

- BriteGuard™ Finish -

- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

BriteGuard™ finish
delivers superior
corrosion protection



L-Wrenches

Yellow=Inch
Red=Metric



Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	16138	HLX10B	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	16136	HLX12B	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	16137	HLX13B	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	16238	HLX10SB	10	Short	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	16236	HLX12SB	12	Short	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	16237	HLX13SB	13	Short	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	17146	HLX6MB	6	Extra Long	1.5, 2, 2.5, 3, 4, 5mm	1	
	17192	HLX7MB	7	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	17199	HLX9MB	9	Extra Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	17195	HLX15MB	15	Extra Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1	
	16246	HLX6MSB	6	Short	1.5, 2, 2.5, 3, 4, 5mm	1	
	16292	HLX7MSB	7	Short	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	16299	HLX9MSB	9	Short	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

SINGLE PACKAGING



BULK



TAGGED/BARCODED

SINGLE PACKAGING



BULK



TAGGED/BARCODED

Singles	SIZE INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA	SIZE INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA
Inch	Long																			
	.028	2.6	66	0.22	6	26100	50	16100	10		.028	1.2	31	0.22	6	26200	50	16200	10	
	.035	2.7	68	0.34	9	26101	50	16101	10		.035	1.2	31	0.34	9	26201	50	16201	10	
	.050	2.8	72	0.53	13	26102	50	16102	10		.050	1.6	42	0.53	13	26202	50	16202	10	
	1/16	3.0	76	0.56	14	26103	50	16103	10		1/16	1.8	45	0.56	14	26203	50	16203	10	
	5/64	3.2	81	0.61	15	26104	50	16104	10		5/64	1.9	48	0.61	15	26204	50	16204	10	
	3/32	3.4	86	0.65	16	26105	50	16105	10		3/32	2.0	51	0.65	16	26205	50	16205	10	
	7/64	3.6	90	0.70	18	26106	50	16106	10		7/64	2.1	54	0.70	18	26206	50	16206	10	
	1/8	3.8	95	0.75	19	26107	50	16107	10		1/8	2.3	58	0.75	19	26207	50	16207	10	
	9/64	4.0	101	0.80	20	26108	50	16108	10		9/64	2.4	61	0.80	20	26208	50	16208	10	
	5/32	4.2	107	0.84	21	26109	50	16109	10		5/32	2.5	64	0.84	21	26209	50	16209	10	
	3/16	4.5	114	0.94	24	26110	50	16110	10		3/16	2.8	70	0.94	24	26210	50	16210	10	
	7/32	4.9	124	1.03	26	26111	25	16111	5		7/32	3.0	77	1.03	26	26211	25	16211	5	
	1/4	5.3	133	1.13	29	26112	25	16112	5		1/4	3.3	83	1.13	29	26212	25	16212	5	
	5/16	6.0	152	1.25	32	26113	25	16113	5		5/16	3.8	96	1.25	32	26213	25	16213	5	
	3/8	6.8	171	1.38	35	26114	25	16114	5		3/8	4.3	108	1.38	35	26214	25	16214	5	
	7/16	7.5	191	1.50	38		-	16115	1		7/16	4.8	121	1.50	38		-	16215	1	
	1/2	8.3	210	1.63	41		-	16116	1		1/2	5.3	133	1.63	41		-	16216	1	
	9/16	9.0	229	1.75	44		-	16117	1		9/16	5.8	146	1.75	44		-	16217	1	
	5/8	9.8	248	1.88	48		-	16118	1		5/8	6.3	159	1.88	48		-	16218	1	
	3/4	11.3	286	2.13	54		-	16119	1		3/4	7.3	184	2.13	54		-	16219	1	
Metric	Extra Long																			
	.71	2.6	66	0.22	6	27147	50	17147	10		.71	1.2	31	0.22	6	26247	50	16247	10	
	.89	2.7	68	0.34	9	27148	50	17148	10		.89	1.2	31	0.34	9	26248	50	16248	10	
	1.27	2.8	72	0.53	13	27149	50	17149	10		1.27	1.6	42	0.53	13	26249	50	16249	10	
	1.5	3.5	90	0.53	14	27150	50	17150	10		1.5	1.7	44	0.53	14	26250	50	16250	10	
	2.0	3.9	100	0.61	16	27152	50	17152	10		2.0	1.9	49	0.61	16	26252	50	16252	10	
	2.5	4.4	112	0.69	17	27154	50	17154	10		2.5	2.1	54	0.69	17	26254	50	16254	10	
	3.0	5.0	126	0.75	19	27156	50	17156	10		3.0	2.4	61	0.75	19	26256	50	16256	10	
	3.5	5.2	133	0.85	21	27158	50	17158	1		3.5	2.6	65	0.85	21	26258	50	16258	1	
	4.0	5.6	142	0.87	22	27160	50	17160	10		4.0	2.7	68	0.87	22	26260	50	16260	10	
	4.5	5.9	151	1.00	25	27162	50	17162	1		4.5	2.9	73	1.00	25	26262	50	16262	1	
	5.0	6.3	160	1.06	27	27164	50	17164	5		5.0	3.1	78	1.06	27	26264	50	16264	5	
	5.5	6.8	172	1.14	29	27166	25	17166	1		5.5	3.3	83	1.14	29	26266	25	16266	1	
	6	6.8	172	1.22	31	27168	25	17168	5		6	3.5	88	1.22	31	26268	25	16268	5	
	7	7.2	184	1.30	33	27170	25	17170	1		7	3.7	93	1.30	33	26270	25	16270	1	
	8	7.7	195	1.38	35	27172	25	17172	5		8	3.9	98	1.38	35	26272	25	16272	5	
	9	8.0	202	1.46	37	27174	25	17174	1		9	4.0	102	1.46	37	26274	25	16274	1	
	10	8.4	213	1.54	39	27176	10	17176	5		10	4.3	109	1.54	39	26276	10	16276	5	
	11	7.9	200	1.63	42	27178	10	17178	1		11	4.5	115	1.63	42	26278	10	16278	1	
	12	8.7	220	1.73	44	27180	10	17180	1		12	4.8	122	1.73	44	26280	10	16280	1	
	14	10.2	260	2.15	55		-	17184	1		14	5.4	136	2.15	55		-	16284	1	
	17	11.0	280	2.42	61		-	17186	1		17	6.1	156	2.42	61		-	16286	1	
	19	11.6	295	2.70	69		-	17188	1		19	6.9	175	2.72	69		-	16288	1	


 
Ball End L-Wrenches

L-Wrenches

- GoldGuard™ Finish -

- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- 25° angle allows natural hand and wrist movement
- Superior Ball End strength and working angle
- Works in hard to reach places

GoldGuard™ finish.
Real 14 karat Gold

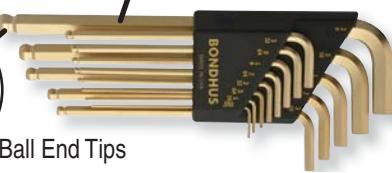

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	37938	BLX10G	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	37936	BLX12G	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	37937	BLX13G	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	38046	BLX6MG	6	Long	1.5, 2, 2.5, 3, 4, 5mm	1	
	38092	BLX7MG	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	38099	BLX9MG	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	38095	BLX15MG	15	Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1	



SINGLE PACKAGING

BULK



TAGGED/BARCODED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA
LONG Inch	.050	2.8	72	0.53	13	27902	50		37902	10	
	1/16	3.0	76	0.56	14	27903	50		37903	10	
	5/64	3.2	81	0.61	15	27904	50		37904	10	
	3/32	3.4	86	0.65	16	27905	50		37905	10	
	7/64	3.6	90	0.70	18	27906	50		37906	10	
	1/8	3.8	95	0.75	19	27907	50		37907	10	
	9/64	4.0	101	0.80	20	27908	50		37908	10	
	5/32	4.2	107	0.84	21	27909	50		37909	10	
	3/16	4.5	114	0.94	24	27910	50		37910	10	
	7/32	4.9	124	1.03	26	27911	25		37911	5	
	1/4	5.6	141	1.13	29	27912	25		37912	5	
	5/16	6.0	152	1.25	32	27913	25		37913	5	
	3/8	6.8	171	1.38	35	27914	25		37914	5	
	7/16	7.5	191	1.50	38		-	-	37915	1	
	1/2	8.3	210	1.63	41		-	-	37916	1	
	9/16	9.0	229	1.75	44		-	-	37917	1	
	5/8	9.8	248	1.88	48		-	-	37918	1	
	3/4	11.3	286	2.13	54		-	-	37919	1	

LONG Metric	1.27	2.8	72	0.53	13	28049	50		38049	10	
	1.5	3.0	77	0.53	14	28050	50		38050	10	
	2.0	3.2	82	0.61	16	28052	50		38052	10	
	2.5	3.5	88	0.69	17	28054	50		38054	10	
	3.0	3.9	98	0.75	19	28056	50		38056	10	
	3.5	3.9	100	0.85	21	28058	50		38058	1	
	4.0	4.3	110	0.87	22	28060	50		38060	10	
	4.5	4.5	114	1.00	25	28062	50		38062	1	
	5.0	4.7	119	1.06	27	28064	50		38064	5	
	5.5	4.9	124	1.14	29	28066	25		38066	1	
	6	5.5	139	1.22	31	28068	25		38068	5	
	7	5.5	140	1.30	33	28070	25		38070	1	
	8	6.0	152	1.38	35	28072	25		38072	5	
	9	6.2	159	1.46	37	28074	25		38074	1	
	10	6.7	171	1.54	39	28076	10		38076	5	
	11	7.9	200	1.63	42	28078	10		38078	1	
	12	8.7	220	1.73	44	28080	10		38080	1	
	14	10.2	260	2.15	55		-	-	38084	1	
	17	11.0	280	2.42	61		-	-	38086	1	
	19	11.6	295	2.70	69		-	-	38088	1	

Did you know...?
Protanium® Steel tools are up to 20% stronger than competitor tools made from standard grades of steel.

Hex End L-Wrenches

- GoldGuard™ Finish -


- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

GoldGuard™ finish.
Real 14 karat Gold



L-Wrenches

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	38138	HLX10G	10	Long	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	38136	HLX12G	12	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	38137	HLX13G	13	Long	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	38238	HLX10SG	10	Short	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	38236	HLX12SG	12	Short	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	38237	HLX13SG	13	Short	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	39146	HLX6MG	6	Long	1.5, 2, 2.5, 3, 4, 5mm	1	
	39192	HLX7MG	7	Long	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	39199	HLX9MG	9	Long	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	39195	HLX15MG	15	Long	1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 7, 8, 9, 10mm	1	
	38246	HLX6MSG	6	Short	1.5, 2, 2.5, 3, 4, 5mm	1	
	38292	HLX7MSG	7	Short	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	38299	HLX9MSG	9	Short	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

 

Sets	SINGLE PACKAGING						SINGLE PACKAGING						SINGLE PACKAGING						
	BULK			TAGGED / BARCODED			BULK			TAGGED / BARCODED			BULK			TAGGED / BARCODED			
	SIZE INCH	MM	INCH	MM	PART#	QTY	LIST EA		SIZE INCH	MM	INCH	MM	PART#	QTY	LIST EA		PART#	QTY	LIST EA
Singles	Long						Short						Long						
	Inch	.028	2.6	66	0.22	6	28100	50	.38100	10	.028	1.2	31	0.22	6	28200	50	38200	10
		.035	2.7	68	0.34	9	28101	50	.38101	10	.035	1.2	31	0.34	9	28201	50	38201	10
		.050	2.8	72	0.53	13	28102	50	.38102	10	.050	1.6	42	0.53	13	28202	50	38202	10
		1/16	3.0	76	0.56	14	28103	50	.38103	10	1/16	1.8	45	0.56	14	28203	50	38203	10
		5/64	3.2	81	0.61	15	28104	50	.38104	10	5/64	1.9	48	0.61	15	28204	50	38204	10
		3/32	3.4	86	0.65	16	28105	50	.38105	10	3/32	2.0	51	0.65	16	28205	50	38205	10
		7/64	3.6	90	0.70	18	28106	50	.38106	10	7/64	2.1	54	0.70	18	28206	50	38206	10
		1/8	3.8	95	0.75	19	28107	50	.38107	10	1/8	2.3	58	0.75	19	28207	50	38207	10
		9/64	4.0	101	0.80	20	28108	50	.38108	10	9/64	2.4	61	0.80	20	28208	50	38208	10
		5/32	4.2	107	0.84	21	28109	50	.38109	10	5/32	2.5	64	0.84	21	28209	50	38209	10
		3/16	4.5	114	0.94	24	28110	50	.38110	10	3/16	2.8	70	0.94	24	28210	50	38210	10
		7/32	4.9	124	1.03	26	28111	25	.38111	5	7/32	3.0	77	1.03	26	28211	25	38211	5
		1/4	5.3	133	1.13	29	28112	25	.38112	5	1/4	3.3	83	1.13	29	28212	25	38212	5
		5/16	6.0	152	1.25	32	28113	25	.38113	5	5/16	3.8	96	1.25	32	28213	25	38213	5
		3/8	6.8	171	1.38	35	28114	25	.38114	5	3/8	4.3	108	1.38	35	28214	25	38214	5
		7/16	7.5	191	1.50	38			.38115	1	7/16	4.8	121	1.50	38			38215	1
		1/2	8.3	210	1.63	41			.38116	1	1/2	5.3	133	1.63	41			38216	1
		9/16	9.0	229	1.75	44			.38117	1	9/16	5.8	146	1.75	44			38217	1
		5/8	9.8	248	1.88	48			.38118	1	5/8	6.3	159	1.88	48			38218	1
		3/4	11.3	286	2.13	54			.38119	1	3/4	7.3	184	2.13	54			38219	1
Metric	Long						Short						Long						
	Metric	.71	2.6	66	0.22	6	29147	50	.39147	10	.71	1.2	31	0.22	6	28247	50	38247	10
		.89	2.7	68	0.34	9	29148	50	.39148	10	.89	1.2	31	0.34	9	28248	50	38248	10
		1.27	2.8	72	0.53	13	29149	50	.39149	10	1.27	1.6	42	0.53	13	28249	50	38249	10
		1.5	3.0	77	0.53	14	29150	50	.39150	10	1.5	1.7	44	0.53	14	28250	50	38250	10
		2.0	3.2	82	0.61	16	29152	50	.39152	10	2.0	1.9	49	0.61	16	28252	50	38252	10
		2.5	3.5	88	0.69	17	29154	50	.39154	10	2.5	2.1	54	0.69	17	28254	50	38254	10
		3.0	3.9	98	0.75	19	29156	50	.39156	10	3.0	2.4	61	0.75	19	28256	50	38256	10
		3.5	3.9	100	0.85	21	29158	50	.39158	1	3.5	2.6	65	0.85	21	28258	50	38258	1
		4.0	4.3	110	0.87	22	29160	50	.39160	10	4.0	2.7	68	0.87	22	28260	50	38260	10
		4.5	4.5	114	1.00	25	29162	50	.39162	1	4.5	2.9	73	1.00	25	28262	50	38262	1
		5.0	4.7	119	1.06	27	29164	50	.39164	5	5.0	3.1	78	1.06	27	28264	50	38264	5
		5.5	4.9	124	1.14	29	29166	25	.39166	1	5.5	3.3	83	1.14	29	28266	25	38266	1
		6	5.5	139	1.22	31	29168	25	.39168	5	6	3.5	88	1.22	31	28268	25	38268	5
		7	5.5	140	1.30	33	29170	25	.39170	1	7	3.7	93	1.30	33	28270	25	38270	1
		8	6.0	152	1.38	35	29172	25	.39172	5	8	3.9	98	1.38	35	28272	25	38272	5
		9	6.2	159	1.46	37	29174	25	.39174	1	9	4.0	102	1.46	37	28274	25	38274	1
		10	6.7	171	1.54	39	29176	10	.39176	5	10	4.3	109	1.54	39	28276	10	38276	5
		11	7.9	200	1.63	42	29178	10	.39178	1	11	4.5	115	1.63	42	28278	10	38278	1
		12	8.7	220	1.73	44	29180	10	.39180	1	12	4.8	122	1.73	44	28280	10	38280	1
		14	10.2	260	2.15	55			.39184	1	14	5.4	136	2.15	55			38284	1
		17	11.0	280	2.42	61			.39186	1	17	6.1	156	2.42	61			38286	1
		19	11.6	295	2.70	69			.39188	1	19	6.9	175	2.72	69			38288	1

Star Tip Tools



Color Coded

■ Star



High Torque Steel:

Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel.

FINISH OPTIONS:



Corrosion-resistant finish:

Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes.

- Fits TORX®* brand screws
- Fits in both Star and Star Plus fasteners
- A full range of tip sizes from T5 to T100
- The only Star Tip tools made with Protanium® steel



Bondhus Star Tip Tools

Bondhus Star Tip tools are made to the same high standards as every tool we make. Our Star Tip tools are precision machined, available in several handle and tip types, and are the only Star Tip tools made from Protanium® High Torque Steel. Bondhus Star Tip and Star Plus Tip tools fit TORX®* brand screws.



L-Wrenches

21-22



Wing and Flag Tools 23



Fold Ups

26-27



T-Handles

33



Screwdrivers

38-39



Socket Bits

45-46

*TORX® is a registered trademark of Acument Intellectual Properties, LLC

Star Tip L-Wrenches

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish delivers superior corrosion protection



L-Wrenches

Tools are in color coded cases for easy recognition
Green=Star

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Star	31832	TLX8S	8	Long	T6, T7, T8, T9, T10, T15, T20, T25	1	
	31834	TLX8	8	Long	T9, T10, T15, T20, T25, T27, T30, T40	1	
	31732	TLXS8S	8	Short	T6, T7, T8, T9, T10, T15, T20, T25	1	
	31734	TLXS8	8	Short	T9, T10, T15, T20, T25, T27, T30, T40	1	
	12699	TLX9S	9	Short	T10, T15, T20, T25, T27, T30, T40, T45, T50 (in pouch)	1	
	31737	TLX13S	13	Short	T7, T8, T9, T10, T15, T20, T25, T27, T30, T40, T45, T50, T55 (in pouch)	1	

SINGLE PACKAGING



BULK

TAGGED/BARCODED

SINGLE PACKAGING



BULK

TAGGED/BARCODED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA	PART#	QTY	LIST EA
	Long								Short					
Star	T6	2.1	55	0.65	16	32806	25		31806	5		T5	0.9	23
	T7	2.4	61	0.65	16	32807	25		31807	5		T6	1.1	29
	T8	2.6	67	0.65	16	32808	25		31808	5		T7	1.4	35
	T9	2.9	74	0.65	16	32809	25		31809	5		T8	1.6	42
	T10	3.2	80	0.73	19	32810	25		31810	5		T9	1.9	48
	T15	3.3	84	0.78	20	32815	25		31815	5		T10	2.2	55
	T20	3.6	91	0.78	20	32820	25		31820	5		T15	2.3	59
	T25	3.8	98	0.88	22	32825	25		31825	5		T20	2.6	66
	T27	4.2	106	0.95	24	32827	25		31827	5		T25	2.8	72
	T30	4.6	116	1.03	26	32830	25		31830	5		T27	3.2	81
	T40	4.9	125	1.11	28	32840	25		31840	5		T30	3.6	90
	T45	5.4	138	1.20	30	32845	10		31845	2		T40	3.9	99
	T50	6.2	156	1.25	32	32850	10		31850	2		T45	3.9	98
	T55	6.7	171	1.36	34	32855	10		31855	2		T50	3.8	97
	T60	7.2	182	1.75	44	32860	10		31860	2		T55	3.8	95

ProHold® Star Tip L-Wrenches

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Holds screw tight on the tool EVERY TIME
- Button is non-magnetic
- Precision machined for ease of use and superior fit

ProGuard™ finish delivers superior corrosion protection



Tools are in color coded cases for easy recognition
Green=Star

Set	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST							
Star	71834	PHTX8	8	Long	T9, T10, T15, T20, T25, T27, T30, T40	1								
SINGLE PACKAGING														
BULK														
Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA	PART#	QTY	LIST EA
LONG Star	T9	2.9	74	0.65	16	72809	25		71809	5				
	T10	3.2	80	0.73	19	72810	25		71810	5				
	T15	3.3	84	0.78	20	72815	25		71815	5				
	T20	3.6	91	0.78	20	72820	25		71820	5				
	T25	3.8	98	0.88	22	72825	25		71825	5				
	T27	4.2	106	0.95	24	72827	25		71827	5				
	T30	4.6	116	1.03	26	72830	25		71830	5				
	T40	4.9	125	1.11	28	72840	25		71840	5				
	T45	5.4	138	1.20	30	72845	10		71845	2				
	T50	6.2	156	1.25	32	72850	10		71850	2				
	T55	6.7	171	1.36	34	72855	10		71855	2				
	T60	7.2	182	1.75	44	72860	10		71860	2				

Did you know...?

Bondhus Star Tip tools fit Star, Star Plus and TORX®* brand screws.

*TORX® is a registered trademark of Acument Intellectual Properties, LLC

BallStar™ Tip L-Wrenches

L-Wrenches

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Ball End inserts into screws at a 20° angle
- Ball End saves time by quickly funneling tool into screw
- Superior Ball End strength and working angle
- Works in hard to reach places



Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Star	11346	LTX6	6	Long	T6, T7, T8, T9, T10, T15	1	
	11331	LTX8S	8	Long	T6, T7, T8, T9, T10, T15, T20, T25	1	
	11332	LTX8	8	Long	T9, T10, T15, T20, T25, T27, T30, T40	1	



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
LONG Star	T6	2.1	55	0.65	16	11706	5	
	T7	2.4	61	0.65	16	11707	5	
	T8	2.6	67	0.65	16	11708	5	
	T9	2.9	74	0.65	16	11709	5	
	T10	3.2	80	0.73	19	11710	5	
	T15	3.3	84	0.78	20	11715	5	
	T20	3.6	91	0.78	20	11720	5	
	T25	3.8	98	0.88	22	11725	5	
	T27	4.2	106	0.95	24	11727	5	
	T30	4.6	116	1.03	26	11730	5	
	T40	4.9	125	1.11	28	11740	5	
	T45	5.4	138	1.20	30	11745	1	
	T50	6.2	156	1.25	32	11750	1	
	T55	6.7	171	1.36	34	11755	1	

Tamper Resistant Star Tip L-Wrenches

- ProGuard™ Finish -

- Fits all Star and TORX®* brand tamper resistant screws
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit



Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Star	32432	TR-TL8S	8	Long	TR6, TR7, TR8, TR9, TR10, TR15, TR20, TR25	1	
	32434	TR-TL8	8	Long	TR9, TR10, TR15, TR20, TR25, TR27, TR30, TR40	1	



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA
LONG Star	TR6	2.1	55	0.65	16	33406	25		32406	2	
	TR7	2.4	61	0.65	16	33407	25		32407	2	
	TR8	2.6	67	0.65	16	33408	25		32408	2	
	TR9	2.9	74	0.65	16	33409	25		32409	2	
	TR10	3.2	80	0.73	19	33410	25		32410	2	
	TR15	3.3	84	0.78	20	33415	25		32415	2	
	TR20	3.6	91	0.78	20	33420	25		32420	2	
	TR25	3.8	98	0.88	22	33425	25		32425	2	
	TR27	4.2	106	0.95	24	33427	25		32427	2	
	TR30	4.6	116	1.03	26	33430	25		32430	2	
	TR40	4.9	125	1.11	28	33440	25		32440	2	

Did you know...?

ProGuard® protection is a permanent solution that does not wipe off like common oil and black oxide finishes; tools remain in good condition with up to 5 times the resistance to rust and corrosion.

Star Tip Wing Tools


- ProGuard™ Finish -

- Fits all Star, Star Plus, and TORX®* brand screws
- ComfortGrip Handles – soft rubber outer coating for maximum comfort and grip
- Chamfered tool tips eliminate burrs and help tools seat in screw head

ProGuard™ finish
delivers superior
corrosion protection




Sets	PART#	MODEL#	PCS	TIP	CONTENTS	QTY	LIST
Star	34745	TWX7	7	Star	T6, T7, T8, T9, T10, T15, T20	1	
	33945	TPWX7	7	Star Plus	TP6, TP7, TP8, TP9, TP10, TP15, TP20	1	

 

PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
Star						
T6	1.5	39		34706	2	
T7	1.5	39		34707	2	
T8	1.5	39		34708	2	
T9	1.5	39		34709	2	
T10	1.5	39		34710	2	
T15	1.5	39		34715	2	
T20	1.5	39		34720	2	

 

PACKAGED

Sizes	INCH	MM	PART#	QTY	LIST EA
Star Plus					
TP6	2.0	52	33906	2	
TP7	2.0	52	33907	2	
TP8	2.0	52	33908	2	
TP9	2.0	52	33909	2	
TP10	2.0	52	33910	2	
TP15	2.0	52	33915	2	
TP20	2.0	52	33920	2	



33945

Star Tip Flag Tools


- ProGuard™ Finish -

- Fits all Star, Star Plus, and TORX®* brand screws
- ComfortGrip Handles – soft rubber outer coating for maximum comfort and grip
- Chamfered tool tips eliminate burrs and help tools seat in screw head

ProGuard™ finish
delivers superior
corrosion protection




Sets	PART#	MODEL#	PCS	TIP	CONTENTS	QTY	LIST
Star	34445	TFX7	7	Star	T6, T7, T8, T9, T10, T15, T20	1	
	35045	TPFX7	7	Star Plus	TP6, TP7, TP8, TP9, TP10, TP15, TP20	1	

 

PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
Star						
T5	1.5	39		34405	2	
T6	1.5	39		34406	2	
T7	1.5	39		34407	2	
T8	1.5	39		34408	2	
T9	1.5	39		34409	2	
T10	1.5	39		34410	2	
T15	1.5	39		34415	2	
T20	1.5	39		34420	2	

 

PACKAGED

Sizes	INCH	MM	PART#	QTY	LIST EA
Star Plus					
TP6	2.0	52	35006	2	
TP7	2.0	52	35007	2	
TP8	2.0	52	35008	2	
TP9	2.0	52	35009	2	
TP10	2.0	52	35010	2	
TP15	2.0	52	35015	2	
TP20	2.0	52	35020	2	



34445

Fold Ups



Color Coded

- Inch
- Metric
- Star
- Inch/Metric
- Motorcycle
- Utility

- Patented handle design makes every job faster and easier
- Durable GorillaGrip® handle is stronger than steel handles
- Tool user can adjust tool tension



High Torque Steel:

Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel.

FINISH OPTIONS:



Corrosion-resistant finish:

Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes.



Next generation chrome finish:

Traditional plated tool look with superior protection and durability.



Real 14 karat gold finish:

Superior protection and durability over traditional chrome and the look and shine of real gold.

Designed with the Tool User in mind


A Bondhus Fold Up is a tool for life. When designing the GorillaGrip® Fold Up, Bondhus engineers eliminated the problems of the average folding tool. GorillaGrip® Fold Up tools are stronger, more comfortable and easier to use.



Patented Flutes allow for easy selection of one tool at a time.



Blades are accessed from both the top and bottom, eliminating the constant 'unstacking' of blades.

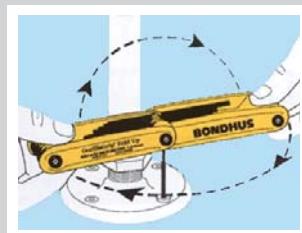

Turn & Flip Feature eliminates constant removal and repositioning in screw head when working against obstructions.



90° stop converts the tool into a non-stop, time saving, speed wrench.


GorillaGrip® Fold Up Multi Packs

Fold Ups

- ProGuard™ Finish -

- Assembled from our most popular Fold Up sets
- Multiple Fold Up sets per package
- Tip selections include Hex End and Star Tip

Inch	Metric	Star

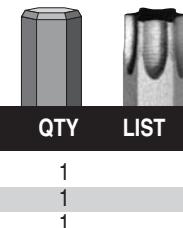

12522

PART# MODEL# PCS CONTENTS

12522	HF16	16	12589 (5/64-1/4") + 12587 (2-8mm)
12544	HF15	15	12587 (2-8mm) + 12634 (T9-T40)
12533	HF24	24	12589 (5/64-1/4") + 12587 (2-8mm) + 12634 (T9-T40)

QTY LIST

Hex End GorillaGrip® Fold Ups

- ProGuard™ Finish -

- Chamfered tool tips eliminate burrs and help tools seat in screws
- World's strongest handle
- Speed-Wrench feature
- Tools open from both the top and bottom
- Molded-in 90° stop
- Patented spacers between tools



ProGuard™ finish
delivers superior
corrosion protection



Yellow=Inch
Red=Metric
Orange=Inch/Metric

Hex End Tips

Sets PART# MODEL# PCS CONTENTS

Inch	12591	HF9S	9	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"
	12589	HF9	9	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"
	12585	HF5	5	3/16, 7/32, 1/4, 5/16, 3/8"
Metric	12592	HF7MS	7	1.5, 2, 2.5, 3, 4, 5, 6mm
	12587	HF7M	7	2, 2.5, 3, 4, 5, 6, 8mm
	12595	HF6M	6	3, 4, 5, 6, 8, 10mm
Inch/ Metric	12550	HF12	12	5/64, 3/32, 7/64, 1/8, 9/64, 5/32" 1.5, 2, 2.5, 3, 4, 5mm

QTY LIST



12587



12550

Ball End GorillaGrip® Fold Ups

- ProGuard™ Finish -

- Ball End inserts into a screw at a 25° angle
- World's strongest handle
- Speed-Wrench feature
- Tools open from both the top and bottom
- Molded-in 90° stop
- Patented spacers between tools



ProGuard™ finish
delivers superior
corrosion protection



Yellow=Inch
Red=Metric

Ball End Tips

Sets PART# MODEL# PCS CONTENTS

Inch	12894	BF5	5	3/16, 7/32, 1/4, 5/16, 3/8"
Metric	12897	BF5M	5	5, 6, 7, 8, 10mm

QTY LIST



12894

Star Tip GorillaGrip® Fold Ups

Fold Ups

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- World's strongest handle
- Speed-Wrench feature
- Tools open from both the top and bottom
- Molded-in 90° stop
- Patented spacers between tools



ProGuard™ finish
delivers superior
corrosion protection



Star Tips

Handles are color
coded for easy
recognition
Green=Star

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Star	12632	TF8S	8	T6, T7, T8, T9, T10, T15, T20, T25	1	
	12634	TF8	8	T9, T10, T15, T20, T25, T27, T30, T40	1	

Tamper Resistant GorillaGrip® Star Tip Fold Ups

- ProGuard™ Finish -

- Fits all Star and TORX®* brand tamper resistant screws
- World's strongest handle
- Speed-Wrench feature
- Tools open from both the top and bottom
- Molded-in 90° stop
- Patented spacers between tools



ProGuard™ finish
delivers superior
corrosion protection



Tamper Resistant Star Tips

Handles are color
coded for easy
recognition
Green=Star

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Star	12636	TR-TF7S	7	TR7, TR8, TR9, TR10, TR15, TR20, TR25	1	
	12638	TR-TF8	8	TR9, TR10, TR15, TR20, TR25, TR27, TR30, TR40	1	

Utility GorillaGrip® Fold Ups

- ProGuard™ Finish -

- Wide selection of tool tips
- World's strongest handle
- Speed-Wrench feature
- Tools open from both the top and bottom
- Molded-in 90° stop
- Patented spacers between tools



ProGuard™ finish
delivers superior
corrosion protection



Five tip styles available

Handles are color
coded for easy
recognition
Teal=Utility

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Utility	12540	HFU5	5	PH #1; Slotted 3/16"; Hex 4, 5, 6mm	1	
	12543	RFU5	5	PH #1, #2; Slotted 3/16"; Square #1, #2	1	
	12545	AFU5	5	PH #1, #2; Slotted 1/8, 3/16"; Awl	1	
	12547	FU5	5	PH #1, #2; Slotted 1/8, 3/16, 1/4"	1	

*TORX® is a registered trademark of Acument Intellectual Properties, LLC

Hawg Buddy GorillaGrip® Motorcycle Fold Up

Fold Ups

- BriteGuard™ Finish -

- Designed for making all common adjustments to Harley Davidson® motorcycles
- World's strongest handle
- Speed-Wrench feature
- Tools open from both the top and bottom
- Molded-in 90° stop



Phillips, Star and Hex
Tips



BriteGuard™ finish,
next generation
chrome



*Harley Davidson® is a Registered Trademark of Harley Davidson Motorcycles

Set	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
12531	FUHB7		7	PH #2; Star T27, T40; Hex 5/32, 3/16, 1/4, 5/16"	1	

Cycle Buddy GorillaGrip® Motorcycle Fold Up

- GoldGuard™ Finish -

- Designed for making all common adjustments to Japanese/European motorcycles
- World's strongest handle
- Speed-Wrench feature
- Tools open from both the top and bottom
- Molded-in 90° stop



Phillips and Hex
Tips



GoldGuard™ finish.
Real 14 karat Gold




Set	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
12594	FUCB6		6	PH #2; Hex 3, 4, 5, 6, 8mm	1	

Metal Fold Ups

- ProGuard™ Finish -

 
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer torque to screw more efficiently and reduce stripping
- Precision machined for ease of use and superior fit



Available in
Hex or Star Tip



ProGuard™ finish
delivers superior
corrosion protection

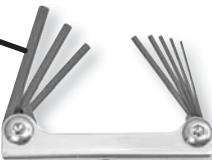



Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Inch	14590	MHF8	8	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1	
	14591	MHF9S	9	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"	1	
	14589	MHF9	9	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	14585	MHF5	5	3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	14592	MHF7MS	7	1.5, 2, 2.5, 3, 4, 5, 6mm	1	
	14587	MHF7M	7	2, 2.5, 3, 4, 5, 6, 8mm	1	
	14595	MHF6M	6	3, 4, 5, 6, 8, 10mm	1	
Star	14532	MTF8S	8	T6, T7, T8, T9, T10, T15, T20, T25	1	
	14534	MTF8	8	T9, T10, T15, T20, T25, T27, T30, T40	1	

Made in the U.S.A.



All Bondhus® tools are made with Protanium® High Torque Steel.

 T-Handles

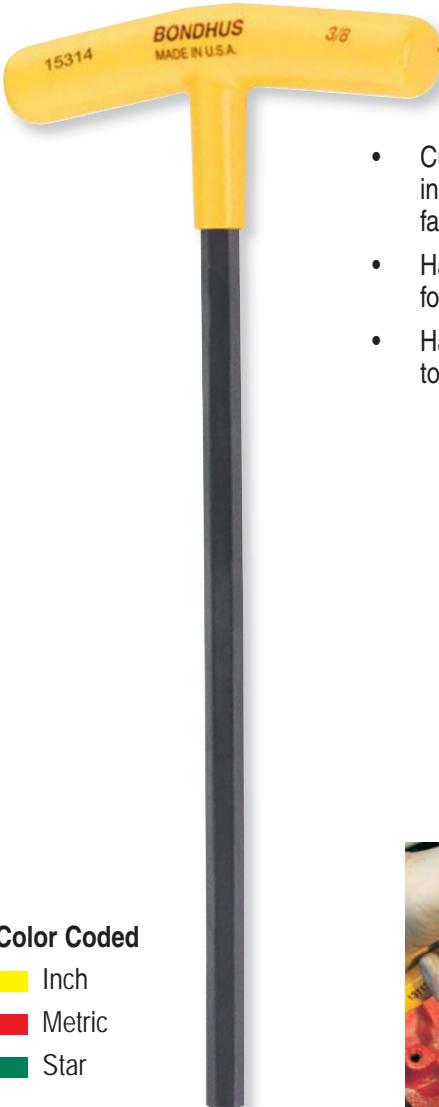

Color Coded

- Inch
- Metric
- Star



High Torque Steel:

Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel.



FINISH OPTIONS:




Corrosion-resistant finish:

Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes.

A Better T-Handle

Bondhus T-Handles are built to be comfortable, strong and durable. The welded handle and blade joint guarantees a permanent connection. The form-fitting handle fits the curve of the user's hand.

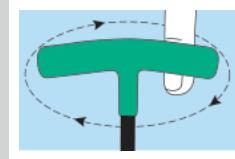

The Bondhus solid steel handle is heavy duty and generates a flywheel effect for super fast insertion and removal of screws.



The Bondhus T-Handle is curved to match the shape of the hand. This design is ergonomically superior to old fashioned straight handles.



Handle and blade are securely welded and will never loosen or slip.



Bondhus is the only company to engineer our handles to match the blade's torque capacity. Tool user's can always feel confident in their tool's strength.

Ball End T-Handles

- ProGuard™ Finish -

T-Handles

- Solid steel handles
- Welded handle/blade connection
- Ergonomic handle design
- Flywheel effect saves time
- Smooth, non-porous handle coating
- Handle coating extends along blade

ProGuard™ finish
delivers superior
corrosion protection



Ball End Tips



Handles are color
coded for easy
recognition
Yellow=Inch
Red=Metric

Sets	PART#	MODEL#	PCS	LENGTH	W/STAND	CONTENTS	QTY	LIST
Inch	13146	BTX60	6	Graduated		5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	13190*	BTX10/S	10	Graduated	✓	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	13138*	BTX10	10	Graduated		3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	13148	BTX50M	5	Graduated		4, 5, 6, 8, 10mm	1	
	13189*	BTX80M/S	8	Graduated	✓	2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	13187*	BTX80M	8	Graduated		2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

*The 3/32, 7/64, 1/8, and 9/64 inch blades, and the 2, 2.5 and 3mm blades are straight hex blades to prevent breakage.

✓ Comes with stand



SINGLE PACKAGING

PACKAGED

TAGGED/BARCODED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	PART#	QTY	LIST EA
Inch	3/32	6.1	154	3.0	76	13205 Hex*	2		53205 Hex*	2	
	7/64	6.8	173	3.0	76	13206 Hex*	2		53206 Hex*	2	
	1/8	7.6	192	3.0	76	13207 Hex*	2		53207 Hex*	2	
	9/64	8.3	211	3.0	76	13208 Hex*	2		53208 Hex*	2	
	5/32	9.1	231	3.0	76	13109	2		53109	2	
	3/16	9.8	250	4.0	102	13110	2		53110	2	
	7/32	10.3	262	4.0	102	13111	2		53111	2	
	1/4	10.8	275	4.0	102	13112	2		53112	2	
	5/16	11.4	289	5.0	127	13113	2		53113	2	
	3/8	11.8	300	5.0	127	13114	2		53114	2	
Metric	2.0	5.9	150	3.0	76	13252 Hex*	2		53252 Hex*	2	
	2.5	6.8	172	3.0	76	13254 Hex*	2		53254 Hex*	2	
	3.0	7.7	196	3.0	76	13256 Hex*	2		53256 Hex*	2	
	4.0	8.7	220	3.0	76	13160	2		53160	2	
	5.0	9.7	246	4.0	102	13164	2		53164	2	
	6	10.5	266	4.0	102	13168	2		53168	2	
	8	11.2	285	5.0	127	13172	2		53172	2	
	10	12.1	307	5.0	127	13176	2		53176	2	



13189 13190



13148

Molded T-Handle Stands

- Extremely durable design
- Can be used free standing or wall mounted
- Sizes are clearly marked on stand
- Available in Inch, Metric, or Star configurations

PART#	DESCRIPTION	QTY	LIST EA
17936	Inch Stand	1	
17935	Metric Stand	1	
17934	Star Stand	1	



Set stand on bench
or mount on wall.

Did you know...?

Welded T-Handle handle/blade connection increases strength and provides greater resistance to breakage. The tool user will never be stabbed in the hand by a blade that has broken free and pushed through the handle.

ProHold® Tip Ball End T-Handles

- ProGuard™ Finish -

T-Handles

- Holds screw tight on the tool EVERY TIME
- Button is non-magnetic
- Super smooth rotational action, with no interference from the ProHold® button
- Tool strength is not compromised by the ProHold® button
- Solid steel handles
- Welded handle/blade connection



Sets	PART#	MODEL#	PCS	LENGTH	W/STAND	CONTENTS	QTY	LIST
Inch	75146	PBTX60	6	Graduated		5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	75148	PBTX50M	5	Graduated		4, 5, 6, 8, 10mm	1	

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Inch	5/32	9.1	231	3.0	76	75109	2	
	3/16	9.8	250	4.0	102	75110	2	
	7/32	10.3	262	4.0	102	75111	2	
	1/4	10.8	275	4.0	102	75112	2	
	5/16	11.4	289	5.0	127	75113	2	
	3/8	11.8	300	5.0	127	75114	2	
Metric	4.0	8.7	220	3.0	76	75160	2	
	5.0	9.7	246	4.0	102	75164	2	
	6	10.5	266	4.0	102	75168	2	
	8	11.2	285	5.0	127	75172	2	
	10	12.1	307	5.0	127	75176	2	




75148

Bondhus also has loop
T-Handles available.
Please call for price and
availability.



ProHold® button holds screw
tight on the tool EVERY TIME

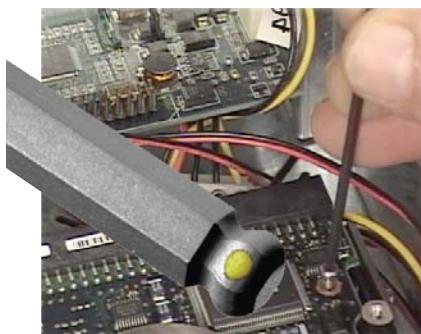

ProHold® buttons are non-magnetic and
safe for use in electronic applications

Hex End T-Handle Sets

- ProGuard™ Finish -

T-Handles

- Solid steel handles
- Welded handle/blade connection
- Ergonomic handle design
- Flywheel effect saves time
- Smooth, non-porous handle coating
- Handle coating extends along blade



Sets	PART#	MODEL#	PCS	LENGTH	W/STAND	CONTENTS	QTY	LIST
Inch	13332	HTX80	8	Graduated		3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	15232	HTX80-6	8	6 inch		3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	15332	HTX80-9	8	9 inch		3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	1	
	13390	HTX10/S	10	Graduated	✓	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	13338	HTX10	10	Graduated		3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	15290	HTX10/S-6	10	6 inch	✓	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	15238	HTX10-6	10	6 inch		3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	15390	HTX10/S-9	10	9 inch	✓	3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	15338	HTX10-9	10	9 inch		3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	13348	HTX60M	6	Graduated		2, 2.5, 3, 4, 5, 6mm	1	
	15248	HTX60M-6	6	6 inch		2, 2.5, 3, 4, 5, 6mm	1	
	15348	HTX60M-9	6	9 inch		2, 2.5, 3, 4, 5, 6mm	1	
	13389	HTX80M/S	8	Graduated	✓	2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	13387	HTX80M	8	Graduated		2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	15289	HTX80M/S-6	8	6 inch	✓	2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	15287	HTX80M-6	8	6 inch		2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	15389	HTX80M/S-9	8	9 inch	✓	2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	15387	HTX80M-9	8	9 inch		2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

✓ Comes with stand 17936 Inch or 17935 Metric



13389



13390



13348

Bondhus



Bondhus handles are permanently welded. There is no chance the blades will ever loosen. The tool user is in no danger of the blade pushing through the top of the handle and stabbing into the palm of the hand.

Competitor



The friction fit blades in competitors' T-Handles are not welded. They can loosen, slip, and even fall out or punch through the top of the handle.



For singles see page 32

Hex End T-Handle Singles

- ProGuard™ Finish -

- Solid steel handles
- Welded handle/blade connection
- Ergonomic handle design
- Flywheel effect saves time
- Smooth, non-porous handle coating
- Handle coating extends along blade



ProGuard™ finish
delivers superior
corrosion protection



Chamfered Hex
Tips fit tighter and
eliminate burrs

T-Handles

Handles are color
coded for easy
recognition
Yellow=Inch
Red=Metric



Singles		SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST	EA	
6" Length											
Inch	3/32	6.0	152	3.0	76	15205	2	45205	2		
	7/64	6.0	152	3.0	76	15206	2	45206	2		
	1/8	6.0	152	3.0	76	15207	2	45207	2		
	9/64	6.0	152	3.0	76	15208	2	45208	2		
	5/32	6.0	152	3.0	76	15209	2	45209	2		
	3/16	6.0	152	4.0	102	15210	2	45210	2		
	7/32	6.0	152	4.0	102	15211	2	45211	2		
	1/4	6.0	152	4.0	102	15212	2	45212	2		
	5/16	6.0	152	5.0	127	15213	2	45213	2		
	3/8	6.0	152	5.0	127	15214	2	45214	2		
	1/2	6.0	152	5.0	127	15216	1	45216	1		

Singles		SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST	EA	
6" Length											
Metric	2.0	6.0	152	3.0	76	15252	2	45252	2		
	2.5	6.0	152	3.0	76	15254	2	45254	2		
	3.0	6.0	152	3.0	76	15256	2	45256	2		
	4.0	6.0	152	3.0	76	15260	2	45260	2		
	5.0	6.0	152	4.0	102	15264	2	45264	2		
	6	6.0	152	4.0	102	15268	2	45268	2		
	7	6.0	152	4.0	102	15270	2	-	-		
	8	6.0	152	5.0	127	15272	2	45272	2		
	9	6.0	152	5.0	127	15274	2	-	-		
	10	6.0	152	5.0	127	15276	2	45276	2		

Singles		SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST	EA	
9" Length											
Inch	3/32	9.0	229	3.0	76	15305	2				
	7/64	9.0	229	3.0	76	15306	2				
	1/8	9.0	229	3.0	76	15307	2				
	9/64	9.0	229	3.0	76	15308	2				
	5/32	9.0	229	3.0	76	15309	2				
	3/16	9.0	229	4.0	102	15310	2				
	7/32	9.0	229	4.0	102	15311	2				
	1/4	9.0	229	4.0	102	15312	2				
	5/16	9.0	229	5.0	127	15313	2				
	3/8	9.0	229	5.0	127	15314	2				
	1/2	9.0	229	5.0	127	15316	1				

Graduated Length											
3/32	4.2	105	3.0	76	13305	2					
7/64	4.4	112	3.0	76	13306	2					
1/8	4.6	118	3.0	76	13307	2					
9/64	4.9	124	3.0	76	13308	2					
5/32	5.2	132	3.0	76	13309	2					
3/16	5.6	141	4.0	102	13310	2					
7/32	6.1	154	4.0	102	13311	2					
1/4	6.5	165	4.0	102	13312	2					
5/16	7.4	189	5.0	127	13313	2					
3/8	8.3	211	5.0	127	13314	2					

Singles		SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST	EA	
9" Length											
Metric	2.0	9.0	229	3.0	76	15352	2				
	2.5	9.0	229	3.0	76	15354	2				
	3.0	9.0	229	3.0	76	15356	2				
	4.0	9.0	229	3.0	76	15360	2				
	5.0	9.0	229	4.0	102	15364	2				
	6	9.0	229	4.0	102	15368	2				
	8	9.0	229	5.0	127	15372	2				
	10	9.0	229	5.0	127	15376	2				

Graduated Length											
2.0	4.0	100	3.0	76	13352	2					
2.5	4.3	110	3.0	76	13354	2					
3.0	4.7	120	3.0	76	13356	2					
4.0	5.3	136	3.0	76	13360	2					
5.0	5.9	150	4.0	102	13364	2					
6	6.8	173	4.0	102	13368	2					
8	7.9	202	5.0	127	13372	2					
10	9.1	232	5.0	127	13376	2					

For sets see page 31

Star Tip T-Handles

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Solid steel handles
- Welded handle/blade connection
- Ergonomic handle design
- Flywheel effect saves time
- Smooth, non-porous handle coating

ProGuard™ finish
delivers superior
corrosion protection



Handles are color
coded for easy
recognition
Green=Star



Set	PART#	MODEL#	PCS	LENGTH	W/STAND	CONTENTS	QTY	LIST
Star	33034	TTHX8	8	Graduated	✓	T9, T10, T15, T20, T25, T27, T30, T40	1	

✓ Comes with stand 17934



PACKAGED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Star	T9	6.1	155	3.0	76	33009	2	
	T10	6.4	161	3.0	76	33010	2	
	T15	6.6	168	3.0	76	33015	2	
	T20	6.9	174	3.0	76	33020	2	
	T25	7.1	180	3.0	76	33025	2	
	T27	7.4	187	4.0	102	33027	2	
	T30	7.6	193	4.0	102	33030	2	
	T40	7.9	199	4.0	102	33040	2	
	T45	8.1	206	5.0	127	33045	2	
	T50	8.4	212	5.0	127	33050	2	
	T55	8.6	218	5.0	127	33055	2	

Did you know...?

Bondhus Star Tip and Star Plus
Tip tools fit Star, Star Plus and
TORX®* brand screws.

ProHold® Star Tip T-Handles

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Holds screw tight on the tool EVERY TIME
- Button is non-magnetic
- Welded handle/blade connection

ProGuard™ finish
delivers superior
corrosion protection



Handles are color
coded for easy
recognition
Green=Star



Set	PART#	MODEL#	PCS	LENGTH	W/STAND	CONTENTS	QTY	LIST
Star	74034	PHTHX8	8	Graduated	✓	T9, T10, T15, T20, T25, T27, T30, T40	1	

✓ Comes with stand 17934



PACKAGED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Star	T9	6.1	155	3.0	76	74009	2	
	T10	6.4	161	3.0	76	74010	2	
	T15	6.6	168	3.0	76	74015	2	
	T20	6.9	174	3.0	76	74020	2	
	T25	7.1	180	3.0	76	74025	2	
	T27	7.4	187	4.0	102	74027	2	
	T30	7.6	193	4.0	102	74030	2	
	T40	7.9	199	4.0	102	74040	2	
	T45	8.1	206	5.0	127	74045	2	
	T50	8.4	212	5.0	127	74050	2	
	T55	8.6	218	5.0	127	74055	2	

Did you know...?

Bondhus T-Handle tools feature
an ergonomic handle design
to increase user comfort and
decrease hand fatigue.

Screwdrivers



- Ergonomic handle design greatly reduces pain and discomfort associated with repetitive tasks
- Non-slip grip generates maximum torque even when wet or oily
- Anti-roll design prevents rolling on vibrating surfaces and inclines up to 15°
- Two component ComfortGrip Handle is durable and comfortable

Color Coded

- Inch
- Metric
- Star



High Torque Steel:

Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel.

FINISH OPTIONS:



Corrosion-resistant finish:

Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes.



Next generation chrome finish:

Traditional plated tool look with superior protection and durability.



Real 14 karat gold finish:

Superior protection and durability over traditional chrome and the look and shine of real gold.

Attention to Detail

To create a superior screwdriver, Bondhus gives great attention to detail. The ComfortGrip handle is more comfortable and features a better grip than typical screwdrivers. Bondhus is also the only company to match the size of our screwdriver handles to the screwdriver blade's maximum torque.



The Bondhus ComfortGrip handle features a durable thermoplastic core wrapped in cushioned rubber for increased comfort and torque.



Bondhus handles are designed and sized to match the torque capacity of each blade tip.



Ergonomically designed handles deliver maximum torque with unrivaled comfort and grip.



Slight texture of handle helps retain grip, even when hands are wet or oily.

Ball End Screwdrivers

- ProGuard™ Finish -

- Ball End inserts into screw at a 25° angle
- Ergonomic handle design
- Non-slip grip
- Two component handle with tough inner core and cushioned rubber exterior
- Anti-roll design



Screwdrivers

Handles are color coded for easy recognition
Yellow=Inch
Red=Metric

Sets	PART#	MODEL#	PCS	LENGTH	CONTENTS	QTY	LIST
Inch	10645	BSX7	7	Standard	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"	1	
	10632	BSX8S	8	Standard	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1	
	10633	BSX8	8	Standard	7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	1	
	10637	BSX13	13	Standard	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	10737	BSX11L	11	Long	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	10686	BSX6M	6	Standard	1.5, 2, 2.5, 3, 4, 5mm	1	
	10687	BSX7M	7	Standard	1.27, 1.5, 2, 2.5, 3, 4, 5mm	1	
	10699	BSX9M	9	Standard	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	
	10733	BSX8ML	8	Long	2, 2.5, 3, 4, 5, 6, 8, 10mm	1	



10637

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA	SINGLE PACKAGING		PART#	QTY	LIST EA
									PACKAGED	TAGGED/BARCODED			
Standard													
Inch	.050	2.4	60	4.1	104	10602	2		40602	2			
	1/16	2.5	64	4.7	118	10603	2		40603	2			
	5/64	2.6	67	4.8	122	10604	2		40604	2			
	3/32	2.8	71	5.2	132	10605	2		40605	2			
	7/64	2.9	74	5.3	136	10606	2		40606	2			
	1/8	3.1	80	6.6	168	10607	2		40607	2			
	9/64	3.3	83	6.8	171	10608	2		40608	2			
	5/32	3.6	91	7.9	201	10609	2		40609	2			
	3/16	3.7	94	8.0	204	10610	2		40610	2			
	7/32	4.2	107	9.0	230	10611	2		40611	2			
	1/4	5.0	126	9.8	249	10612	2		40612	2			
	5/16	5.6	142	10.4	265	10613	2		40613	2			
	3/8	6.5	164	11.3	287	10614	2		40614	2			
	7/16	7.6	194	12.5	317	10615	1						
	1/2	8.6	217	13.4	340	10616	1						
Long													
Metric	1.27	2.4	60	4.1	104	10649	2		40649	2			
	1.5	2.6	66	4.7	120	10650	2		40650	2			
	2.0	2.8	72	5.0	127	10652	2		40652	2			
	2.5	2.7	69	5.1	130	10654	2		40654	2			
	3.0	3.3	83	6.7	171	10656	2		40656	2			
	3.5	3.5	88	6.9	176	10658	1						
	4.0	3.7	95	8.1	205	10660	2		40660	2			
	4.5	4.3	109	8.6	218	10662	1						
	5.0	4.3	109	8.6	219	10664	2		40664	2			
	5.5	5.0	126	9.3	236	10666	1						
	6	5.4	137	10.2	260	10668	2		40668	2			
	7	5.7	145	10.5	268	10670	1						
	8	6.4	162	11.2	286	10672	2		40672	2			
	9	6.9	175	11.7	298	10674	1						
	10	7.3	184	12.1	307	10676	2		40676	2			

For Extra Long and Custom Length singles
see page 36

Ball End Screwdriver Extra Long and Custom Length Singles

Screwdrivers

- ProGuard™ Finish -

- Ball End inserts into screw at a 25° angle
- Ergonomic handle design
- Non-slip grip



ProGuard™ finish
delivers superior
corrosion protection



SINGLE PACKAGING
PACKAGED

SINGLE PACKAGING
PACKAGED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
---------	------	------	----	------	----	-------	-----	---------

Extra Long								
Inch	.050	11.1	283	12.8	326	3702	1	
1/16	11.1	281	13.2	336	3703	1		
5/64	11.0	279	13.2	334	3704	1		
3/32	11.0	279	13.4	341	3705	1		
7/64	10.6	270	13.0	331	3706	1		
1/8	10.6	270	14.1	358	3707	1		
9/64	10.5	267	14.0	355	3708	1		
5/32	10.5	267	14.8	377	3709	1		
3/16	10.3	260	14.6	370	3710	1		
7/32	10.3	260	15.1	383	3711	1		
1/4	10.3	260	15.1	383	3712	1		
5/16	10.3	260	15.1	383	3713	1		
3/8	10.3	260	15.1	383	3714	1		
7/16	10.5	267	15.3	390	3715	1		
1/2	10.5	267	15.3	390	3716	1		

SIZE	PART#	QTY	LIST EA
Custom Length			
.050	193102	1	
1/16	193103	1	
5/64	193104	1	
3/32	193105	1	
7/64	193106	1	
1/8	193107	1	
9/64	193108	1	
5/32	193109	1	
3/16	193110	1	
7/32	193111	1	
1/4	193112	1	
5/16	193113	1	
3/8	193114	1	
7/16	193115	1	
1/2	193116	1	

Extra Long								
Metric	1.5	11.0	279	13.2	334	3750	1	
2.0	11.0	279	13.2	334	3752	1		
2.5	10.5	267	12.9	328	3754	1		
3.0	10.6	270	14.1	358	3756	1		
4.0	10.5	267	14.8	377	3760	1		
5.0	10.3	260	14.6	370	3764	1		
6	10.3	260	15.1	383	3768	1		
8	10.3	260	15.1	383	3772	1		
10	10.3	260	15.1	383	3776	1		

SIZE	PART#	QTY	LIST EA
Custom Length			
1.5	193150	1	
2.0	193152	1	
2.5	193154	1	
3.0	193156	1	
4.0	193160	1	
5.0	193164	1	
6	193168	1	
8	193172	1	
10	193176	1	

ProHold® Ball End Screwdrivers

- ProGuard™ Finish -

- Holds screw tight on the tool EVERY TIME
- Button is non-magnetic
- Super smooth rotational action, with no interference from the ProHold® button

ProGuard™ finish
delivers superior
corrosion protection



SINGLE PACKAGING

PACKAGED

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Inch	74632	PBSX8S	8	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1	
	74637	PBSX13	13	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	74686	PBSX6M	6	1.5, 2, 2.5, 3, 4, 5mm	1	
	74699	PBSX9M	9	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Inch								
.050	3.2	81	4.1	104	74602	2		
1/16	3.3	84	4.7	118	74603	2		
5/64	3.5	88	4.8	122	74604	2		
3/32	3.7	94	5.2	132	74605	2		
7/64	2.9	74	5.3	136	74606	2		
1/8	3.1	80	6.6	168	74607	2		
9/64	3.3	83	6.8	171	74608	2		
5/32	3.6	91	7.9	201	74609	2		
3/16	3.7	94	8.0	204	74610	2		
7/32	4.2	107	9.0	230	74611	2		
1/4	4.7	118	9.8	249	74612	2		
5/16	5.6	142	10.4	265	74613	2		
3/8	6.5	164	11.3	287	74614	2		

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Metric								
1.27	2.4	60	4.1	104	74649	2		
1.5	2.6	66	4.7	120	74650	2		
2.0	2.8	72	5.0	127	74652	2		
2.5	2.7	69	5.1	130	74654	2		
3.0	3.3	83	6.7	171	74656	2		
4.0	3.7	95	8.1	205	74660	2		
5.0	4.3	109	8.6	219	74664	2		
6	5.4	137	10.2	260	74668	2		
8	6.4	162	11.2	286	74672	2		
10	7.3	184	12.1	307	74676	2		


SINGLE PACKAGING

PACKAGED

Ball End Screwdrivers

- BriteGuard™ Finish -

- Ball End inserts into screw at a 25° angle
- Ergonomic handle design
- Non-slip grip
- Two component handle with tough inner core and cushioned rubber exterior
- Anti-roll design

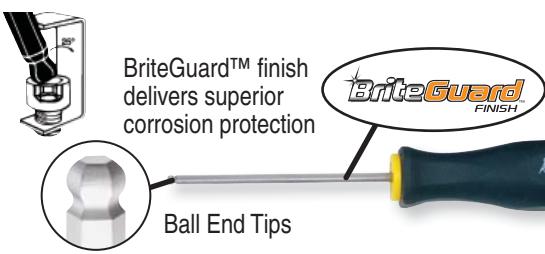

Handles are color coded for easy recognition
Yellow=Inch
Red=Metric

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Inch	16632	BSX8SB	8	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1	
	16637	BSX13B	13	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	16686	BSX6MB	6	1.5, 2, 2.5, 3, 4, 5mm	1	
	16699	BSX9MB	9	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Inch	.050	2.4	60	4.1	104	16602	2	
	1/16	2.5	64	4.7	118	16603	2	
	5/64	2.6	67	4.8	122	16604	2	
	3/32	2.8	71	5.2	132	16605	2	
	7/64	2.9	74	5.3	136	16606	2	
	1/8	3.1	80	6.6	168	16607	2	
	9/64	3.3	83	6.8	171	16608	2	
	5/32	3.6	91	7.9	201	16609	2	
	3/16	3.7	94	8.0	204	16610	2	
	7/32	4.2	107	9.0	230	16611	2	
	1/4	5.0	126	9.8	249	16612	2	
	5/16	5.6	142	10.4	265	16613	2	
	3/8	6.5	164	11.3	287	16614	2	
	7/16	7.6	194	12.5	317	16615	1	
	1/2	8.6	217	13.4	340	16616	1	

Ball End Screwdrivers

- GoldGuard™ Finish -

- Ball End inserts into screw at a 25° angle
- Ergonomic handle design
- Non-slip grip
- Two component handle with tough inner core and cushioned rubber exterior
- Anti-roll design



Handles are color coded for easy recognition
Yellow=Inch
Red=Metric

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Inch	38632	BSX8SG	8	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	1	
	38637	BSX13G	13	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	38686	BSX6MG	6	1.5, 2, 2.5, 3, 4, 5mm	1	
	38699	BSX9MG	9	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	1	



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Inch	.050	2.4	60	4.1	104	38602	2	
	1/16	2.5	64	4.7	118	38603	2	
	5/64	2.6	67	4.8	122	38604	2	
	3/32	2.8	71	5.2	132	38605	2	
	7/64	2.9	74	5.3	136	38606	2	
	1/8	3.1	80	6.6	168	38607	2	
	9/64	3.3	83	6.8	171	38608	2	
	5/32	3.6	91	7.9	201	38609	2	
	3/16	3.7	94	8.0	204	38610	2	
	7/32	4.2	107	9.0	230	38611	2	
	1/4	5.0	126	9.8	249	38612	2	
	5/16	5.6	142	10.4	265	38613	2	
	3/8	6.5	164	11.3	287	38614	2	
	7/16	7.6	194	12.5	317	38615	1	
	1/2	8.6	217	13.4	340	38616	1	

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Metric	1.27	2.4	60	4.1	104	38649	2	
	1.5	2.6	66	4.7	120	38650	2	
	2.0	2.8	72	5.0	127	38652	2	
	2.5	2.7	69	5.1	130	38654	2	
	3.0	3.3	83	6.8	172	38656	2	
	4.0	3.7	95	8.1	205	38660	2	
	5.0	4.3	109	8.6	219	38664	2	
	6	5.4	137	10.2	260	38668	2	
	8	6.4	162	11.2	286	38672	2	
	10	7.3	184	12.1	307	38676	2	

Star Tip Screwdrivers

Screwdrivers

 
- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping

ProGuard™ finish
delivers superior
corrosion protection



Handles are color
coded for easy
recognition
Green=Star



Star Tip

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Star	34532	TSX8S	8	T6, T7, T8, T9, T10, T15, T20, T25	1	
	34534	TSX8	8	T9, T10, T15, T20, T25, T27, T30, T40	1	

SINGLE PACKAGING



PACKAGED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Star	T5	4.0	102	6.2	156	34505	2	
	T6	4.3	108	6.4	163	34506	2	
	T7	4.5	114	6.7	169	34507	2	
	T8	4.8	121	7.2	182	34508	2	
	T9	4.9	124	7.3	186	34509	2	
	T10	5.0	128	7.4	189	34510	2	
	T15	5.1	131	8.6	219	34515	2	
	T20	5.4	138	9.8	248	34520	2	
	T25	5.7	144	10.0	253	34525	2	
	T27	5.8	147	10.6	270	34527	2	
	T30	6.0	153	10.9	276	34530	2	
	T40	6.3	159	11.1	282	34540	2	
	T45	6.5	166	11.4	289	34545	1	
	T50	6.8	172	11.6	295	34550	1	
	T55	7.0	178	11.9	301	34555	1	
	T60	7.3	185	12.1	308	34560	1	

Did you know...?

ProGuard™ Dry Surface Technology is the world's best corrosion protection. The tool user does not have to work with rusty tools. ProGuard™ protection delivers up to 5 times the corrosion resistance of any other Hex or Star Tip tool finish.

ProHold® Star Tip Screwdrivers

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Holds screw tight on the tool EVERY TIME
- Button is non-magnetic
- Chamfered tool tips eliminate burrs and help tools seat in screw head

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Star	75534	PHTSX8	8	T9, T10, T15, T20, T25, T27, T30, T40	1	

SINGLE PACKAGING



PACKAGED

Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Star	T9	4.9	124	7.3	186	75509	1	
	T10	5.0	128	7.4	189	75510	1	
	T15	5.1	131	8.6	219	75515	1	
	T20	5.4	138	9.8	248	75520	1	
	T25	5.7	144	10.0	253	75525	1	
	T27	5.8	147	10.6	270	75527	1	
	T30	6.0	153	10.9	276	75530	1	
	T40	6.3	159	11.1	282	75540	1	
	T45	6.5	166	11.4	289	75545	1	
	T50	6.8	172	11.6	295	75550	1	
	T55	7.0	178	11.9	301	75555	1	
	T60	7.3	185	12.1	308	75560	1	

ProGuard™ finish
delivers superior
corrosion protection



Handles are color
coded for easy
recognition
Green=Star



ProHold®
Star Tip

Did you know...?

ProHold® buttons are non-magnetic and work on all fastener types. They are safe to use on sensitive equipment. They will not rust and will hold non-magnetic screws (aluminum, stainless and plastic)

Ball Star Tip Screwdrivers

Screwdrivers

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Ball End inserts into a screw at a 20° angle
- Ball End saves time by quickly funneling tool into screw
- Superior Ball End strength and working angle
- Works in hard to reach places



ProGuard™ finish
delivers superior
corrosion protection



Ball Star Tip

Handles are color
coded for easy
recognition
Green=Star

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Star	13546	STX6	6	T6, T7, T8, T9, T10, T15	1	
	13532	STX8	8	T9, T10, T15, T20, T25, T27, T30, T40	1	

SINGLE PACKAGING



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Star	T6	2.6	65	4.7	119	12706	2	
	T7	2.6	65	4.7	119	12707	2	
	T8	2.6	65	5.0	126	12708	2	
	T9	2.6	65	5.0	126	12709	2	
	T10	2.8	70	5.2	132	12710	2	
	T15	2.9	73	6.4	161	12715	2	
	T20	3.2	81	7.5	191	12720	2	
	T25	3.4	87	7.7	197	12725	2	
	T27	3.8	97	8.7	220	12727	2	
	T30	4.2	106	9.0	229	12730	2	
	T40	4.6	117	9.4	240	12740	2	
	T45	5.2	132	10.0	255	12745	1	
	T50	6.0	153	10.9	276	12750	1	
	T55	6.8	172	11.6	295	12755	1	

Did you know...?

BallStar™ tools work at a 20° angle; screws can be turned continuously without constantly taking the tool out of the screw, repositioning it and reinserting it, even at angles up to 20°.

Tamper Resistant Star Tip Screwdrivers

- ProGuard™ Finish -

- Fits all Star and TORX®* brand tamper resistant screws
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit



ProGuard™ finish
delivers superior
corrosion protection



Tamper Resistant
Star Tip

Handles are color
coded for easy
recognition
Green=Star

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Star	33832	TR-SX8S	8	TR6, TR7, TR8, TR9, TR10, TR15, TR20, TR25	1	
	33834	TR-SX8	8	TR9, TR10, TR15, TR20, TR25, TR27, TR30, TR40	1	

SINGLE PACKAGING



Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
Star	TR6	4.3	108	6.4	163	33806	1	
	TR7	4.5	114	6.7	169	33807	1	
	TR8	4.8	121	7.2	182	33808	1	
	TR9	4.9	124	7.3	186	33809	1	
	TR10	5.0	128	7.4	189	33810	1	
	TR15	5.1	131	8.6	219	33815	1	
	TR20	5.4	138	9.8	248	33820	1	
	TR25	5.7	144	10.0	253	33825	1	
	TR27	5.8	147	10.6	270	33827	1	
	TR30	6.0	153	10.9	276	33830	1	
	TR40	6.3	159	11.1	282	33840	1	

Did you know...?

Bondhus' ergonomic handle design greatly reduces fatigue associated with repetitive tasks and the application of torque.

*TORX® is a registered trademark of Acument Intellectual Properties, LLC

Square Ball End Screwdrivers


Screwdrivers

- ProGuard™ Finish -

- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- Two component handle with tough inner core and cushioned rubber exterior
- Non-slip grip
- Anti-roll design



ProGuard™ finish
delivers superior
corrosion protection

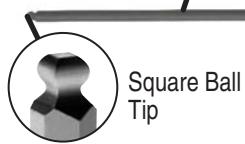

Ergonomic handle
design

Set	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
	11640	BRX4	4	SQ0, SQ1, SQ2, SQ3	1	

SINGLE PACKAGING



PACKAGED


Singles	SIZE	INCH	MM	INCH	MM	PART#	QTY	LIST EA
	SQ0	3.5	90	7.0	178	11600	2	
	SQ1	3.8	95	7.2	183	11601	2	
	SQ2	4.0	102	8.3	212	11602	2	
	SQ3	4.0	102	8.3	212	11603	2	
	SQ4	4.5	115	8.8	225	11604	2	



Bondhex™ Cases

- Provides a convenient means of keeping L-Wrenches neat and organized
- Sizes are printed on the case for quick tool selection
- Case can be used in conjunction with the tool to increase torque

PART#	FITS SIZES	QTY	LIST
Inch	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32"	10	
	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16"	10	
	.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	10	
	1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4"	10	
	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16"	10	
Metric	1.5, 2, 2.5, 3, 4, 5mm	10	
	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10mm	10	

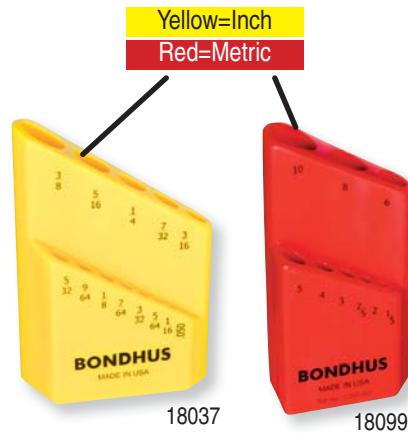

18037

18099

About the Bondhex™ Case For Ball End, Hex and Star Tip L-Wrenches

Bondhus Ball End, Hex and Star key sets are packed in a color coded Bondhex™ case to keep tools neat and sorted. A simple 60 degree turn locks keys in place to eliminate loose, spilled and lost keys. Tool sizes are clearly printed beneath each tool for quick size selection. A Bondhex™ case can also be used with a hex key to increase grip and comfortably generate additional torque.

Most Bondhus L-Wrench sets come standard with our Bondhex™ case.



Hollow Shaft Nut Drivers

Nut Drivers

- Hexagonal upper shaft for use with a wrench for increased torque
- Ergonomic handle design
- Non-slip grip
- Anti-roll handle
- High strength chrome plated shaft



Handles are color coded for easy recognition
Yellow=Inch
Red=Metric

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Inch	48445	BNX7	7	3/16, 1/4, 5/16, 11/32, 3/8, 7/16, 1/2"	1	
Metric	48492	BNX7M	7	6, 7, 8, 9, 10, 11, 12mm	1	
	48496	BNX7ML	7	6, 7, 8, 9, 10, 11, 13mm	1	

SINGLE PACKAGING									
Singles	SIZE	INCH		MM		PART#	QTY	LIST EA	TAGGED/BARCODED
		INCH	MM	INCH	MM				
Inch	5/32	3	76	7.3	186	38409	1	48409	1
	3/16	3	76	7.3	186	38410	1	48410	1
	7/32	3	76	7.3	186	38411	1	48411	1
	1/4	3	76	7.3	186	38412	1	48412	1
	9/32	3	76	7.3	186	38432	1	48432	1
	5/16	3	76	7.3	186	38413	1	48413	1
	11/32	3	76	7.3	186	38435	1	48435	1
	3/8	3	76	7.3	186	38414	1	48414	1
	7/16	3	76	7.3	186	38415	1	48415	1
	1/2	3	76	7.3	186	38416	1	48416	1
Metric	4.0	3	76	7.3	186	38460	1	48460	1
	5.0	3	76	7.3	186	38464	1	48464	1
	5.5	3	76	7.3	186	38466	1	48466	1
	6	3	76	7.3	186	38468	1	48468	1
	7	3	76	7.3	186	38470	1	48470	1
	8	3	76	7.3	186	38472	1	48472	1
	9	3	76	7.3	186	38474	1	48474	1
	10	3	76	7.3	186	38476	1	48476	1
	11	3	76	7.3	186	38478	1	48478	1
	12	3	76	7.3	186	38480	1	48480	1
	13	3	76	7.3	186	38482	1	48482	1




48492

Lifetime Warranty

Bondhus manufactures the highest quality Hex and Star tools available, and every tool is backed by an unconditional lifetime warranty.

"All Bondhus products are guaranteed for life. If you are not satisfied with a Bondhus tool - for any reason - simply return it. A replacement will be shipped right out at no cost - no hassles, no questions asked."

A warranty is only as good as the company standing behind it. Bondhus has been the leading innovator in the Hex and Star tool industry for over forty years.

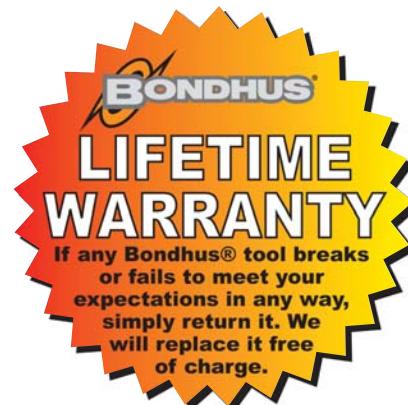

Socket Bits



High Torque Steel:

Up to 20% stronger, with more torque and twice the wear resistance of standard grades of steel.

FINISH OPTIONS:



Corrosion-resistant finish:

Environmentally safe, provides better tool grip, resists solvents and is 5 times more corrosion resistant than competitor finishes.

ProHold® Socket Bit Technology

Bondhus ProHold® technology is a revolution in holding systems that makes all other holding systems obsolete. Bits seat firmly into socket. No special tools are required to remove bits from sockets.



Bit sizes are clearly printed in white ink.



ProHold® buttons hold bit securely while allowing easy removal without the use of set screws or roll pins.



Bits are suitable for use with standard or impact sockets.

Hex End Socket Bits

- ProGuard™ Finish -

- Bits fit any standard six point socket
- Bits are suitable for use with impact sockets
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish
delivers superior
corrosion protection



Hex End Tips



Molded Black Case



Clamshell Package

Socket Bits

Sets	PART#	MODEL#	PCS	BIT LENGTH	DESCRIPTION	PACKED IN	CONTENTS	QTY	LIST
Inch	43299	PHX9/S-2	9	2"/50mm	Sockets & Bits	Transparent Clamshell	5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2, 9/16, 5/8"	1	
	43645	PHX5/S-6	5	6"/150mm	Sockets & Bits	Transparent Clamshell	5/16, 3/8, 1/2, 9/16, 5/8"	1	
	33299	PHX9-2	9	2"/50mm	Bits Only	Transparent Clamshell	5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2, 9/16, 5/8"	1	
	33645	PHX5-6	5	6"/150mm	Bits Only	Transparent Clamshell	5/16, 3/8, 1/2, 9/16, 5/8"	1	
	30299	PHX9/S-2C	9	2"/50mm	Sockets & Bits	Molded Black Case	5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2, 9/16, 5/8"	1	
	30645	PHX5/S-6C	5	6"/150mm	Sockets & Bits	Molded Black Case	5/16, 3/8, 1/2, 9/16, 5/8"	1	
	23299	PHX9-2C	9	2"/50mm	Bits Only	Molded Black Case	5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2, 9/16, 5/8"	1	
Metric	43298	PHX9M/S-2	9	2"/50mm	Sockets & Bits	Transparent Clamshell	4, 5, 6, 7, 8, 10, 12, 14, 17mm	1	
	43646	PHX6M/S-6	6	6"/150mm	Sockets & Bits	Transparent Clamshell	4, 5, 6, 7, 8, 10mm	1	
	33298	PHX9M-2	9	2"/50mm	Bits Only	Transparent Clamshell	4, 5, 6, 7, 8, 10, 12, 14, 17mm	1	
	33646	PHX6M-6	6	6"/150mm	Bits Only	Transparent Clamshell	4, 5, 6, 7, 8, 10mm	1	
	30298	PHX9M/S-2C	9	2"/50mm	Sockets & Bits	Molded Black Case	4, 5, 6, 7, 8, 10, 12, 14, 17mm	1	
	30646	PHX6M/S-6C	6	6"/150mm	Sockets & Bits	Molded Black Case	4, 5, 6, 7, 8, 10mm	1	
	23246	PHX6M-2C	6	2"/50mm	Bits Only	Molded Black Case	4, 5, 6, 7, 8, 10mm	1	
	23298	PHX9M-2C	9	2"/50mm	Bits Only	Molded Black Case	4, 5, 6, 7, 8, 10, 12, 14, 17mm	1	
	23296	PHX9ML-2C	9	2"/50mm	Bits Only	Molded Black Case	5, 6, 7, 8, 10, 12, 14, 17, 19mm	1	



BIT ONLY



SOCKET AND BIT



BIT ONLY



SOCKET AND BIT

Singles	SIZE	PART# QTY LIST EA	PART# QTY DRIVE LIST EA
	2" Long	50mm Long	
Inch	1/8	33207 1	43207 1 3/8"
	5/32	33209 1	43209 1 3/8"
	3/16	33210 1	43210 1 3/8"
	7/32	33211 1	43211 1 3/8"
	1/4	33212 1	43212 1 3/8"
	5/16	33213 1	43213 1 3/8"
	3/8	33214 1	43214 1 3/8"
	1/2	33216 1	43216 1 1/2"
	9/16	33217 1	43217 1 1/2"
	5/8	33218 1	43218 1 1/2"
	3/4	33219 1	43219 1 1/2"
	2.5" Long	65mm Long	
Inch	7/8	33220 1	- - -
	1	33221 1	- - -
	1 1/8	33223 1	- - -
	1 1/4	33225 1	- - -
	1 1/2	33229 1	- - -
	1 3/4	33231 1	- - -
	2	33233 1	- - -
	6" Long	150mm Long	
Inch	1/8	33607 1	43507 1 3/8"
	5/32	33609 1	43509 1 3/8"
	3/16	33610 1	43510 1 3/8"
	7/32	33611 1	43511 1 3/8"
	1/4	33612 1	43512 1 3/8"
	5/16	33613 1	43513 1 3/8"
	3/8	33614 1	43514 1 3/8"
	5/16	- -	43613 1 1/2"
	3/8	- -	43614 1 1/2"
	1/2	33616 1	43616 1 1/2"
	9/16	33617 1	43617 1 1/2"
	5/8	33618 1	43618 1 1/2"
	3/4	33619 1	43619 1 1/2"

Singles	SIZE	PART# QTY LIST EA	PART# QTY DRIVE LIST EA
	2" Long	50mm Long	
Metric	3.0	33256 1	43256 1 3/8"
	4.0	33260 1	43260 1 3/8"
	5.0	33264 1	43264 1 3/8"
	6	33268 1	43268 1 3/8"
	7	33270 1	43270 1 3/8"
	8	33272 1	43272 1 3/8"
	9	33274 1	43274 1 3/8"
	10	33276 1	43276 1 3/8"
	12	33280 1	43280 1 1/2"
	14	33284 1	43284 1 1/2"
	17	33286 1	43286 1 1/2"
	19	33288 1	43288 1 1/2"
	2.5" Long	65mm Long	
Metric	22	33291 1	- - -
	24	33293 1	- - -
	27	33295 1	- - -
	32	33297 1	- - -
	36	33200 1	- - -
	6" Long	150mm Long	
Metric	3.0	33656 1	43656 1 3/8"
	4.0	33660 1	43660 1 3/8"
	5.0	33664 1	43664 1 3/8"
	6	33668 1	43668 1 3/8"
	7	33670 1	43670 1 3/8"
	8	33672 1	43672 1 3/8"
	9	33674 1	43674 1 3/8"
	10	33676 1	43676 1 3/8"
	12	33680 1	43680 1 1/2"
	14	33684 1	43684 1 1/2"
	17	33686 1	43686 1 1/2"
	19	33688 1	43688 1 1/2"

Ball End Socket Bits

Socket Bits

- ProGuard™ Finish -

- Bits fit any standard six point socket
 - Ball End inserts into a screw at a 25° angle
 - Ball End saves time by quickly funneling tool into screw
 - Superior Ball End strength and working angle



ProGuard™ finish
delivers superior
corrosion protection



Molded Black Case



Clamshell Package

Sets	Part#	Model#	PCS	Bit Length	Description	Packed In	Contents	Qty	List
Inch	43445	PHBX7/S-2	7	2 ¹ /50mm	Sockets & Bits	Transparent Clamshell	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	43845	PHBX7/S-6	7	6"/150mm	Sockets & Bits	Transparent Clamshell	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	31445	PHBX7-2	7	2 ¹ /50mm	Bits Only	Transparent Clamshell	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	31645	PHBX7-6	7	6"/150mm	Bits Only	Transparent Clamshell	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	30445	PHBX7/S-2C	7	2 ¹ /50mm	Sockets & Bits	Molded Black Case	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	30845	PHBX7/S-6C	7	6"/150mm	Sockets & Bits	Molded Black Case	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
	23445	PHBX7-2C	7	2 ¹ /50mm	Bits Only	Molded Black Case	1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"	1	
Metric	43487	PHBX8M/S-2	8	2 ¹ /50mm	Sockets & Bits	Transparent Clamshell	3, 4, 5, 6, 7, 8, 9, 10mm	1	
	43887	PHBX8M/S-6	8	6"/150mm	Sockets & Bits	Transparent Clamshell	3, 4, 5, 6, 7, 8, 9, 10mm	1	
	31487	PHBX8M-2	8	2 ¹ /50mm	Bits Only	Transparent Clamshell	3, 4, 5, 6, 7, 8, 9, 10mm	1	
	31687	PHBX8M-6	8	6"/150mm	Bits Only	Transparent Clamshell	3, 4, 5, 6, 7, 8, 9, 10mm	1	
	30487	PHBX8M/S-2C	8	2 ¹ /50mm	Sockets & Bits	Molded Black Case	3, 4, 5, 6, 7, 8, 9, 10mm	1	
	30887	PHBX8M/S-6C	8	6"/150mm	Sockets & Bits	Molded Black Case	3, 4, 5, 6, 7, 8, 9, 10mm	1	
	23487	PHBX8M-2C	8	2 ¹ /50mm	Bits Only	Molded Black Case	3, 4, 5, 6, 7, 8, 9, 10mm	1	



BIT ONLY



SOCKET AND BIT

Singles		SIZE	PART#	QTY	LIST EA	PART#	QTY	DRIVE	LIST EA
		2" Long				50mm Long			
Inch	1/8	31407	1			43407	1	3/8"	
	5/32	31409	1			43409	1	3/8"	
	3/16	31410	1			43410	1	3/8"	
	7/32	31411	1			43411	1	3/8"	
	1/4	31412	1			43412	1	3/8"	
	5/16	31413	1			43413	1	3/8"	
	3/8	31414	1			43414	1	3/8"	
	5/16	-	-			43913	1	1/2"	
	3/8	-	-			43914	1	1/2"	
	1/2	31416	1			43916	1	1/2"	
	9/16	31417	1			43917	1	1/2"	
	5/8	31418	1			43918	1	1/2"	
	3/4	31419	1			43919	1	1/2"	
		6" Long				150mm Long			
Inch	1/8	31607	1			43807	1	3/8"	
	5/32	31609	1			43809	1	3/8"	
	3/16	31610	1			43810	1	3/8"	
	7/32	31611	1			43811	1	3/8"	
	1/4	31612	1			43812	1	3/8"	
	5/16	31613	1			43813	1	3/8"	
	3/8	31614	1			43814	1	3/8"	
	1/2	31616	1			43716	1	1/2"	
	9/16	31617	1			43717	1	1/2"	
	5/8	31618	1			43718	1	1/2"	
	3/4	31619	1			43719	1	1/2"	



BIT ONLY



SOCKET AND BIT

Singles		SIZE	PART#	QTY	LIST EA	PART#	QTY	DRIVE	LIST EA
		2" Long				50mm Long			
Metric	3.0	31456	1			43456	1	3/8"	
	4.0	31460	1			43460	1	3/8"	
	5.0	31464	1			43464	1	3/8"	
	6	31468	1			43468	1	3/8"	
	7	31470	1			43470	1	3/8"	
	8	31472	1			43472	1	3/8"	
	9	31474	1			43474	1	3/8"	
	10	31476	1			43476	1	3/8"	
	12	31480	1			43480	1	3/8"	
	12	-	-			43980	1	1/2"	
	14	31484	1			43984	1	1/2"	
	17	31486	1			43986	1	1/2"	
	19	31488	1			43988	1	1/2"	
		6" Long				150mm Long			
Metric	3.0	31656	1			43856	1	3/8"	
	4.0	31660	1			43860	1	3/8"	
	5.0	31664	1			43864	1	3/8"	
	6	31668	1			43868	1	3/8"	
	7	31670	1			43870	1	3/8"	
	8	31672	1			43872	1	3/8"	
	9	31674	1			43874	1	3/8"	
	10	31676	1			43876	1	3/8"	
	12	31680	1			43780	1	1/2"	
	14	31684	1			43784	1	1/2"	
	17	31686	1			43786	1	1/2"	
	19	31688	1			43788	1	1/2"	

Star Tip Socket Bits

- ProGuard™ Finish -

- Fits all Star and TORX®* brand screws
- Bits fit any standard six point socket
- Bits are suitable for use with impact sockets
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Sharp corners transfer more torque to the screw and reduce stripping
- Precision machined for ease of use and superior fit

ProGuard™ finish
delivers superior
corrosion protection



Molded Black Case



Clamshell Package

Socket Bits

Sets	PART#	MODEL#	PCS	BIT LENGTH	DESCRIPTION	PACKED IN	CONTENTS	QTY	LIST
Star	44038	PHTX10/S-2	10	2"/50mm	Sockets & Bits	Transparent Clamshell	T10, T15, T20, T25, T27, T30, T40, T45, T50, T55	1	
	44037	PHTX13/S-2	13	2"/50mm	Sockets & Bits	Transparent Clamshell	T8, T10, T15, T20, T25, T27, T30, T40, T45, T47, T50, T55, T60	1	
	44699	PHTX9/S-6	9	6"/150mm	Sockets & Bits	Transparent Clamshell	T8, T9, T10, T15, T20, T25, T27, T30, T40	1	
	44632	PHTX8/S-6	8	6"/150mm	Sockets & Bits	Transparent Clamshell	T8, T10, T15, T20, T25, T27, T30, T40	1	
	32038	PHTX10-2	10	2"/50mm	Bits Only	Transparent Clamshell	T10, T15, T20, T25, T27, T30, T40, T45, T50, T55	1	
	32037	PHTX13-2	13	2"/50mm	Bits Only	Transparent Clamshell	T8, T10, T15, T20, T25, T27, T30, T40, T45, T47, T50, T55, T60	1	
	34099	PHTX9-6	9	6"/150mm	Bits Only	Transparent Clamshell	T8, T9, T10, T15, T20, T25, T27, T30, T40	1	
	34032	PHTX8-6	8	6"/150mm	Bits Only	Transparent Clamshell	T8, T10, T15, T20, T25, T27, T30, T40	1	
	31038	PHTX10/S-2C	10	2"/50mm	Sockets & Bits	Molded Black Case	T10, T15, T20, T25, T27, T30, T40, T45, T50, T55	1	
	30799	PHTX9/S-6C	9	6"/150mm	Sockets & Bits	Molded Black Case	T8, T9, T10, T15, T20, T25, T27, T30, T40	1	
	31037	PHTX13/S-2C	13	2"/50mm	Sockets & Bits	Molded Black Case	T8, T10, T15, T20, T25, T27, T30, T40, T45, T47, T50, T55, T60	1	
	22489	PHTX9L-2C	9	2"/50mm	Bits Only	Molded Black Case	T15, T20, T25, T30, T40, T45, T50, T55, T60	1	
	22491	PHTX9-2C	9	2"/50mm	Bits Only	Molded Black Case	T8, T9, T10, T15, T20, T25, T27, T30, T40	1	
	22437	PHTX13-2C	13	2"/50mm	Bits Only	Molded Black Case	T8, T10, T15, T20, T25, T27, T30, T40, T45, T47, T50, T55, T60	1	



BIT ONLY

SOCKET AND BIT



BIT ONLY

SOCKET AND BIT

Singles	SIZE	BIT STOCK	PART#	QTY	LIST EA	PART#	QTY	DRIVE	LIST EA	SIZE	BIT STOCK	PART#	QTY	LIST EA	PART#	QTY	DRIVE	LIST EA
	2" Long	50mm Long				6" Long	150mm Long											
Star	T7	3mm	32007	1		44007	1	1/4"		T8	3mm	34008	1		44608	1	1/4"	
	T8	3mm	32008	1		44008	1	1/4"		T9	3mm	34009	1		44609	1	1/4"	
	T9	3mm	32009	1		44009	1	1/4"		T10	3mm	34010	1		44610	1	1/4"	
	T10	3mm	32010	1		44010	1	1/4"		T15	3mm	34015	1		44615	1	1/4"	
	T15	3mm	32015	1		44015	1	1/4"		T20	4mm	34020	1		44620	1	1/4"	
	T20	4mm	32020	1		44020	1	1/4"		T25	4mm	34025	1		44625	1	1/4"	
	T25	4mm	32025	1		44025	1	1/4"		T27	5mm	34027	1		44627	1	1/4"	
	T27	5mm	32027	1		44027	1	1/4"		T30	5mm	34030	1		44630	1	1/4"	
	T30	5mm	32030	1		44030	1	1/4"		T40	6mm	34040	1		44640	1	3/8"	
	T40	6mm	32040	1		44240	1	3/8"		T45	7mm	32045	1		44245	1	3/8"	
	T45	7mm	32045	1		44245	1	3/8"		T47	8mm	32047	1		44247	1	3/8"	
	T47	8mm	32047	1		44247	1	3/8"		T50	9mm	32050	1		44250	1	3/8"	
	T50	9mm	32050	1		44250	1	3/8"		T55	10mm	32055	1		44255	1	3/8"	
	T55	10mm	32055	1		44255	1	3/8"		T60	12mm	32060	1		44260	1	1/2"	
	T60	12mm	32060	1		44260	1	1/2"		T70	17mm	32070	1		-	-	-	-
	T70	17mm	32070	1		-	-	-		T80	19mm	32080	1		-	-	-	-
	T80	19mm	32080	1		-	-	-		T90*	22mm	32090*	1		-	-	-	-
	T100*	22mm	32000*	1		-	-	-		T100*	22mm	32000*	1		-	-	-	-

*32090 (T90) & 32000 (T100) are 2.5" long.

See Next Page for our Star & Metric Hex Socket Bit combo set

Socket Bit Combo Set

- ProGuard™ Finish -

- Bits fit any standard six point socket
- Bits are suitable for use with impact sockets
- Chamfered tool tips eliminate burrs and help tools seat in screw head
- Perfect set for truck and large equipment maintenance

Hextenders



Star & Metric Hex

PART#	MODEL#	PCS	BIT LENGTH	DESCRIPTION	PACKED IN	CONTENTS	QTY	LIST
23290	PHTXH7-2C	7	2"/50mm	Bits Only	Molded Black Case	T45, T50, T55 & 12, 14, 17, 19mm	1	

Hextenders

- Extend tool reach
- Allows blades to be coupled with Hex or Star tools
- Extra length can be achieved using multiple Hextender/Blade combinations



Singles	SIZE	INCH	MM	DIA	PART#	QTY	LIST EA
Inch	.050	0.50	13	0.25	22302	1	
	1/16	0.50	13	0.25	22303	1	
	5/64	0.50	13	0.25	22304	1	
	3/32	0.50	13	0.25	22305	1	
	7/64	0.50	13	0.25	22306	1	
	1/8	0.50	13	0.31	22307	1	
	9/64	0.50	13	0.31	22308	1	
	5/32	0.75	19	0.37	22309	1	
	3/16	0.75	19	0.37	22310	1	
	7/32	0.75	19	0.50	22311	1	
Metric	1.5	0.50	13	0.25	22350	1	
	2.0	0.50	13	0.25	22352	1	
	2.5	0.50	13	0.25	22354	1	
	3.0	0.50	13	0.31	22356	1	
	4.0	0.75	19	0.37	22360	1	
	5.0	0.75	19	0.37	22364	1	
	6	0.75	19	0.50	22368	1	
	8	1.0	25	0.75	22372	1	
	10	1.0	25	0.75	22376	1	



Did you know...?

You can extend tool reach with Bondhus' exclusive Hextender which saves time because any like sized blades can be coupled together to create a tool length for every need.

Ball End Blades

- ProGuard™ Finish -

- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- Superior Ball End strength and working angle
- Works in hard to reach places
- Ideal for use in socket wrenches, power tools or with a Hextender for added reach
- Available in Extra Long lengths

Bits and Blades

ProGuard™ finish
delivers superior
corrosion protection



Ball End Tips

SINGLE PACKAGING

PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
---------	------	------	----	-------	-----	---------

Standard Length

Inch	.050	3.4	86	0102	1
1/16	3.5	89		0103	1
5/64	3.6	93		0104	1
3/32	3.8	96		0105	1
7/64	4.3	109		0106	1
1/8	4.5	115		0107	1
9/64	4.8	121		0108	1
5/32	5.1	129		0109	1
3/16	5.5	139		0110	1
7/32	5.9	151		0111	1
1/4	6.7	170		0112	1
5/16	7.3	186		0113	1
3/8	8.2	208		0114	1
7/16	9.1	232		0115	1
1/2	10.1	255		0116	1
9/16	10.9	277		0117	1
5/8	11.8	299		0118	1
3/4	13.5	344		0119	1

SINGLE PACKAGING

PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
---------	------	------	----	-------	-----	---------

Standard Length

Metric	1.5	3.6	91	0150	1
2.0	3.8	98	0152	1	
2.5	4.2	107	0154	1	
3.0	4.6	118	0156	1	
3.5	4.8	123	0158	1	
4.0	5.2	133	0160	1	
4.5	5.5	140	0162	1	
5.0	5.8	148	0164	1	
5.5	6.1	155	0166	1	
6	6.7	170	0168	1	
7	7.3	184	0170	1	
8	7.8	199	0172	1	
9	8.4	214	0174	1	
10	9.0	229	0176	1	
11	9.6	245	0178	1	
12	10.5	267	0180	1	
14	12.5	318	0184	1	
17	13.6	346	0186	1	
19	14.5	368	0188	1	

SINGLE PACKAGING

PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
---------	------	------	----	-------	-----	---------

Long

Inch	-	-	-	-	-
5/64	5.3	135		0404	1
3/32	5.8	148		0405	1
7/64	7.3	186		0406	1
1/8	7.8	199		0407	1
9/64	8.4	214		0408	1
5/32	8.9	227		0409	1
3/16	9.7	246		0410	1
7/32	10.2	259		0411	1
1/4	10.7	270		0412	1
5/16	11.3	286		0413	1
3/8	11.7	297		0414	1
-	-	-		-	-
-	-	-		-	-

SINGLE PACKAGING

PACKAGED

SIZE	INCH	MM	PART#	QTY	LIST EA
------	------	----	-------	-----	---------

Extra Long

.050	12.0	305	3602	1
1/16	12.0	305	3603	1
5/64	12.0	305	3604	1
3/32	12.0	305	3605	1
7/64	12.0	305	3606	1
1/8	12.0	305	3607	1
9/64	12.0	305	3608	1
5/32	12.0	305	3609	1
3/16	12.0	305	3610	1
7/32	12.0	305	3611	1
1/4	12.0	305	3612	1
5/16	12.0	305	3613	1
3/8	12.0	305	3614	1
7/16	12.0	305	3615	1
1/2	12.0	305	3616	1

Metric	Long				
--------	------	--	--	--	--

SINGLE PACKAGING

PACKAGED

Metric	2.0	5.0	128	0452	1
2.5	5.8	148		0454	1
3.0	7.6	193		0456	1
4.0	8.5	217		0460	1
5.0	9.6	243		0464	1
6	10.4	263		0468	1
8	11.1	281		0472	1
10	11.9	303		0476	1

SINGLE PACKAGING

PACKAGED

Extra Long				
------------	--	--	--	--

1.5	12.0	305	3650	1
2.0	12.0	305	3652	1
2.5	12.0	305	3654	1
3.0	12.0	305	3656	1
4.0	12.0	305	3660	1
5.0	12.0	305	3664	1
6	12.0	305	3668	1
8	12.0	305	3672	1
10	12.0	305	3676	1

Ball End Insert Bits

- ProGuard™ Finish -

- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- Superior Ball End strength and working angle
- Works in hard to reach places

Bits and Blades

ProGuard™ finish
delivers superior
corrosion protection



Ball End Tips

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Inch	11036	BIX12	12	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2"	1	
Metric	11099	BIX9M	9	2, 2.5, 3, 4, 5, 6, 8, 10, 12mm	1	

SINGLE PACKAGING



PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
Inch	5/64	1.0	25	11004	10	
	3/32	1.0	25	11005	10	
	7/64	1.0	25	11006	10	
	1/8	1.0	25	11007	10	
	9/64	1.0	25	11008	10	
	5/32	1.0	25	11009	10	
	3/16	1.0	25	11010	10	
	7/32	1.0	25	11011	10	
	1/4	1.0	25	11012	10	
	5/16	1.5	38	11013	1	
	3/8	1.5	38	11014	1	
	1/2	1.5	38	11016	1	

SINGLE PACKAGING



PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
Metric	2.0	1.0	25	11052	10	
	2.5	1.0	25	11054	10	
	3.0	1.0	25	11056	10	
	4.0	1.0	25	11060	10	
	5.0	1.0	25	11064	10	
	6	1.0	25	11068	10	
	8	1.5	38	11072	1	
	10	1.5	38	11076	1	
	12	1.5	38	11080	1	

Ball End Power Bits

- ProGuard™ Finish -

- Ball End inserts into a screw at a 25° angle
- Ball End saves time by quickly funneling tool into screw
- Superior Ball End strength and working angle
- Works in hard to reach places

ProGuard™ finish
delivers superior
corrosion protection



Ball End Tips

Sets	PART#	MODEL#	PCS	CONTENTS	QTY	LIST
Inch	10836	BHX12	12	5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8, 1/2"	1	
Metric	10899	BHX9M	9	2, 2.5, 3, 4, 5, 6, 8, 10, 12mm	1	

SINGLE PACKAGING



PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
Inch	5/64	3.0	76	10804	10	
	3/32	3.0	76	10805	10	
	7/64	3.0	76	10806	10	
	1/8	3.0	76	10807	10	
	9/64	3.0	76	10808	10	
	5/32	3.0	76	10809	10	
	3/16	3.0	76	10810	10	
	7/32	3.0	76	10811	10	
	1/4	3.0	76	10812	10	
	5/16	3.0	76	10813	1	
	3/8	3.0	76	10814	1	
	1/2	3.0	76	10816	1	

SINGLE PACKAGING



PACKAGED

Singles	SIZE	INCH	MM	PART#	QTY	LIST EA
Metric	2.0	3.0	76	10852	10	
	2.5	3.0	76	10854	10	
	3.0	3.0	76	10856	10	
	4.0	3.0	76	10860	10	
	5.0	3.0	76	10864	10	
	6	3.0	76	10868	10	
	8	3.0	76	10872	1	
	10	3.0	76	10876	1	
	12	3.0	76	10880	1	

Part Number Index

PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA
0102	47	3668	47	10752	35	10986	7	12129	11	12262	13			
0103	47	3672	47	10754	35	10988	7	12132	10	12264	13			
0104	47	3676	47	10756	35	10989	7	12136	10	12266	13			
0105	47	3702	36	10760	35	10991	7	12137	10	12268	13			
0106	47	3703	36	10764	35	10992	7	12138	10	12270	13			
0107	47	3704	36	10768	35	10993	7	12145	10	12272	13			
0108	47	3705	36	10772	35	10995	7	12146	12	12274	13			
0109	47	3706	36	10776	35	10999	7	12147	13	12276	13			
0110	47	3707	36	10804	48	11004	48	12148	13	12278	13			
0111	47	3708	36	10805	48	11005	48	12149	13	12280	13			
0112	47	3709	36	10806	48	11006	48	12150	13	12284	13			
0113	47	3710	36	10807	48	11007	48	12152	13	12286	13			
0114	47	3711	36	10808	48	11008	48	12154	13	12288	13			
0115	47	3712	36	10809	48	11009	48	12156	13	12291	13			
0116	47	3713	36	10810	48	11010	48	12158	13	12292	12			
0117	47	3714	36	10811	48	11011	48	12160	13	12293	13			
0118	47	3715	36	10812	48	11012	48	12162	13	12295	13			
0119	47	3716	36	10813	48	11013	48	12164	13	12296	13			
0150	47	3750	36	10814	48	11014	48	12166	13	12298	13			
0152	47	3752	36	10816	48	11016	48	12168	13	12299	12			
0154	47	3754	36	10836	48	11036	48	12170	13	12333	10			
0156	47	3756	36	10852	48	11052	48	12172	13	12335	10			
0158	47	3760	36	10854	48	11054	48	12174	13	12338	10			
0160	47	3764	36	10856	48	11056	48	12176	13	12339	10			
0162	47	3768	36	10860	48	11060	48	12178	13	12341	10			
0164	47	3772	36	10864	48	11064	48	12180	13	12342	10			
0166	47	3776	36	10868	48	11068	48	12184	13	12343	10			
0168	47	10602	35	10872	48	11072	48	12186	13	12344	10			
0170	47	10603	35	10876	48	11076	48	12188	13	12345	10			
0172	47	10604	35	10880	48	11080	48	12191	13	12347	10			
0174	47	10605	35	10899	48	11099	48	12192	12	12349	12			
0176	47	10606	35	10902	6	11331	22	12193	13	12351	10			
0178	47	10607	35	10903	6	11332	22	12195	12	12391	12			
0180	47	10608	35	10904	6	11346	22	12196	13	12392	12			
0184	47	10609	35	10905	6	11600	40	12198	13	12393	12			
0186	47	10610	35	10906	6	11601	40	12199	12	12394	12			
0188	47	10611	35	10907	6	11602	40	12200	11	12396	12			
0404	47	10612	35	10908	6	11603	40	12201	11	12397	12			
0405	47	10613	35	10909	6	11604	40	12202	11	12399	12			
0406	47	10614	35	10910	6	11640	40	12203	11	12522	25			
0407	47	10615	35	10911	6	11706	22	12204	11	12531	27			
0408	47	10616	35	10912	6	11707	22	12205	11	12533	25			
0409	47	10632	35	10913	6	11708	22	12206	11	12540	26			
0410	47	10633	35	10914	6	11709	22	12207	11	12543	26			
0411	47	10637	35	10915	6	11710	22	12208	11	12544	25			
0412	47	10645	35	10916	6	11715	22	12209	11	12545	26			
0413	47	10649	35	10917	6	11720	22	12210	11	12547	26			
0414	47	10650	35	10918	6	11725	22	12211	11	12550	25			
0452	47	10652	35	10919	6	11727	22	12212	11	12585	25			
0454	47	10654	35	10920	6	11730	22	12213	11	12587	25			
0456	47	10656	35	10921	6	11740	22	12214	11	12589	25			
0460	47	10658	35	10932	6	11745	22	12215	11	12591	25			
0464	47	10660	35	10933	6	11750	22	12216	11	12592	25			
0468	47	10662	35	10935	6	11755	22	12217	11	12594	27			
0472	47	10664	35	10936	6	12100	11	12218	11	12595	25			
0476	47	10666	35	10937	6	12101	11	12219	11	12632	26			
3602	47	10668	35	10938	6	12102	11	12220	11	12634	26			
3603	47	10670	35	10945	6	12103	11	12221	11	12636	26			
3604	47	10672	35	10946	7	12104	11	12225	11	12638	26			
3605	47	10674	35	10949	7	12105	11	12229	11	12699	21			
3606	47	10676	35	10950	7	12106	11	12231	11	12706	39			
3607	47	10686	35	10952	7	12107	11	12232	10	12707	39			
3608	47	10687	35	10954	7	12108	11	12233	11	12708	39			
3609	47	10699	35	10956	7	12109	11	12236	10	12709	39			
3610	47	10704	35	10958	7	12110	11	12237	10	12710	39			
3611	47	10705	35	10960	7	12111	11	12238	10	12715	39			
3612	47	10706	35	10962	7	12112	11	12245	10	12720	39			
3613	47	10707	35	10964	7	12113	11	12246	12	12725	39			
3614	47	10708	35	10966	7	12114	11	12247	13	12727	39			
3615	47	10709	35	10968	7	12115	11	12248	13	12730	39			
3616	47	10710	35	10970	7	12116	11	12249	13	12740	39			
3650	47	10711	35	10972	7	12117	11	12250	13	12745	39			
3652	47	10712	35	10974	7	12118	11	12252	13	12750	39			
3654	47	10713	35	10976	7	12119	11	12254	13	12755	39			
3656	47	10714	35	10978	7	12120	11	12256	13	12894	25			
3660	47	10733	35	10980	7	12121	11	12258	13	12897	25			
3664	47	10737	35	10984	7	12125	11	12260	13	12902	6			

Part Number Index

PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA
12903	6	13360	32	13954	13	15360	32	15866	13	16100	17			
12904	6	13364	32	13956	13	15364	32	15868	13	16101	17			
12905	6	13368	32	13958	13	15368	32	15870	13	16102	17			
12906	6	13372	32	13960	13	15372	32	15872	13	16103	17			
12907	6	13376	32	13962	13	15376	32	15874	13	16104	17			
12908	6	13387	31	13964	13	15387	31	15876	13	16105	17			
12909	6	13389	31	13966	13	15389	31	15878	13	16106	17			
12910	6	13390	31	13968	13	15390	31	15880	13	16107	17			
12911	6	13532	39	13970	13	15702	6	15884	13	16108	17			
12912	6	13546	39	13972	13	15703	6	15886	13	16109	17			
12913	6	13800	11	13974	13	15704	6	15888	13	16110	17			
12914	6	13801	11	13976	13	15705	6	15900	11	16111	17			
12915	6	13802	11	13978	13	15706	6	15901	11	16112	17			
12916	6	13803	11	13980	13	15707	6	15902	11	16113	17			
12917	6	13804	11	13984	13	15708	6	15903	11	16114	17			
12918	6	13805	11	13986	13	15709	6	15904	11	16115	17			
12919	6	13806	11	13988	13	15710	6	15905	11	16116	17			
12949	7	13807	11	14126	5	15711	6	15906	11	16117	17			
12950	7	13808	11	14128	5	15712	6	15907	11	16118	17			
12952	7	13809	11	14130	5	15713	6	15908	11	16119	17			
12954	7	13810	11	14132	5	15714	6	15909	11	16136	17			
12956	7	13811	11	14138	5	15715	6	15910	11	16137	17			
12958	7	13812	11	14187	5	15716	6	15911	11	16138	17			
12960	7	13813	11	14189	5	15717	6	15912	11	16200	17			
12962	7	13814	11	14532	27	15718	6	15913	11	16201	17			
12964	7	13815	11	14534	27	15719	6	15914	11	16202	17			
12966	7	13816	11	14585	27	15749	7	15915	11	16203	17			
12968	7	13817	11	14587	27	15750	7	15916	11	16204	17			
12970	7	13818	11	14589	27	15752	7	15917	11	16205	17			
12972	7	13819	11	14590	27	15754	7	15918	11	16206	17			
12974	7	13847	13	14591	27	15756	7	15919	11	16207	17			
12976	7	13848	13	14592	27	15758	7	15947	13	16208	17			
12978	7	13849	13	14595	27	15760	7	15948	13	16209	17			
12980	7	13850	13	15205	32	15762	7	15949	13	16210	17			
12984	7	13852	13	15206	32	15764	7	15950	13	16211	17			
12986	7	13854	13	15207	32	15766	7	15952	13	16212	17			
12988	7	13856	13	15208	32	15768	7	15954	13	16213	17			
13109	29	13858	13	15209	32	15770	7	15956	13	16214	17			
13110	29	13860	13	15210	32	15772	7	15958	13	16215	17			
13111	29	13862	13	15211	32	15774	7	15960	13	16216	17			
13112	29	13864	13	15212	32	15776	7	15962	13	16217	17			
13113	29	13866	13	15213	32	15778	7	15964	13	16218	17			
13114	29	13868	13	15214	32	15780	7	15966	13	16219	17			
13138	29	13870	13	15216	32	15784	7	15968	13	16236	17			
13146	29	13872	13	15232	31	15786	7	15970	13	16237	17			
13148	29	13874	13	15238	31	15788	7	15972	13	16238	17			
13160	29	13876	13	15248	31	15800	11	15974	13	16246	17			
13164	29	13878	13	15252	32	15801	11	15976	13	16247	17			
13168	29	13880	13	15254	32	15802	11	15978	13	16248	17			
13172	29	13884	13	15256	32	15803	11	15980	13	16249	17			
13176	29	13886	13	15260	32	15804	11	15984	13	16250	17			
13187	29	13888	13	15264	32	15805	11	15986	13	16252	17			
13189	29	13900	11	15268	32	15806	11	15988	13	16254	17			
13190	29	13901	11	15270	32	15807	11	16002	6	16256	17			
13205	29	13902	11	15272	32	15808	11	16003	6	16258	17			
13206	29	13903	11	15274	32	15809	11	16004	6	16260	17			
13207	29	13904	11	15276	32	15810	11	16005	6	16262	17			
13208	29	13905	11	15287	31	15811	11	16006	6	16264	17			
13252	29	13906	11	15289	31	15812	11	16007	6	16266	17			
13254	29	13907	11	15290	31	15813	11	16008	6	16268	17			
13256	29	13908	11	15305	32	15814	11	16009	6	16270	17			
13305	32	13909	11	15306	32	15815	11	16010	6	16272	17			
13306	32	13910	11	15307	32	15816	11	16011	6	16274	17			
13307	32	13911	11	15308	32	15817	11	16012	6	16276	17			
13308	32	13912	11	15309	32	15818	11	16013	6	16278	17			
13309	32	13913	11	15310	32	15819	11	16014	6	16280	17			
13310	32	13914	11	15311	32	15847	13	16037	6	16284	17			
13311	32	13915	11	15312	32	15848	13	16050	7	16286	17			
13312	32	13916	11	15313	32	15849	13	16052	7	16288	17			
13313	32	13917	11	15314	32	15850	13	16054	7	16292	17			
13314	32	13918	11	15316	32	15852	13	16056	7	16299	17			
13332	31	13919	11	15332	31	15854	13	16060	7	16456	32			
13338	31	13947	13	15338	31	15856	13	16064	7	16460	32			
13348	31	13948	13	15348	31	15858	13	16068	7	16464	32			
13352	32	13949	13	15352	32	15860	13	16072	7	16468	32			
13354	32	13950	13	15354	32	15862	13	16076	7	16472	32			
13356	32	13952	13	15356	32	15864	13	16099	7	16502	9			

Part Number Index

PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA
16503	9	16768	16	17935	29	26107	17	26714	16	28056	18			
16504	9	16772	16	17936	29	26108	17	26749	16	28058	18			
16505	9	16776	16	18032	40	26109	17	26750	16	28060	18			
16506	9	16792	16	18036	40	26110	17	26752	16	28062	18			
16507	9	16799	16	18037	40	26111	17	26754	16	28064	18			
16508	9	16902	15	18038	40	26112	17	26756	16	28066	18			
16509	9	16903	15	18045	40	26113	17	26760	16	28068	18			
16510	9	16904	15	18046	40	26114	17	26764	16	28070	18			
16511	9	16905	15	18099	40	26200	17	26768	16	28072	18			
16512	9	16906	15	20196	5	26201	17	26772	16	28074	18			
16513	9	16907	15	20199	5	26202	17	26776	16	28076	18			
16514	9	16908	15	20399	5	26203	17	26902	15	28078	18			
16537	9	16909	15	20499	5	26204	17	26903	15	28080	18			
16538	9	16910	15	20599	5	26205	17	26904	15	28100	19			
16549	9	16911	15	20899	5	26206	17	26905	15	28101	19			
16550	9	16912	15	22199	5	26207	17	26906	15	28102	19			
16552	9	16913	15	22302	46	26208	17	26907	15	28103	19			
16554	9	16914	15	22303	46	26209	17	26908	15	28104	19			
16556	9	16915	15	22304	46	26210	17	26909	15	28105	19			
16560	9	16916	15	22305	46	26211	17	26910	15	28106	19			
16564	9	16917	15	22306	46	26212	17	26911	15	28107	19			
16568	9	16918	15	22307	46	26213	17	26912	15	28108	19			
16572	9	16919	15	22308	46	26214	17	26913	15	28109	19			
16576	9	16936	15	22309	46	26247	17	26914	15	28110	19			
16592	9	16937	15	22310	46	26248	17	27049	15	28111	19			
16599	9	16938	15	22311	46	26249	17	27050	15	28112	19			
16602	37	17046	15	22312	46	26250	17	27052	15	28113	19			
16603	37	17049	15	22313	46	26252	17	27054	15	28114	19			
16604	37	17050	15	22314	46	26254	17	27056	15	28200	19			
16605	37	17052	15	22350	46	26256	17	27058	15	28201	19			
16606	37	17054	15	22352	46	26258	17	27060	15	28202	19			
16607	37	17056	15	22354	46	26260	17	27062	15	28203	19			
16608	37	17058	15	22356	46	26262	17	27064	15	28204	19			
16609	37	17060	15	22360	46	26264	17	27066	15	28205	19			
16610	37	17062	15	22364	46	26266	17	27068	15	28206	19			
16611	37	17064	15	22368	46	26268	17	27070	15	28207	19			
16612	37	17066	15	22372	46	26270	17	27072	15	28208	19			
16613	37	17068	15	22376	46	26272	17	27074	15	28209	19			
16614	37	17070	15	22437	45	26274	17	27076	15	28210	19			
16615	37	17072	15	22489	45	26276	17	27078	15	28211	19			
16616	37	17074	15	22491	45	26278	17	27080	15	28212	19			
16632	37	17076	15	22704	10	26280	17	27147	17	28213	19			
16637	37	17078	15	22705	10	26502	9	27148	17	28214	19			
16649	37	17080	15	22706	10	26503	9	27149	17	28247	19			
16650	37	17084	15	22707	10	26504	9	27150	17	28248	19			
16652	37	17086	15	22708	10	26505	9	27152	17	28249	19			
16654	37	17088	15	22709	10	26506	9	27154	17	28250	19			
16656	37	17092	15	22710	10	26507	9	27156	17	28252	19			
16660	37	17095	15	22711	10	26508	9	27158	17	28254	19			
16664	37	17099	15	22712	10	26509	9	27160	17	28256	19			
16668	37	17146	17	22713	10	26510	9	27162	17	28258	19			
16672	37	17147	17	22714	10	26511	9	27164	17	28260	19			
16676	37	17148	17	22789	10	26512	9	27166	17	28262	19			
16686	37	17149	17	23246	43	26513	9	27168	17	28264	19			
16699	37	17150	17	23290	46	26514	9	27170	17	28266	19			
16702	16	17152	17	23296	43	26549	9	27172	17	28268	19			
16703	16	17154	17	23298	43	26550	9	27174	17	28270	19			
16704	16	17156	17	23299	43	26552	9	27176	17	28272	19			
16705	16	17158	17	23445	44	26554	9	27178	17	28274	19			
16706	16	17160	17	23487	44	26556	9	27180	17	28276	19			
16707	16	17162	17	25404	10	26560	9	27902	18	28278	19			
16708	16	17164	17	25405	10	26564	9	27903	18	28280	19			
16709	16	17166	17	25406	10	26568	9	27904	18	29147	19			
16710	16	17168	17	25407	10	26572	9	27905	18	29148	19			
16711	16	17170	17	25408	10	26576	9	27906	18	29149	19			
16712	16	17172	17	25409	10	26702	16	27907	18	29150	19			
16713	16	17174	17	25410	10	26703	16	27908	18	29152	19			
16714	16	17176	17	25411	10	26704	16	27909	18	29154	19			
16737	16	17178	17	25412	10	26705	16	27910	18	29156	19			
16738	16	17180	17	25445	10	26706	16	27911	18	29158	19			
16749	16	17184	17	26100	17	26707	16	27912	18	29160	19			
16750	16	17186	17	26101	17	26708	16	27913	18	29162	19			
16752	16	17188	17	26102	17	26709	16	27914	18	29164	19			
16754	16	17192	17	26103	17	26710	16	28049	18	29166	19			
16756	16	17195	17	26104	17	26711	16	28050	18	29168	19			
16760	16	17199	17	26105	17	26712	16	28052	18	29170	19			
16764	16	17934	29	26106	17	26713	16	28054	18	29172	19			

Part Number Index

PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA	PART#	PG#	LIST EA
29174	19		31734	21		32809	21		33613	43		34555	38	
29176	19		31737	21		32810	21		33614	43		34560	38	
29178	19		31740	21		32815	21		33616	43		34706	23	
29180	19		31745	21		32820	21		33617	43		34707	23	
30298	43		31750	21		32825	21		33618	43		34708	23	
30299	43		31755	21		32827	21		33619	43		34709	23	
30445	44		31760	21		32830	21		33645	43		34710	23	
30487	44		31806	21		32840	21		33646	43		34715	23	
30645	43		31807	21		32845	21		33656	43		34720	23	
30646	43		31808	21		32850	21		33660	43		34745	23	
30799	45		31809	21		32855	21		33664	43		35006	23	
30845	44		31810	21		32860	21		33668	43		35007	23	
30887	44		31815	21		33009	33		33670	43		35008	23	
31037	45		31820	21		33010	33		33672	43		35009	23	
31038	45		31825	21		33015	33		33674	43		35010	23	
31407	44		31827	21		33020	33		33676	43		35015	23	
31409	44		31830	21		33025	33		33680	43		35020	23	
31410	44		31832	21		33027	33		33684	43		35045	23	
31411	44		31834	21		33030	33		33686	43		37902	18	
31412	44		31840	21		33034	33		33688	43		37903	18	
31413	44		31845	21		33040	33		33806	39		37904	18	
31414	44		31850	21		33045	33		33807	39		37905	18	
31416	44		31855	21		33050	33		33808	39		37906	18	
31417	44		31860	21		33055	33		33809	39		37907	18	
31418	44		32000	45		33200	43		33810	39		37908	18	
31419	44		32007	45		33207	43		33815	39		37909	18	
31445	44		32008	45		33209	43		33820	39		37910	18	
31456	44		32009	45		33210	43		33825	39		37911	18	
31460	44		32010	45		33211	43		33827	39		37912	18	
31464	44		32015	45		33212	43		33830	39		37913	18	
31468	44		32020	45		33213	43		33832	39		37914	18	
31470	44		32025	45		33214	43		33834	39		37915	18	
31472	44		32027	45		33216	43		33840	39		37916	18	
31474	44		32030	45		33217	43		33906	23		37917	18	
31476	44		32037	45		33218	43		33907	23		37918	18	
31480	44		32038	45		33219	43		33908	23		37919	18	
31484	44		32040	45		33220	43		33909	23		37936	18	
31486	44		32045	45		33221	43		33910	23		37937	18	
31487	44		32047	45		33223	43		33915	23		37938	18	
31488	44		32050	45		33225	43		33920	23		38046	18	
31607	44		32055	45		33229	43		33945	23		38049	18	
31609	44		32060	45		33231	43		34008	45		38050	18	
31610	44		32070	45		33233	43		34009	45		38052	18	
31611	44		32080	45		33256	43		34010	45		38054	18	
31612	44		32090	45		33260	43		34015	45		38056	18	
31613	44		32406	14, 22		33264	43		34020	45		38058	18	
31614	44		32407	14, 22		33268	43		34025	45		38060	18	
31616	44		32408	14, 22		33270	43		34027	45		38062	18	
31617	44		32409	14, 22		33272	43		34030	45		38064	18	
31618	44		32410	14, 22		33274	43		34032	45		38066	18	
31619	44		32415	14, 22		33276	43		34040	45		38068	18	
31645	44		32420	14, 22		33280	43		34099	45		38070	18	
31656	44		32425	14, 22		33284	43		34405	23		38072	18	
31660	44		32427	14, 22		33286	43		34406	23		38074	18	
31664	44		32430	14, 22		33288	43		34407	23		38076	18	
31668	44		32432	14, 22		33291	43		34408	23		38078	18	
31670	44		32434	14, 22		33293	43		34409	23		38080	18	
31672	44		32440	14, 22		33295	43		34410	23		38084	18	
31674	44		32705	21		33297	43		34415	23		38086	18	
31676	44		32706	21		33298	43		34420	23		38088	18	
31680	44		32707	21		33299	43		34445	23		38092	18	
31684	44		32708	21		33406	14, 22		34505	38		38095	18	
31686	44		32709	21		33407	14, 22		34506	38		38099	18	
31687	44		32710	21		33408	14, 22		34507	38		38100	19	
31688	44		32715	21		33409	14, 22		34508	38		38101	19	
31705	21		32720	21		33410	14, 22		34509	38		38102	19	
31706	21		32725	21		33415	14, 22		34510	38		38103	19	
31707	21		32727	21		33420	14, 22		34515	38		38104	19	
31708	21		32730	21		33425	14, 22		34520	38		38105	19	
31709	21		32740	21		33427	14, 22		34525	38		38106	19	
31710	21		32745	21		33430	14, 22		34527	38		38107	19	
31715	21		32750	21		33440	14, 22		34530	38		38108	19	
31720	21		32755	21		33607	43		34532	38		38109	19	
31725	21		32760	21		33609	43		34534	38		38110	19	
31727	21		32806	21		33610	43		34540	38		38111	19	
31730	21		32807	21		33611	43		34545	38		38112	19	
31732	21		32808	21		33612	43		34550	38		38113	19	

Part Number Index

PART#	PG#	LIST EA														
38482	41		40672	35		43784	44		48305	14		72827	21		75703	8
38602	37		40676	35		43786	44		48307	14		72830	21		75704	8
38603	37		43207	43		43788	44		48309	14		72840	21		75705	8
38604	37		43209	43		43807	44		48310	14		72845	21		75706	8
38605	37		43210	43		43809	44		48311	14		72850	21		75707	8
38606	37		43211	43		43810	44		48312	14		72855	21		75708	8
38607	37		43212	43		43811	44		48313	14		72860	21		75709	8
38608	37		43213	43		43812	44		48314	14		74009	33		75710	8
38609	37		43214	43		43813	44		48332	14		74010	33		75711	8
38610	37		43216	43		43814	44		48354	14		74015	33		75712	8
38611	37		43217	43		43845	44		48356	14		74020	33		75713	8
38612	37		43218	43		43856	44		48360	14		74025	33		75714	8
38613	37		43219	43		43860	44		48364	14		74027	33		75749	8
38614	37		43256	43		43864	44		48368	14		74030	33		75750	8
38615	37		43260	43		43868	44		48372	14		74034	33		75752	8
38616	37		43264	43		43870	44		48376	14		74040	33		75754	8
38632	37		43268	43		43872	44		48386	14		74045	33		75756	8
38637	37		43270	43		43874	44		48409	41		74050	33		75760	8
38649	37		43272	43		43876	44		48410	41		74055	33		75764	8
38650	37		43274	43		43887	44		48411	41		74602	36		75768	8
38652	37		43276	43		43913	44		48412	41		74603	36		75772	8
38654	37		43280	43		43914	44		48413	41		74604	36		75776	8
38656	37		43284	43		43916	44		48414	41		74605	36		75902	8
38660	37		43286	43		43917	44		48415	41		74606	36		75903	8
38664	37		43288	43		43918	44		48416	41		74607	36		75904	8
38668	37		43298	43		43919	44		48432	41		74608	36		75905	8
38672	37		43299	43		43980	44		48435	41		74609	36		75906	8
38676	37		43407	44		43984	44		48445	41		74610	36		75907	8
38686	37		43409	44		43986	44		48460	41		74611	36		75908	8
38699	37		43410	44		43988	44		48464	41		74612	36		75909	8
39146	19		43411	44		44007	45		48466	41		74613	36		75910	8
39147	19		43412	44		44008	45		48468	41		74614	36		75911	8
39148	19		43413	44		44009	45		48470	41		74632	36		75912	8
39149	19		43414	44		44010	45		48472	41		74637	36		75913	8
39150	19		43445	44		44015	45		48474	41		74649	36		75914	8
39152	19		43456	44		44020	45		48476	41		74650	36		75949	8
39154	19		43460	44		44025	45		48478	41		74652	36		75950	8
39156	19		43464	44		44027	45		48480	41		74654	36		75952	8
39158	19		43468	44		44030	45		48482	41		74656	36		75954	8
39160	19		43470	44		44037	45		48492	41		74660	36		75956	8
39162	19		43472	44		44038	45		48496	41		74664	36		75960	8
39164	19		43474	44		44240	45	53109	29			74668	36		75964	8
39166	19		43476	44		44245	45	53110	29			74672	36		75968	8
39168	19		43480	44		44247	45	53111	29			74676	36		75972	8
39170	19		43487	44		44250	45	53112	29			74686	36		75976	8
39172	19		43507	43		44255	45	53113	29			74699	36		193102	36
39174	19		43509	43		44260	45	53114	29			74937	8		193103	36
39176	19		43510	43		44608	45	53160	29			74938	8		193104	36
39178	19		43511	43		44609	45	53164	29			74992	8		193105	36
39180	19		43512	43		44610	45	53168	29			74999	8		193106	36
39184	19		43513	43		44615	45	53172	29			75109	30		193107	36
39186	19		43514	43		44620	45	53176	29			75110	30		193108	36
39188	19		43613	43		44625	45	53205	29			75111	30		193109	36
39192	19		43614	43		44627	45	53206	29			75112	30		193110	36
39195	19		43616	43		44630	45	53207	29			75113	30		193111	36
39199	19		43617	43		44632	45	53208	29			75114	30		193112	36
40602	35		43618	43		44640	45	53252	29			75146	30		193113	36
40603	35		43619	43		44699	45	53254	29			75148	30		193114	36
40604	35		43645	43		45205	32	53256	29			75160	30		193115	36
40605	35		43646	43		45206	32	71809	21			75164	30		193116	36
40606	35		43656	43		45207	32	71810	21			75168	30		193150	36
40607	35		43660	43		45208	32	71815	21			75172	30		193152	36
40608	35		43664	43		45209	32	71820	21			75176	30		193154	36
40609	35		43668	43		45210	32	71825	21			75509	38		193156	36
40610	35		43670	43		45211	32	71827	21			75510	38		193160	36
40611	35		43672	43		45212	32	71830	21			75515	38		193164	36
40612	35		43674	43		45213	32	71834	21			75520	38		193168	36
40613	35		43676	43		45214	32	71840	21			75525	38		193172	36
40614	35		43680	43		45216	32	71845	21			75527	38		193176	36
40649	35		43684	43		45252	32	71850	21			75530	38			
40650	35		43686	43		45254	32	71855	21			75534	38			
40652	35		43688	43		45256	32	71860	21			75540	38			
40654	35		43716	44		45260	32	72809	21			75545	38			
40656	35		43717	44		45264	32	72810	21			75550	38			
40660	35		43718	44		45268	32	72815	21			75555	38			
40664	35		43719	44		45272	32	72820	21			75560	38			
40668	35		43780	44		45276	32	72825	21			75702	8			

NOTES



Torque & Interchangeability

Hex Size Inch	Torque Capacity**				Screw Interchangeability				
	Bondhus Straight Hex		Bondhus Ball End Tip						
	in-lb	Nm	in-lb	Nm					
.050	7.9	0.892	3	0.339	0	1, 2	1, 2	3, 4	—
1/16	15.9	1.796	7	0.0791	1	3, 4	3, 4	5, 6	—
5/64	34	3.842	13	1.469	2, 3	5, 6	5, 6	8	—
3/32	51	5.763	24	2.712	4, 5	8	8	10	—
7/64	84	9.492	39	4.407	6	10	—	—	—
1/8	129	14.57	57	6.441	—	—	10	1/4	1/4
9/64	185	20.90	86	9.718	8	1/4	—	—	—
5/32	265	29.94	127	14.35	10	5/16	1/4	5/16	5/16
3/16	431	48.7	189	21.35	1/4	3/8	5/16	3/8	3/8
7/32	673	76.04	318	35.93	—	7/16	3/8	7/16	—
1/4	950	107.3	482	54.44	5/16	1/2	—	1/2	1/2
5/16	2022	228.4	888	100.3	3/8	5/8	1/2	5/8	5/8
3/8	3005	339.5	14.88	168.1	7/16, 1/2	—	5/8	3/4	3/4
7/16	4047	457.3	1661	187.7	9/16	3/4	—	—	—
1/2	6033	681.7	2451	277.0	5/8	—	—	7/8	1
9/16	8605	972.2	3459	390.8	—	—	—	1, 1-1/8	—
5/8	11819	1335.4	4711	532.3	3/4	—	—	1-1/4, 1-3/8	1-1/4
3/4	20424	2307.6	8052	909.8	7/8, 1	—	—	1-1/2	—
Hex Size Metric	in-lb	Nm	in-lb	Nm					
1.27	7.9	.892	3	3.39	1.4	—	—	2.5	—
1.5	13.1	1.480	5	.565	1.6, 2	—	—	3	—
2	33	3.729	13	1.469	2.5	3	3	4	—
2.5	63	7.119	33	3.729	3	1.469	2.5	5	—
3	106	11.97	52	5.876	4	5	5	6	5
3.5	143	16.13	70	7.910	—	—	—	—	—
4	264	29.83	131	14.8	5	6	6	8	6
4.5	305	34.50	147	16.6	—	—	—	—	—
5	483	54.57	247	27.91	6	8	8	10	8
5.5	559	63.24	270	30.5	—	—	—	—	—
6	855	96.61	396	44.74	8	10	10	12	10
7	1090.8	123.2	549	62.1	—	—	—	—	—
8	1861	210.2	989	111.7	10	12	12	14, 16	12
9	2326	262.8	1132	128.0	—	—	—	—	—
10	3563	402.6	1591	179.7	12	14, 16	14, 16	18, 20	16
12	5103	576.6	2022	228.5	14	18, 20	18, 20	22, 24	20
14	8081	913.0	3215	363.5	16, 18	22, 24	22, 24	—	—
17	14507	1639.1	5694	643.3	20, 22	—	—	—	—
19	20285	2291.9	8052	909.8	24, 27	—	—	—	—
Star Size	Bondhus Straight Star								
	in-lb	Nm	in-lb	Nm					
T5	3.8	0.4	—	—	—	—	—	3	—
T6	6.6	0.7	4	0.45	—	2	—	4	—
T7	12	1.4	9	1.0	—	3	2	5, 6	—
T8	20	2.3	16	1.8	—	4	3	8	—
T9	25	2.8	19	2.1	—	5	4	—	—
T10	33	307	25	2.8	4, 5	6	5	10, 12	—
T15	57	6.4	41	4.6	6	8	6	—	—
T20	93	10.5	61	6.9	—	10	8	1/4	—
T25	140	15.8	85	9.6	8	12	10	—	—
T27	199	22.5	96	10.8	10, 12	1/4	12	5/16	—
T30	276	31.2	110	12.4	1/4	—	1/4	3/8	—
T40	480	54.2	363	41.0	—	5/16, 3/8	—	7/16	—
T45	763	86.2	409	46.2	5/16	—	3/8	1/2	—
T50	1171	132.3	440	49.7	3/8	7/16	7/16	—	—
T55	1931	218.2	799	90.3	7/16, 1/2	1/2	1/2	—	—

**Minimum torque capacities Bondhus tools generate without breakage.


Other manufacturer's tools may break with considerably less torque.

Discover the Bondhus Difference

#1 In Customer Service!

Here's why:

- No Minimum Orders
- No Stocking Requirements
- No Drop Ship Fees
- No Hassle Returns
- Lifetime Warranty
- Highly-Trained, Experienced In-House Customer Service Department
- End User Education
- Full Range of Hex & Star Products
- Free Sales Aides & Merchandisers
- Custom Manufacturing
- Customer Service Hours:
7 am to 5 pm central time

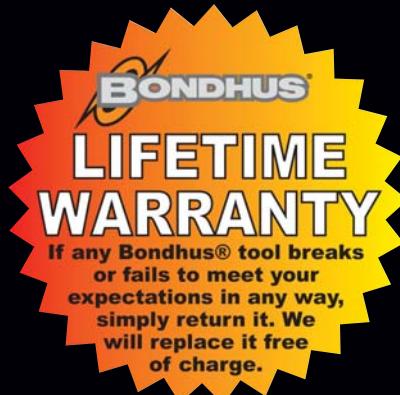

Our highly trained, experienced customer service staff is waiting to serve you. Call 1-800-328-8310 or email us at cservice@bondhus.com today!

Special Manufactured Products

As one of the few tool companies in the world that will do custom manufacturing, we can help you create the exact tool to fit your application or requirements.

- Call 800-328-8310 with your requirements. Our Customer Service Department will speak with you about:
Quantity
Tool type, length and diameter
Construction material and coating
- With 35 years of experience, we can offer suggestions on the best tool configuration for your application.
- Our engineering department will quickly process your request and offer a quotation*. Upon your approval, CAD drawings will be created. A simple signoff is all that is required.
- Production will begin. Within approximately 8 weeks from final approval, your Special Manufactured Product will be shipped.

* F.O.B. Monticello, MN. Quotes are valid for 6 months.
Minimum order is \$750 per line item



1-800-328-8310

1400 E. Broadway
P.O. Box 660
Monticello, MN 55362
U.S.A.

Phone 763-295-2162
Fax: 763-295-4440
E-mail: cservice@bondhus.com
Website: www.bondhus.com

©Bondhus Corporation 2012

Distributed by: